

Catalog Number
Notes
Type

## FEATURES & SPECIFICATIONS

**INTENDED USE** — The OLF 2RH provides years of maintenance-free general illumination for residential and commercial outdoor applications such as yards, driveways, patios, loading areas and warehouses.

**CONSTRUCTION** — Rugged cast-aluminum, corrosion-resistant rear housing and lamp heads thermally isolate the LEDs and driver promoting long life.

120V driver operates at 60 Hz.

25W, .25A.

Operating temperature -40°C to 40°C.

**OPTICS** — High-performance LEDs produce over 2,000 lumens and maintain 70% of light output at 50,000 hours of service. (LED lifespan based on IESNA LM-80-08 results and calculated per IESNA TM-21-11 methodology.)

Removable aluminum visors allow for maximum brightness or “neighbor-friendly” shading. 4000K CCT.

See Lighting Facts labels for specific fixture performance.

**INSTALLATION** — Designed for wall- or eave-mounting to existing junction box (provided by others). Mount 6-10 feet high for optimum range and detection.

**LISTINGS** — UL Certified to US and Canadian safety standards for wet-location mounting higher than 4 feet off the ground.

Tested in accordance with IESNA LM-79 and LM-80 standards.

**WARRANTY** — 5-year limited warranty. Complete warranty terms located at [www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx)

Note: Actual performance may differ as a result of end-user environment and application.

All values are design or typical values, measured under laboratory conditions at 25 °C.

Specifications subject to change without notice.




Outdoor General Purpose

# OLF 2RH



LED SECURITY FLOODLIGHT

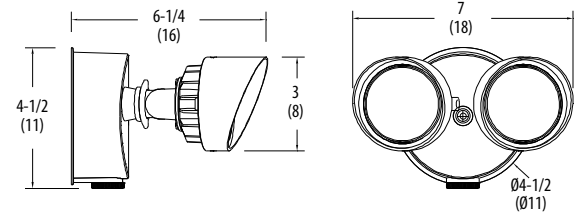

All dimensions are inches (centimeters) unless otherwise indicated.

### ORDERING INFORMATION

For shortest lead times, configure product using standard options (shown in bold).

**Example:** OLF 2RH 40K 120V BZ

Series	Light Heads	Color Temperature <sup>1</sup>	Voltage	Options	Finish
<b>OLF</b>	<b>2RH</b> 2 heads, round	<b>40K</b> 4000K	<b>120</b> 120V	<b>PE</b> Photoelectric cell, button	<b>BZ</b> Bronze <b>WH</b> White

**Notes**



<sup>1</sup> Nominal correlated color temperature (CCT) per ANSI C78.377-2008.

# OLF 2RH Outdoor LED Security Floodlight

## PHOTOMETRICS

To see complete photometric reports or download .ies files for this product, visit [www.lithonia.com](http://www.lithonia.com)

### OLF 2RH

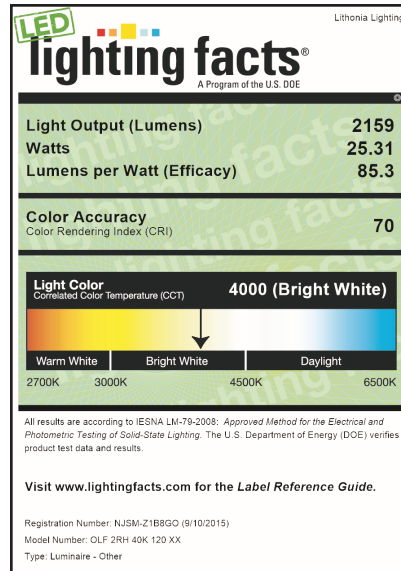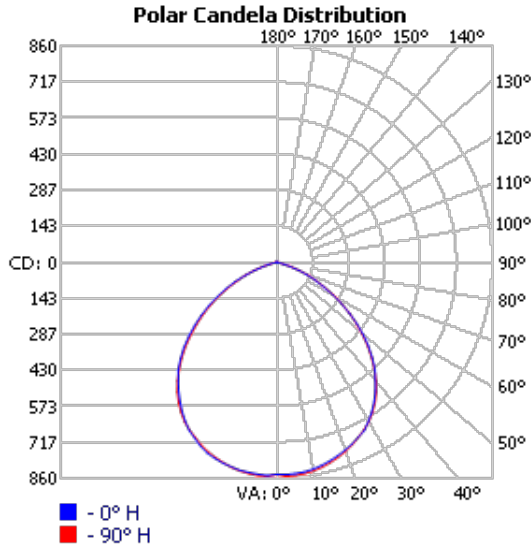

Catalog Number
Notes
Type

## FEATURES & SPECIFICATIONS

**INTENDED USE** — The OLF 2RH provides years of maintenance-free general illumination for residential and commercial outdoor applications such as yards, driveways, patios, loading areas and warehouses.

**CONSTRUCTION** — Rugged cast-aluminum, corrosion-resistant rear housing and lamp heads thermally isolate the LEDs and driver promoting long life.

120V driver operates at 60 Hz.

25W, .25A.

Operating temperature -40°C to 40°C.

**OPTICS** — High-performance LEDs produce over 2,000 lumens and maintain 70% of light output at 50,000 hours of service. (LED lifespan based on IESNA LM-80-08 results and calculated per IESNA TM-21-11 methodology.)

Removable aluminum visors allow for maximum brightness or “neighbor-friendly” shading.

4000K CCT.

See Lighting Facts labels for specific fixture performance.

**INSTALLATION** — Designed for wall- or eave-mounting to existing junction box (provided by others). Mount 6-10 feet high for optimum range and detection.

**LISTINGS** — UL Certified to US and Canadian safety standards for wet-location mounting higher than 4 feet off the ground.

Tested in accordance with IESNA LM-79 and LM-80 standards.

**WARRANTY** — 5-year limited warranty. Complete warranty terms located at

[www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx)

Note: Actual performance may differ as a result of end-user environment and application.

All values are design or typical values, measured under laboratory conditions at 25 °C.

Specifications subject to change without notice.




Outdoor General Purpose

# OLF 2RH



LED SECURITY FLOODLIGHT

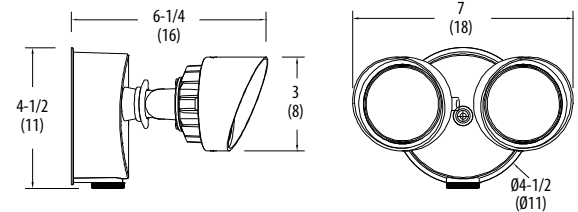

All dimensions are inches (centimeters) unless otherwise indicated.

### ORDERING INFORMATION

For shortest lead times, configure product using standard options (shown in bold).

**Example:** OLF 2RH 40K 120V BZ

Series	Light Heads	Color Temperature <sup>1</sup>	Voltage	Options	Finish
<b>OLF</b>	<b>2RH</b> 2 heads, round	<b>40K</b> 4000K	<b>120</b> 120V	<b>PE</b> Photoelectric cell, button	<b>BZ</b> Bronze <b>WH</b> White

**Notes**


<sup>1</sup> Nominal correlated color temperature (CCT) per ANSI C78.377-2008.

# OLF 2RH Outdoor LED Security Floodlight

## PHOTOMETRICS

To see complete photometric reports or download .ies files for this product, visit [www.lithonia.com](http://www.lithonia.com)

### OLF 2RH

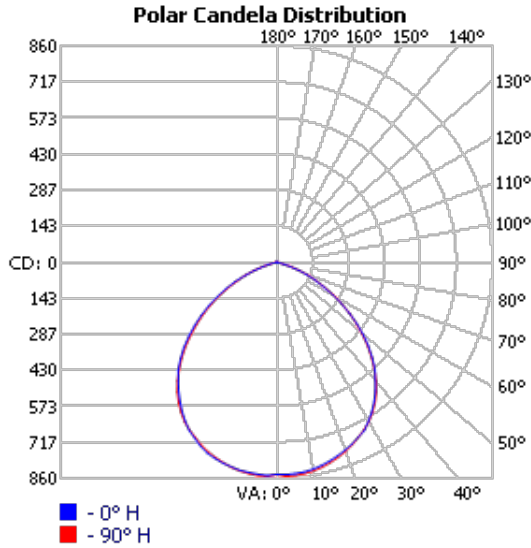

Lithonia Lighting

**LED lighting facts®**  
A Program of the U.S. DOE

Light Output (Lumens)	2159
Watts	25.31
Lumens per Watt (Efficacy)	85.3

Color Accuracy Color Rendering Index (CRI)	70
---	----

**Light Color**  
Correlated Color Temperature (CCT) **4000 (Bright White)**

Warm White | Bright White | Daylight  
2700K | 3000K | 4500K | 6500K

All results are according to IESNA LM-79-2008: *Approved Method for the Electrical and Photometric Testing of Solid-State Lighting*. The U.S. Department of Energy (DOE) verifies product test data and results.

Visit [www.lightingfacts.com](http://www.lightingfacts.com) for the **Label Reference Guide**.

Registration Number: NJSM-Z1B8G0 (8/10/2015)  
Model Number: OLF 2RH 40K 120 XX  
Type: Luminaire - Other