



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## 30.5 mm, Heavy-Duty, Assembled Selector Switch

10250T20KB-POP

UPC:782114408506

### Dimensions:

- **Height:** 3 IN
- **Length:** 7 IN
- **Width:** 6 IN

**Weight:** .43 LB

**Notes:** Includes three different legend plates. Point-of-Purchase Packaging.

### Warranties:

- 1 year

### Specifications:

- **Type:** 30.5 mm, Heavy-Duty
- **Actuator:** Knob
- **Actuator Color:** Black
- **Contact Configuration:** 1NO-1NC
- **Illumination:** Non-illuminated
- **Legend:** OFF/ON HAND/AUTO RUN/JOG
- **Number Of Positions:** Two-position
- **Rating:** NEMA 3, 3R, 4, 4X, 12, 13
- **Series:** 10250T

### Supporting documents:


- [Eatons Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [Quick Selector - 10250T Pilot Devices](#)

### Certifications:

- UL Listed
- CSA Certified

### Product compliance:

- CE Marked

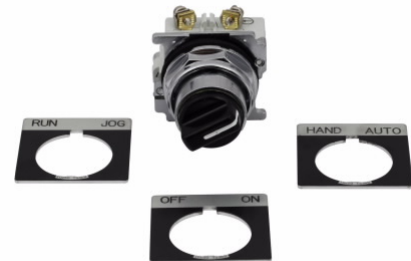





Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## 30.5 mm, Heavy-Duty, Assembled Selector Switch

10250T20KB-POP

UPC:782114408506

### Dimensions:

- **Height:** 3 IN
- **Length:** 7 IN
- **Width:** 6 IN

**Weight:** .43 LB

**Notes:** Includes three different legend plates. Point-of-Purchase Packaging.

### Warranties:

- 1 year

### Specifications:

- **Type:** 30.5 mm, Heavy-Duty
- **Actuator:** Knob
- **Actuator Color:** Black
- **Contact Configuration:** 1NO-1NC
- **Illumination:** Non-illuminated
- **Legend:** OFF/ON HAND/AUTO RUN/JOG
- **Number Of Positions:** Two-position
- **Rating:** NEMA 3, 3R, 4, 4X, 12, 13
- **Series:** 10250T

### Supporting documents:

- [Eaton's Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [Quick Selector - 10250T Pilot Devices](#)

### Certifications:

- UL Listed
- CSA Certified

### Product compliance:

- CE Marked



