



123-M CONDUIT TO Z PURLIN CLIP, 3/4", 1" EMT, 0.922"–1.378" OD, 0.06"–0.1" FLANGE

CATALOG NUMBER

12316M



CERTIFICATIONS



FEATURES

Snap-close conduit support

Conduit clip rotates 360 degrees

Supports conduit from purlin

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

EMT Conduit Size: 3/4";1"


Outer Diameter (OD): 0.920" - 1.38"

Flange Thickness (FT): 0.0600" - 0.1"

B: 5/8" Min

Static Load (F): 100lb

DIAGRAMS

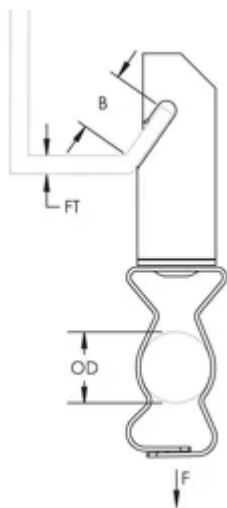

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER



123-M CONDUIT TO Z PURLIN CLIP, 3/4", 1" EMT, 0.922"–1.378" OD, 0.06"–0.1" FLANGE

CATALOG NUMBER

12316M



CERTIFICATIONS




FEATURES

- Snap-close conduit support
- Conduit clip rotates 360 degrees
- Supports conduit from purlin

PRODUCT ATTRIBUTES

- Material: Spring Steel
- Finish: nVent CADDY Armour
- EMT Conduit Size: 3/4";1"
- Outer Diameter (OD): 0.920" - 1.38"
- Flange Thickness (FT): 0.0600" - 0.1"
- B: 5/8" Min
- Static Load (F): 100lb

DIAGRAMS

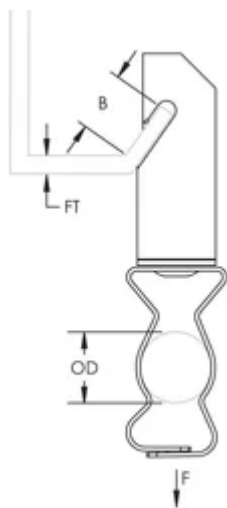

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER