

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300170020

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Field Attachable, Male Connector, 4 Pole, Cable Range: 5.08-11.43mm Outside Diameter with External Threads

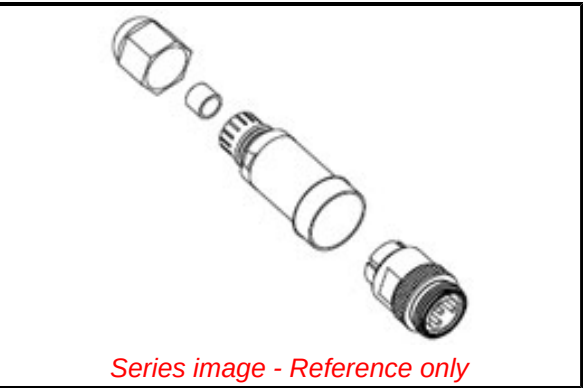

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	130017
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	78172553189
Physical	
Cable Diameter	5.08-11.43mm (.200-.450")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold over Copper
Net Weight	57.500/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A4006-34
Reference - Drawing Numbers	
Sales Drawing	SD-130017-008

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130017 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300170020

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Field Attachable, Male Connector, 4 Pole, Cable Range: 5.08-11.43mm Outside Diameter with External Threads

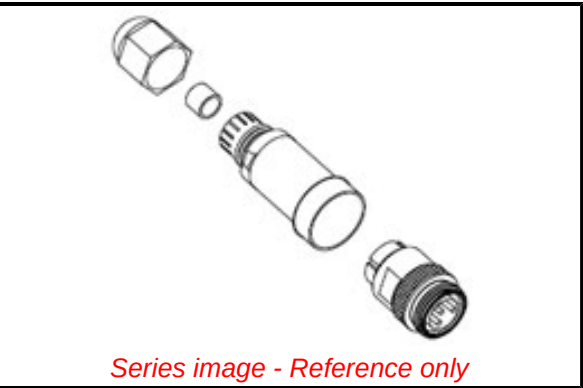

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	130017
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	78172553189
Physical	
Cable Diameter	5.08-11.43mm (.200-.450")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold over Copper
Net Weight	57.500/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A4006-34
Reference - Drawing Numbers	
Sales Drawing	SD-130017-008

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130017 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION