





GE
Lighting

16069 - 200A/CL-1 12PK

GE crystal clear 200 watt A21 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- 2900K soft white light appearance
- A21 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- Lasts 0.7 years based on 3 hours per day usage
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- 3780 lumens providing strong, vibrant™ light

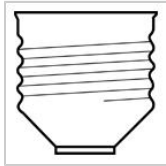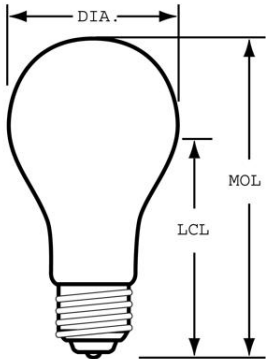

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	3780.0
Color Temperature	2900.0 K
Nominal Initial Lumens per Watt	18

ELECTRICAL CHARACTERISTICS

Wattage	200.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	2.625 in(66.7 mm)
Light Center Length (LCL)	4.060 in(103.1 mm)

PRODUCT INFORMATION

Product Code	16069
Description	200A/CL-1 12PK
Standard Package	Case
Standard Package GTIN	00043168160698
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168904568





GE
Lighting

16069 - 200A/CL-1 12PK

GE crystal clear 200 watt A21 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- 2900K soft white light appearance
- A21 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- Lasts 0.7 years based on 3 hours per day usage
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- 3780 lumens providing strong, vibrant™ light

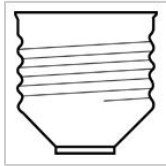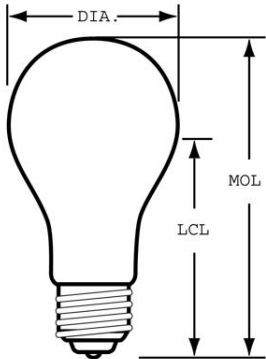

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	3780.0
Color Temperature	2900.0 K
Nominal Initial Lumens per Watt	18

ELECTRICAL CHARACTERISTICS

Wattage	200.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	2.625 in(66.7 mm)
Light Center Length (LCL)	4.060 in(103.1 mm)

PRODUCT INFORMATION

Product Code	16069
Description	200A/CL-1 12PK
Standard Package	Case
Standard Package GTIN	00043168160698
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168904568