


### Commercial grade AC toggle combination switches

#### Product description

Single-pole, 3-way  
 15A, 120/277V/AC; 15A, 120V/AC  
 20A, 120V/AC

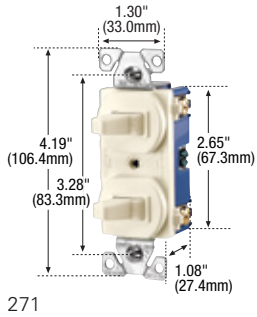


#### Toggle combination switches, back & side wire



Rating	A	V/AC	Description	Color suffix	Catalog no.	
15	120/277	(2) Single-pole, switches	A, B, LA, V, W	□ 271__	•	
		(1) Single-pole, switch with (1) 3-Way switch	B, LA, V, W	□ 275__	•	
		(2) 3-Way, switches	LA, V, W	□ 276__	•	
15	120	(1) Single-pole, switch 1/25w (1) 125V pilot light	B, LA, V, W	□ 277__*	•	
		(1) 3-Way, switch w/pilot light 1/25w (1) 125V pilot light	B, V	□ 294__*	•	

\* Not NOM cert

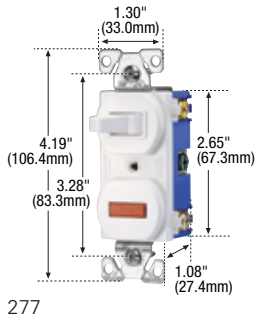


#### Toggle switch with receptacle, back & side wire



Rating	A	V/AC	Description	Color suffix	Catalog no.	
15	120	(1) Single-pole, switch with NEMA 5-15	A, B, BK, LA, V, W	□ TR274__	•	
15	125	(1) 2-Pole, 3-wire tamper resistant receptacle				
15	120	(1) 3-Way switch with NEMA 5-15	A, B, BK, LA, V, W	□ TR293__	•	
15	125	(1) 2-Pole, 3-wire tamper resistant receptacle				
15	120	(1) Single-pole, switch with NEMA 5-20	A, B, BK, LA, V, W	□ TR291__*	•	
20	125	(1) 2-Pole, 3-wire tamper resistant receptacle				

\* Not NOM cert

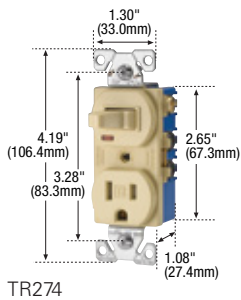

#### Accessories for commercial specification grade toggle combination switches



Description	Catalog no.	
1-Gang, standard size duplex, 302/304 Stainless steel receptacle wallplate	□ 93101	• •
1-Gang, standard size duplex, unbreakable nylon receptacle wallplate, almond	□ 5132A	• •



93101



5132A

#### Color ordering information:

For ordering devices, include Catalog no. Followed by the Color suffix: A (Almond), B (Brown), BK (Black), LA (Light Almond), V (Ivory), W (White)

A	B	BK	LA	V	W
(Almond)	(Brown)	(Black)	(Lt. Almond)	(Ivory)	(White)

**Specification information:** 120/277V/AC commercial toggle combination: E-40

**Compliances, specifications and availability are subject to change without notice.**

Indicates NAFTA compliant - Page Q-32


RoHS compliant - Page Q-32

Tamper resistant

### Commercial grade AC toggle combination switches

#### Product description

Single-pole, 3-way  
 15A, 120/277V/AC; 15A, 120V/AC  
 20A, 120V/AC

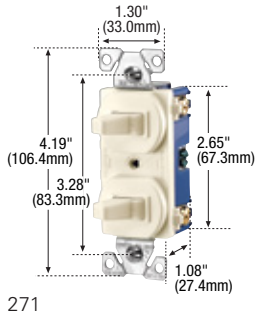


#### Toggle combination switches, back & side wire



Rating		Description	Color suffix	Catalog no.	✓
A	V/AC				
15	120/277	(2) Single-pole, switches	A, B, LA, V, W	□ 271__	•
		(1) Single-pole, switch with (1) 3-Way switch	B, LA, V, W	□ 275__	•
		(2) 3-Way, switches	LA, V, W	□ 276__	•
15	120	(1) Single-pole, switch 1/25w (1) 125V pilot light	B, LA, V, W	□ 277__*	•
		(1) 3-Way, switch w/pilot light 1/25w (1) 125V pilot light	B, V	□ 294__*	•

\* Not NOM cert

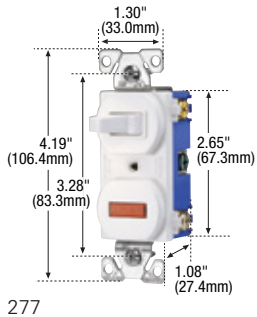


#### Toggle switch with receptacle, back & side wire



Rating		Description	Color suffix	Catalog no.	✓
A	V/AC				
15	120	(1) Single-pole, switch with NEMA 5-15	A, B, BK, LA, V, W	□ TR274__	•
15	125	(1) 2-Pole, 3-wire tamper resistant receptacle			
15	120	(1) 3-Way switch with NEMA 5-15	A, B, BK, LA, V, W	□ TR293__	•
15	125	(1) 2-Pole, 3-wire tamper resistant receptacle			
15	120	(1) Single-pole, switch with NEMA 5-20	A, B, BK, LA, V, W	□ TR291__*	•
20	125	(1) 2-Pole, 3-wire tamper resistant receptacle			

\* Not NOM cert

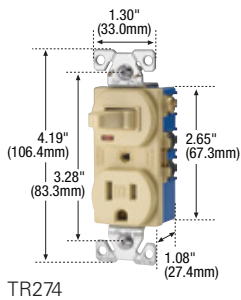

#### Accessories for commercial specification grade toggle combination switches



Description	Catalog no.	USA	✓
1-Gang, standard size duplex, 302/304 Stainless steel receptacle wallplate	□ 93101	•	•
1-Gang, standard size duplex, unbreakable nylon receptacle wallplate, almond	□ 5132A	•	•



93101



5132A

#### Color ordering information:

For ordering devices, include Catalog no. Followed by the Color suffix: A (Almond), B (Brown), BK (Black), LA (Light Almond), V (Ivory), W (White)

A	B	BK	LA	V	W
(Almond)	(Brown)	(Black)	(Lt. Almond)	(Ivory)	(White)

**Specification information:** 120/277V/AC commercial toggle combination: E-40

**Compliances, specifications and availability are subject to change without notice.**

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32

Tamper resistant