

SNA Terminal Blocks
T&B Catalog Number:

029006107

UPC Number:

66201997013

Status:

Active

Description:

Gray feed through terminal block with 6 mm spacing, 25 amp rated UL current and spring clamp connection

Features

Top entry wire connection

Touch-safe IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

| | |
|--|--------------|
| Style | Feed Through |
| Color | Gray |
| Mounting | DIN 3 |
| Series | D 4/6.2L |
| Connection Technology | Spring Clamp |
| UL Wire Range (AWG) | 24-10 |
| Rated IEC Wire Range (Solid) (mm ²) | 0.2 - 6 |
| Rated IEC Wire Range (Stranded) (mm ²) | 0.2 - 4 |

Dimension Information

| | |
|------------------|--------------------|
| L x W x H (mm) | 62.5 x 6 x 38 |
| Spacing (mm) | 6 |
| L x W x H (in) | 2.46 x .238 x 1.49 |
| Spacing (inches) | .238 |

Specifications

| | |
|--------------------------|-----|
| UL Current (Amps) | 25 |
| UL Voltage (VAC) | 600 |
| Rated UL Wire Size (AWG) | 10 |

Packaging


| | |
|--------------------|-------------------|
| T&B Order Multiple | 50 |
| T&B Inner Pack | 50 |
| Package in Units | 750 |
| T&B Sold in UOM | Each |
| T&B Weight Per UOM | 2.13 lbs. per 100 |

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email: techsupport@tnb.com

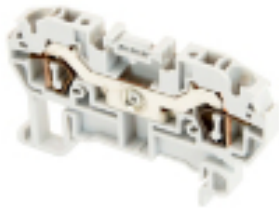

SNA Terminal Blocks
T&B Catalog Number:

029006107

UPC Number:

66201997013

Status:

Active

Description:

Gray feed through terminal block with 6 mm spacing, 25 amp rated UL current and spring clamp connection

Features

Top entry wire connection

Touch-safe IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

| | |
|--|--------------|
| Style | Feed Through |
| Color | Gray |
| Mounting | DIN 3 |
| Series | D 4/6.2L |
| Connection Technology | Spring Clamp |
| UL Wire Range (AWG) | 24-10 |
| Rated IEC Wire Range (Solid) (mm ²) | 0.2 - 6 |
| Rated IEC Wire Range (Stranded) (mm ²) | 0.2 - 4 |

Dimension Information

| | |
|------------------|--------------------|
| L x W x H (mm) | 62.5 x 6 x 38 |
| Spacing (mm) | 6 |
| L x W x H (in) | 2.46 x .238 x 1.49 |
| Spacing (inches) | .238 |

Specifications

| | |
|--------------------------|-----|
| UL Current (Amps) | 25 |
| UL Voltage (VAC) | 600 |
| Rated UL Wire Size (AWG) | 10 |

Packaging

| | |
|--------------------|-------------------|
| T&B Order Multiple | 50 |
| T&B Inner Pack | 50 |
| Package in Units | 750 |
| T&B Sold in UOM | Each |
| T&B Weight Per UOM | 2.13 lbs. per 100 |

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email: techsupport@tnb.com