



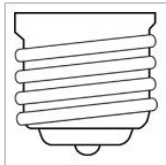

GE  
Lighting

**21025 - 300**

GE Arcstream® PS35

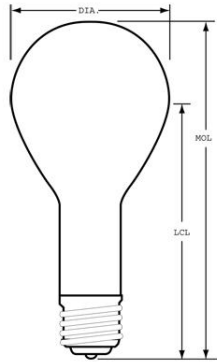

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - A-line
Bulb	PS35
Base	Mogul Screw (E39)
Filament	C-9
Bulb Finish	Clear
Rated Life	1000.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	5200.0
Nominal Initial Lumens per Watt	19

**ELECTRICAL CHARACTERISTICS**

Wattage	300.0
Voltage	130.0

**DIMENSIONS**

Maximum Overall Length (MOL)	9.3700 in(238.0 mm)
Bulb Diameter (DIA)	4.375 in(111.1 mm)
Light Center Length (LCL)	7.000 in(177.8 mm)

**PRODUCT INFORMATION**



Product Code	21025
Description	300
Standard Package	Case
Standard Package GTIN	10043168210253
Standard Package Quantity	24
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	24
UPC	043168210256



GE  
Lighting

**21025 - 300**

GE Arcstream® PS35

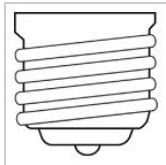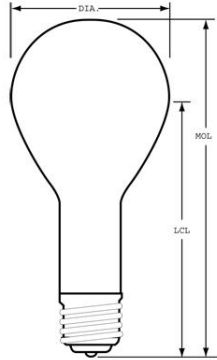

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - A-line
Bulb	PS35
Base	Mogul Screw (E39)
Filament	C-9
Bulb Finish	Clear
Rated Life	1000.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	5200.0
Nominal Initial Lumens per Watt	19

**ELECTRICAL CHARACTERISTICS**

Wattage	300.0
Voltage	130.0

**DIMENSIONS**

Maximum Overall Length (MOL)	9.3700 in(238.0 mm)
Bulb Diameter (DIA)	4.375 in(111.1 mm)
Light Center Length (LCL)	7.000 in(177.8 mm)

**PRODUCT INFORMATION**

Product Code	21025
Description	300
Standard Package	Case
Standard Package GTIN	10043168210253
Standard Package Quantity	24
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	24
UPC	043168210256