






GE
Lighting

27495 - 40A15/F/CD

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

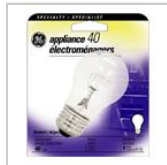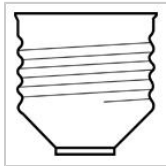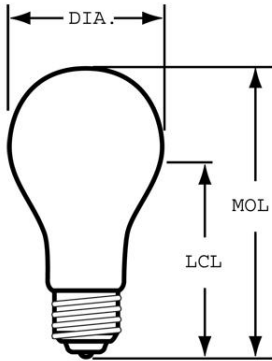

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Frost
Rated Life (NOM)	1500.0 h
Bulb Material	Soft glass
Primary Application	Standard;Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	355.0
Color Temperature (NOM)	2600.0 K
Nominal Initial Lumens per Watt (NOM)	8.875

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	40.0
Voltage (NOM)	120.0
Burn Position	Universal burning position

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	3.500 in(88.9 mm)
Bulb Diameter (DIA) (NOM)	1.875 in(47.6 mm)
Light Center Length (LCL) (NOM)	2.370 in(60.2 mm)

PRODUCT INFORMATION

Product Code	27495
Description	40A15/F/CD
Standard Package	BUNDLE
Standard Package GTIN	30043168274952
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168274951






GE
Lighting

27495 - 40A15/F/CD

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

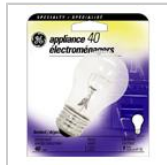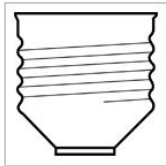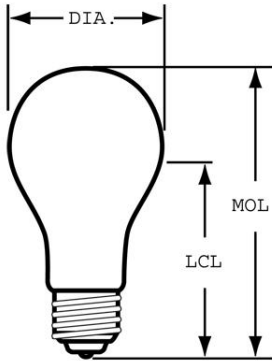

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Frost
Rated Life (NOM)	1500.0 h
Bulb Material	Soft glass
Primary Application	Standard;Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	355.0
Color Temperature (NOM)	2600.0 K
Nominal Initial Lumens per Watt (NOM)	8.875

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	40.0
Voltage (NOM)	120.0
Burn Position	Universal burning position

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	3.500 in(88.9 mm)
Bulb Diameter (DIA) (NOM)	1.875 in(47.6 mm)
Light Center Length (LCL) (NOM)	2.370 in(60.2 mm)

PRODUCT INFORMATION

Product Code	27495
Description	40A15/F/CD
Standard Package	BUNDLE
Standard Package GTIN	30043168274952
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168274951