


Heavy Duty Grade Vinyl Plugs & Connectors

2-Pole, 3-Wire Grounding
15A, 125V/AC
20A, 125V/AC

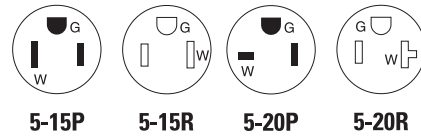

FEATURES

- Solid brass plug blades are firmly embedded in body.
- Vinyl plugs and connectors resist chemical attack and are less brittle in extremely low temperatures.
- Vinyl angle plugs have eight possible positions for maximum convenience.
- Terminals in individual chambers to positively insulate conductors.
- Terminal screw clamps are designed to contain wire and prevent binding.
- Terminal screws backed out and ready for wiring.
- Combination Slot/Phillips head mounting and terminal screws for installation flexibility (Slot/Robertson screws in Canada where available).

Vinyl Plugs & Connectors

15A 125V/AC; 20A 125V/AC

Description	Cord Diameter	Color	Plug	Catalog No.	
				<input type="checkbox"/> 4867	<input type="checkbox"/> 4887
15A NEMA 5-15, Straight Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4867	<input checked="" type="checkbox"/>	<input type="checkbox"/> 4887
15A NEMA 5-15, Angled Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4867AN	<input checked="" type="checkbox"/>	—
15A NEMA 5-15, Angled Body	0.25-0.66" (6.4-16.6mm)	White	<input type="checkbox"/> 4867ANW	<input checked="" type="checkbox"/>	—
20A NEMA 5-20, Straight Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4409	<input checked="" type="checkbox"/>	<input type="checkbox"/> 4228
20A NEMA 5-20, Angled Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4409AN	<input checked="" type="checkbox"/>	—




4867ANW

Listed to UL498, file no. E15012; CSA certified to C22.2, no. 42; NOM certified except 4228

Heavy Duty Grade Vinyl Plugs & Connectors

2-Pole, 3-Wire Grounding
15A, 250V/AC
20A, 250V/AC

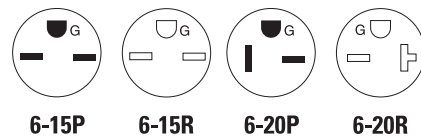

FEATURES

- Solid brass plug blades are firmly embedded in body.
- Vinyl plugs and connectors resist chemical attack and are less brittle in extremely low temperatures.
- Vinyl angle plugs have eight possible positions for maximum convenience.
- Terminals in individual chambers to positively insulate conductors.
- Terminal screw clamps are designed to contain wire and prevent binding.
- Terminal screws backed out and ready for wiring.
- Combination Slot/Phillips head mounting and terminal screws for installation flexibility (Slot/Robertson screws in Canada where available).

Vinyl Plugs & Connectors

15A 250V/AC; 20A 250V/AC

Description	Cord Diameter	Color	Plug	Catalog No.	
				<input type="checkbox"/> 4866	<input type="checkbox"/> 4227
15A NEMA 6-15, Straight Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4866	<input checked="" type="checkbox"/>	<input type="checkbox"/> 4227
15A NEMA 6-15, Angled Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4866AN	<input checked="" type="checkbox"/>	—
20A NEMA 6-20, Straight Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4509	<input checked="" type="checkbox"/>	<input type="checkbox"/> 4229
20A NEMA 6-20, Angled Body	0.25-0.66" (6.4-16.6mm)	Yellow	<input type="checkbox"/> 4509AN	<input checked="" type="checkbox"/>	—




4229

Listed to UL498, file no. E15012; CSA certified to C22.2, no. 42; NOM certified except 4227 & 4229

Dimensional Information: B-62
Specification Information: Please visit www.cooperwiringdevices.com

NAFTA Compliant: See page F-21

Power Devices, Flush Receptacles

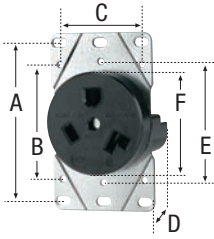

Cat. Nos.	A	B	C	D (depth)	E	F (face dia.)
30 & 1200 Series	3.28" (83.3mm)	2.38" (60.5mm)	1.81" (46.0mm)	1.42" (36.1mm)	2.50" (63.5mm)	2.10" (53.5mm)

Power Devices, Surface Receptacles




Cat. Nos.	A	B	C
100 & 1200 Series	2.10" (53.3mm)	4.75" (120.7mm)	2.50" (63.5mm)

Power Devices, Panel Mount Receptacles




Cat. Nos.	A	B
58, 60	2.80" (71.1mm)	2.80" (71.1mm)
U1263	1.69" (42.9mm)	2.09" (53.1mm)

Power Devices, Angled Plugs

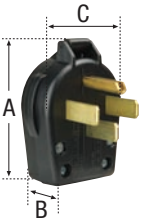


Cat. Nos.	A	B	C	Cord Dia.
S80 & 83	2.92" (74.2mm)	1.03" (26.2mm)	2.80" (71.1mm)	S80: 0.80" (20.3mm) max. 83: 0.64" (16.3mm) max.
S41 & S42 S20 & S21	3.37" (85.6mm)	1.38" (35.1mm)	2.87" (72.9mm)	S41 & S42: 1.10" (27.9mm) S20 & S21: 1.13" (28.7mm)

Miscellaneous Power Devices

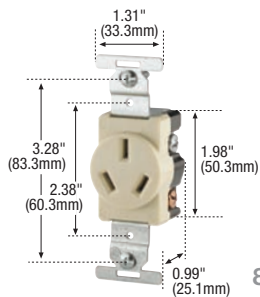

805V

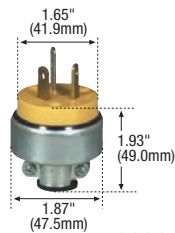


2836

Heavy Duty Grade Connectors



Family	A	B	C	Cord Dia.
QuickGrip™	1.40" (35.6mm)	2.57" (65.4mm)	1.65" (42.0mm)	0.22-0.66" (5.6-16.8mm)
Armored Vinyl	1.35" (34.3mm)	2.60" (66.0mm)	1.50" (38.1mm)	0.25-0.63" (6.4-15.9mm)
Vinyl	1.35" (34.3mm)	2.61" (66.3mm)	1.54" (39.1mm)	0.25-0.66" (6.4-16.6mm)
Rubber	1.36" (34.5mm)	2.90" (73.7mm)	1.54" (39.1mm)	0.25-0.60" (6.4-15.2mm)

Heavy Duty Grade Plugs

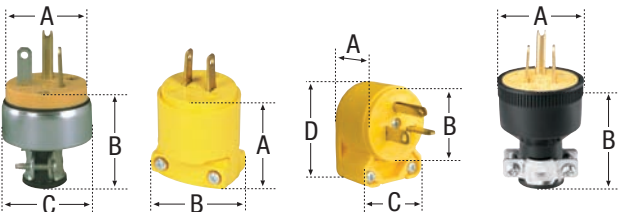

Family	A	B	C	D	Cord Dia.
QuickGrip™	1.40" (35.6mm)	1.95" (49.7mm)	1.68" (42.6mm)	-	0.22-0.66" (5.6-16.8mm)
Armored Vinyl	1.65" (41.9mm)	1.93" (49.0mm)	1.87" (47.4mm)	-	0.25-0.63" (6.4-15.9mm)
Vinyl	1.65" (41.9mm)	1.54" (39.1mm)	-	-	0.25-0.66" (6.4-16.8mm)
Angled Vinyl	1.25" (31.8mm)	1.42" (36.1mm)	1.50" (38.1mm)	1.95" (49.5mm)	0.25-0.66" (6.4-16.8mm)
Rubber	1.54" (39.1mm)	2.00" (50.8mm)	-	-	0.25-0.60" (6.4-15.2mm)