



THREADED ROD HANGER W/ANGLE BRACKET 0.25" HOLE 1 PLAIN, 0.25" HOLE 2 THREADED

CATALOG NUMBER

4TIB



CERTIFICATIONS



FEATURES

Suspends threaded rod from horizontal structures such as laminated wood or concrete beams, joists, ceilings and walls

PRODUCT ATTRIBUTES

Material: Spring Steel;Steel

Finish: nVent CADDY Armour;Pregalvanized

Hole Size 1 (HS1): 1/4"

Hole Type 1: Plain

Hole Size 2 (HS2): 1/4"

Hole Type 2: Threaded


Static Load (F): 160lb

ADDITIONAL PRODUCT DETAILS

Loads indicated are for nVent CADDY Fasteners only.

Method of attachment to structure must be evaluated separately.

DIAGRAMS

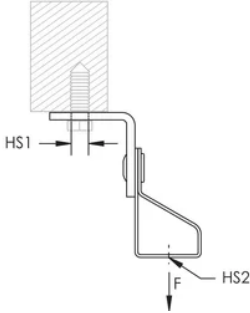

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER



THREADED ROD HANGER W/ANGLE BRACKET 0.25" HOLE 1 PLAIN, 0.25" HOLE 2 THREADED

CATALOG NUMBER

4TIB



CERTIFICATIONS



FEATURES

Suspends threaded rod from horizontal structures such as laminated wood or concrete beams, joists, ceilings and walls

PRODUCT ATTRIBUTES

Material: Spring Steel;Steel

Finish: nVent CADDY Armour;Pregalvanized

Hole Size 1 (HS1): 1/4"

Hole Type 1: Plain

Hole Size 2 (HS2): 1/4"

Hole Type 2: Threaded


Static Load (F): 160lb

ADDITIONAL PRODUCT DETAILS

Loads indicated are for nVent CADDY Fasteners only.

Method of attachment to structure must be evaluated separately.

DIAGRAMS

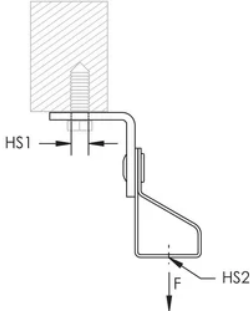

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER