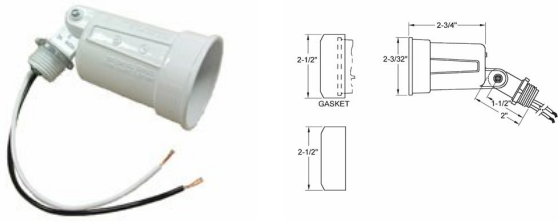


**LAMP HOLDERS****Traditional Lampholder**
75-150 Watt Par 38 Lamps**D23**

Catalog #: 5606-1

APPLICATIONS

For general outdoor lighting in wet, damp or dry locations
 May be used with BELL® cluster covers and boxes

PRODUCT FEATURES

Rugged die cast construction
 State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
 Locking swivel knuckle assures positive lamp positioning and provides pin-point directional aiming
 Extra long wire leads for easy hook-up
 Porcelain socket
 Inside Gasket
 Multi-lingual instructions in each package
 1/2 in. locknut
 N/A

UL LISTED

Standard 1598

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION


Color: White

PRODUCT MEASUREMENTS

Wt. Ea. (Lbs.): 0.464

PACKAGING

Package Type: Shrink
 Std. Pkg.: 30
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 46.40
 Ship Carton Length (in.): 16.19
 Ship Carton Width (in.): 4.25
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 13.92
 Pallet Qty: 4500.00
 UPC Number: 050169560617
 I2of5: 50050169560612

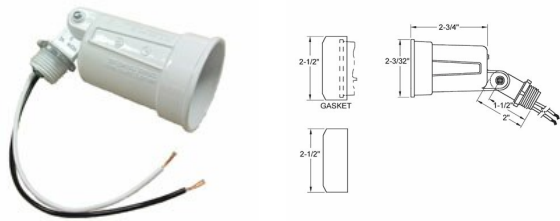**LAMP HOLDERS****Traditional Lampholder
75-150 Watt Par 38 Lamps****D23**

Catalog #: 5606-1

APPLICATIONS

For general outdoor lighting in wet, damp or dry locations
 May be used with BELL® cluster covers and boxes

PRODUCT FEATURES

Rugged die cast construction
 State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
 Locking swivel knuckle assures positive lamp positioning and provides pin-point directional aiming
 Extra long wire leads for easy hook-up
 Porcelain socket
 Inside Gasket
 Multi-lingual instructions in each package
 1/2 in. locknut
 N/A

UL LISTED

Standard 1598

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Color: White

PRODUCT MEASUREMENTS

Wt. Ea. (Lbs.): 0.464

PACKAGING

Package Type: Shrink
 Std. Pkg.: 30
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 46.40
 Ship Carton Length (in.): 16.19
 Ship Carton Width (in.): 4.25
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 13.92
 Pallet Qty: 4500.00
 UPC Number: 050169560617
 I2of5: 50050169560612