




GE  
Lighting

**26591 - 755**

GE T3.25 (T3 1/4) - Low Voltage

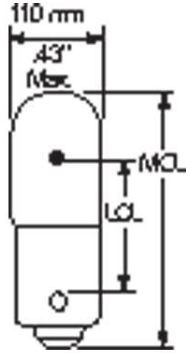

**GENERAL CHARACTERISTICS**

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	20000.0 hrs
Bulb Material	Hard glass
Atmosphere	Vacuum
Primary Application	Low Voltage

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.33

**ELECTRICAL CHARACTERISTICS**

Wattage	1.0
Voltage	6.3

**DIMENSIONS**

Maximum Overall Length (MOL)	1.19 cm
Bulb Diameter (DIA)	0.406 cm
Light Center Length (LCL)	0.78 cm

**PRODUCT INFORMATION**


Product Code	26591
Description	755
ANSI Code	755
Standard Package	Case
Standard Package GTIN	10043168265918
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168265911



GE  
Lighting

**26591 - 755**

GE T3.25 (T3 1/4) - Low Voltage

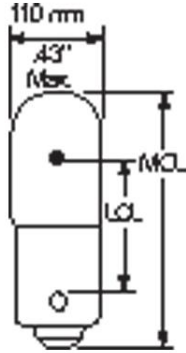

### GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	20000.0 hrs
Bulb Material	Hard glass
Atmosphere	Vacuum
Primary Application	Low Voltage

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.33

### ELECTRICAL CHARACTERISTICS

Wattage	1.0
Voltage	6.3

### DIMENSIONS

Maximum Overall Length (MOL)	1.19 cm
Bulb Diameter (DIA)	0.406 cm
Light Center Length (LCL)	0.78 cm

### PRODUCT INFORMATION

Product Code	26591
Description	755
ANSI Code	755
Standard Package	Case
Standard Package GTIN	10043168265918
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168265911