



842

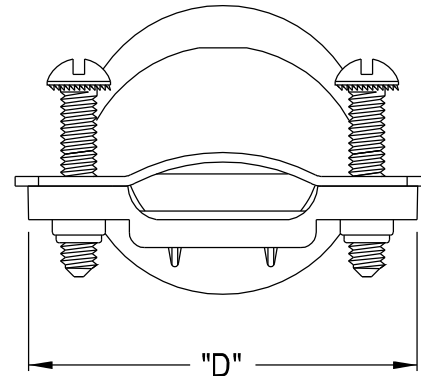

843-849

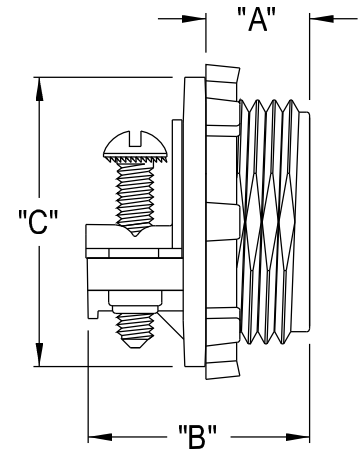

849	2"	.750	1.630	2.632	3.020	1.700-1.940
848	1 1/2"	.723	1.470	2.115	2.990	1.210-1.690
844	1 1/4"	.650	1.325	1.890	2.250	.990-1.160
843	1"	.540	1.180	1.505	2.030	.790-.980
842	3/4"	.475	1.060	1.125	1.650	.300-.780
PART NO.	TRADE SIZE	"A"	"B"	"C"	"D"	"CABLE RANGE"