



## Fittings and Brackets


### U Shape Fittings

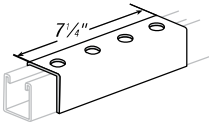


**CAT. NO. A208**  
Does not include strut nut or bolts. For "A" series channel.

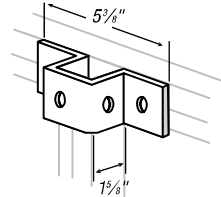


**CAT. NO. A210**  
For attaching "A" series channel

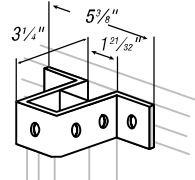


**CAT. NO. A211**  
For attaching "A" series channel.

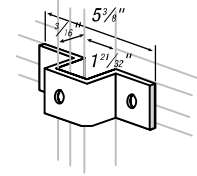


**CAT. NO. B210**

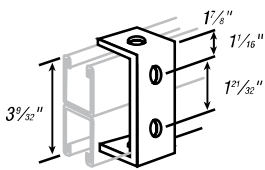


**CAT. NO. AB245**

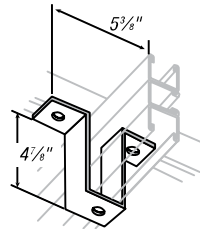


**CAT. NO. AN211**

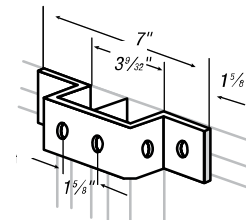


**CAT. NO. A212**

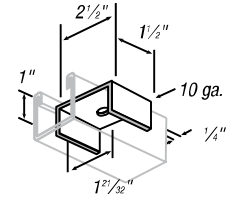


**CAT. NO. AB-288**

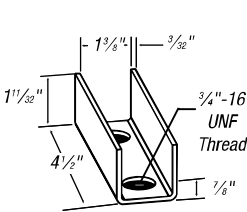

**CAT. NO. A-213**

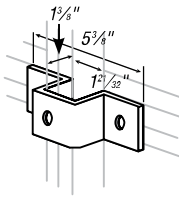

**CAT. NO. C210**  
For attaching "C" series channel.

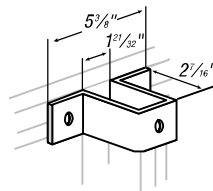


**CAT. NO. E210**  
For attaching "E" series channel.

#### Standard Dimensions


- Hole Spacing: 1 3/8" From End
- Hole Spacing: 1 7/8" Centers
- Hole Size: 1" Diameter
- Material: 1 5/8" Width
- Material: 1/4" Thick

Standard Finish – GoldGalv®, unless otherwise stated.  
Add EG suffix for SilverGalv® Finish


### Angular Fittings

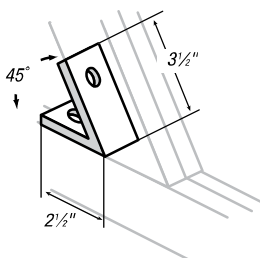

**CAT. NO. AB225**

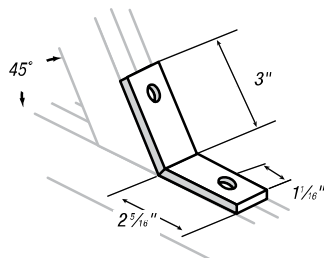

**CAT. NO. AB227**

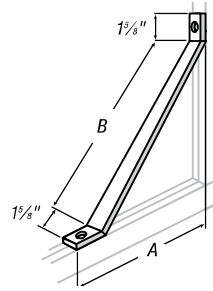


**CAT. NO. AB-239**

CAT. NO.	A (IN.)	B (IN.)	STD. CTN.
AB239 1	7 13/16	8 1/2	15
AB-239-2	13 3/4	17	10
AB-239-3	19 3/4	25 1/2	10


Standard Finish – GoldGalv®, unless otherwise stated.  
Add EG suffix for SilverGalv® Finish

## Fittings and Brackets


### U Shape Fittings

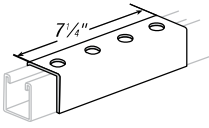


**CAT. NO. A208**  
Does not include strut nut or bolts. For "A" series channel.

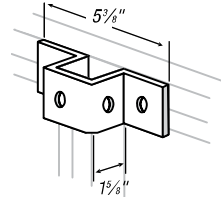


**CAT. NO. A210**  
For attaching "A" series channel.

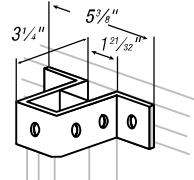


**CAT. NO. A211**  
For attaching "A" series channel.

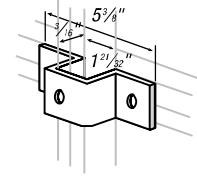


**CAT. NO. B210**

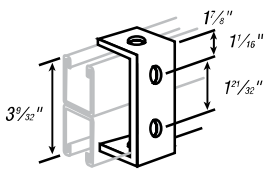


**CAT. NO. AB245**

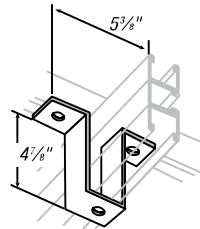


**CAT. NO. AN211**

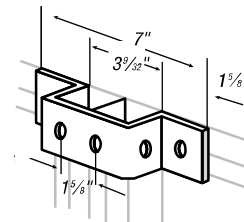


**CAT. NO. A212**

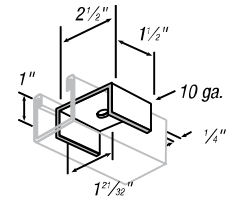


**CAT. NO. AB-288**

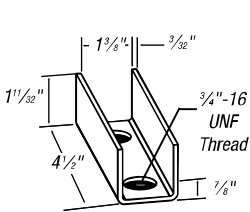

**CAT. NO. A-213**

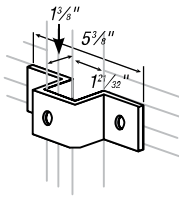

**CAT. NO. C210**  
For attaching "C" series channel.

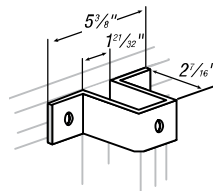


**CAT. NO. E210**  
For attaching "E" series channel.

#### Standard Dimensions


- Hole Spacing: 1 3/8" From End
- Hole Spacing: 1 1/2" Centers
- Hole Size: 1" Diameter
- Material: 1 3/8" Width
- Material: 1/4" Thick

Standard Finish – GoldGalv®, unless otherwise stated.  
Add EG suffix for SilverGalv® Finish


### Angular Fittings

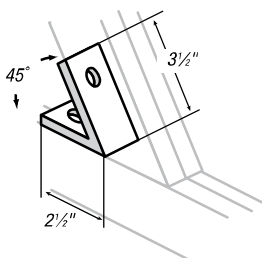

**CAT. NO. AB225**

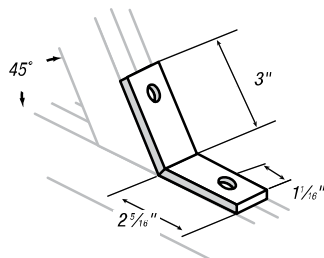

**CAT. NO. AB227**

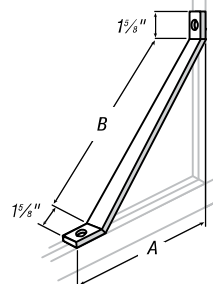

**CAT. NO. AB-239**

CAT. NO.	A (IN.)	B (IN.)	STD. CTN.
AB239 1	7 13/16	8 1/2	15
AB-239-2	13 3/4	17	10
AB-239-3	19 3/4	25 1/2	10

Standard Finish – GoldGalv®, unless otherwise stated.  
Add EG suffix for SilverGalv® Finish