


# B26RIC

## 6" Shallow IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

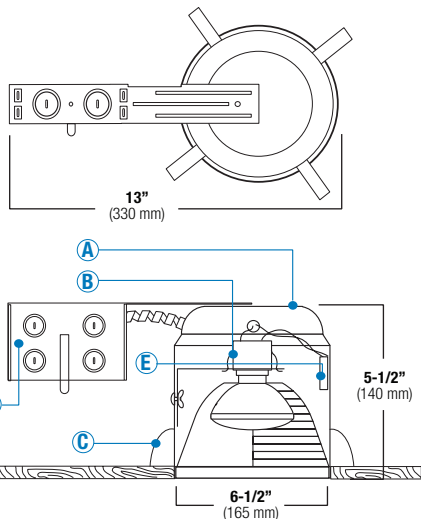

**SAME DAY**  
SHIPPING

PROUDLY  
ASSEMBLED in  
AMERICA

**UL**  
LISTED

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE					BAFFLE	REFLECTOR	TRIM/RING	GLASS
B26RIC	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630	<input type="checkbox"/> B616	<input type="checkbox"/> B642	<input type="checkbox"/> B648	<input type="checkbox"/> B644	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> Green
			<input type="checkbox"/> B620	<input type="checkbox"/> B663	<input type="checkbox"/> B641	<input type="checkbox"/> B652	<input type="checkbox"/> B650	<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> Yellow
			<input type="checkbox"/> B631	<input type="checkbox"/> B673	<input type="checkbox"/> B656	<input type="checkbox"/> B603	<input type="checkbox"/> B622	<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> Pink
			<input type="checkbox"/> AF637	<input type="checkbox"/> B683	<input type="checkbox"/> B657	<input type="checkbox"/> B615	<input type="checkbox"/> B681	<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> Brown
			<input type="checkbox"/> AF631	<input type="checkbox"/> B601	<input type="checkbox"/> B637	<input type="checkbox"/> B633	<input type="checkbox"/> B687	<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> Navy Blue
			<input type="checkbox"/> AF639	<input type="checkbox"/> B601L	<input type="checkbox"/> B643	<input type="checkbox"/> B649	<input type="checkbox"/> B682		<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> Orange
			<input type="checkbox"/> B607	<input type="checkbox"/> B605	<input type="checkbox"/> B658	<input type="checkbox"/> AF633	<input type="checkbox"/> B693		<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> Blue
			<input type="checkbox"/> B617	<input type="checkbox"/> B605L	<input type="checkbox"/> B659	<input type="checkbox"/> B225	<input type="checkbox"/> B688		<input type="checkbox"/> SHZ		<input type="checkbox"/> White
			<input type="checkbox"/> B602	<input type="checkbox"/> B606	<input type="checkbox"/> B675	<input type="checkbox"/> B653	<input type="checkbox"/> B685				<input type="checkbox"/> Red
			<input type="checkbox"/> B609	<input type="checkbox"/> B606L	<input type="checkbox"/> B676	<input type="checkbox"/> B651	<input type="checkbox"/> B696				
			<input type="checkbox"/> B619	<input type="checkbox"/> B635	<input type="checkbox"/> B612	<input type="checkbox"/> B611	<input type="checkbox"/> B689				
			<input type="checkbox"/> B646	<input type="checkbox"/> B636	<input type="checkbox"/> B645	<input type="checkbox"/> B647	<input type="checkbox"/> B680				

### Specifications:

B26RIC - - - - -  
AIR-SHUT OPTION TRIM TYPE BAFFLE REFLECTOR TRIM/RING GLASS

Sample of Catalog Number: B26RIC-AT-W-B630-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:

**elite** LIGHTING

### DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

### SPECIFICATION


**A. HOUSING** - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

**B. SOCKET** - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

**C. INSTALLATION** - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

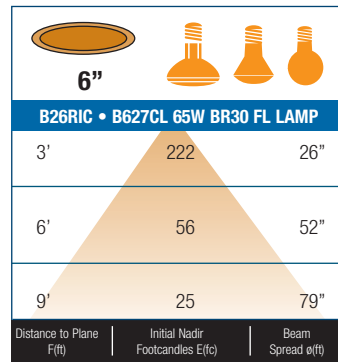

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

### FEATURES

- Thermally Protected Shallow Remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5-1/2" height allows use in 2" x 6" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

#### UL AND C-UL LISTED

- For Damp location
- For Feed-through wiring
- For Direct contact with insulation

# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B630CP-CP**  
METAL STEPPED BAFFLE R30/PAR30



**BAFFLE FINISH:**  
W, P, SN, CP, BZ


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

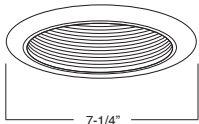


**B620-ORANGE**  
GLASS TRIM



**GLASS FINISH:**  
GREEN, YELLOW,  
PINK, BROWN, NAVY  
BLUE, ORANGE,  
WHITE, RED

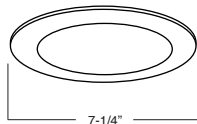


 **B631P-WH**  
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

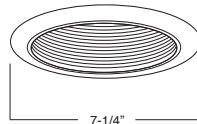

**AF637W-WH**  
SELF FLANGE AIR-SHUT BAFFLE



**AVAILABLE COLOR COMBINATIONS:**  
W-WH, P-WH, P-BK,  
SN-SN, CP-CP, BZ-BZ

**AF631W-WH**  
SELF FLANGE AIR-SHUT BAFFLE



**AVAILABLE COLOR COMBINATIONS:**  
W-WH, P-WH, P-BK,  
SN-SN, CP-CP, BZ-BZ

**AF639W-WH**  
SELF FLANGE AIR-SHUT BAFFLE



**AVAILABLE COLOR COMBINATIONS:**  
W-WH

**MATT WHITE FINISH**

**B607CP-WH**  
REFLECTOR R/PAR30



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN,  
BZ, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ




**B617CL-WH**  
SHALLOW CONE REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN,  
BZ, SHZ


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

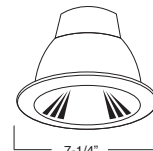

**B602SN**  
EYEBALL



**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

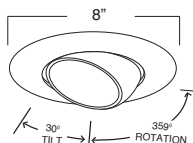


**B609W-WH**  
REGRESSED EYEBALL WITH BAFFLE



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

**EYEBALL FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

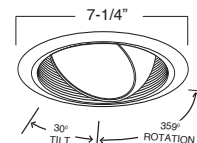


**B619RG-PB**  
REGRESSED EYEBALL WITH REFLECTOR




**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN,  
BZ, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

**EYEBALL FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

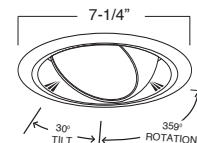


**B646P-WH**  
EYEBALL WITH BAFFLE

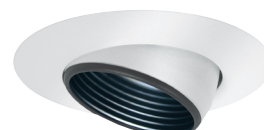

**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH

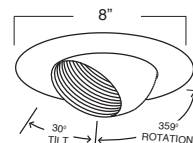


**B616W-WH**  
PAR20 REGRESSED EYEBALL W/ BAFFLE




**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ


**EYEBALL FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

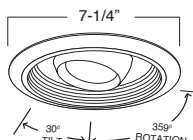


**B663PB**  
PAR30 GIMBAL RING

 

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

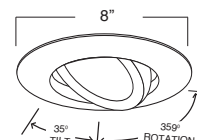


 **B673P-WH**  
PAR30 BAFFLE W/ GIMBAL RING




**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

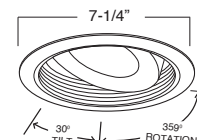


 **B683CL-WH**  
PAR30 REFLECTOR W/ GIMBAL RING



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

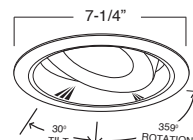

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B601CP**  
METAL ALBALITE LENS



LENS:  
ALBALITE

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

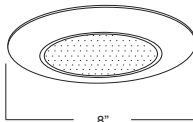


**B601L**  
PLASTIC ALBALITE LENS



LENS:  
ALBALITE

TRIM/RING FINISH:  
WHITE PLASTIC

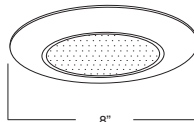


**B605PB**  
METAL FRESNEL LENS



LENS:  
FRESNEL

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

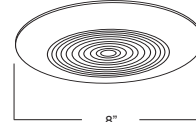


**B605L**  
PLASTIC FRESNEL LENS



LENS:  
FRESNEL

TRIM/RING FINISH:  
WHITE PLASTIC

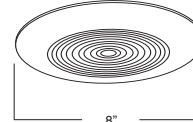


**B606CP**  
METAL DROP OPAL LENS



LENS:  
DROP OPAL

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

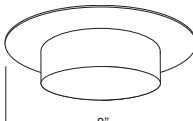


**B606L**  
PLASTIC DROP OPAL LENS




LENS:  
DROP OPAL

TRIM/RING FINISH:  
WHITE PLASTIC

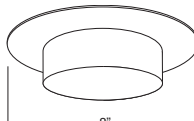


**B635P-WH**  
BAFFLE W/ ALBALITE LENS

 

BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

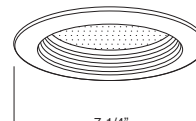


**B636W-WH**  
BAFFLE W/ FRESNEL LENS



BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

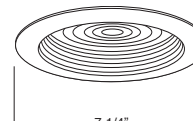


**B642CL-WH**  
REFLECTOR W/ FRESNEL LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

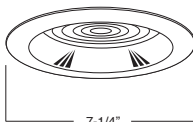


**B641RG-WH**  
REFLECTOR W/ ALBALITE LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

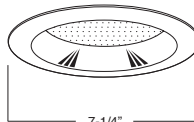


**B656W-WH**  
BAFFLE W/ FROSTED DOME SHOWER LENS




BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

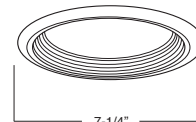

 **B657CL-WH**  
REFLECTOR W/ FROSTED DOME SHOWER LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ




**B637W-WH**  
BAFFLE W/ DROP OPAL LENS



BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

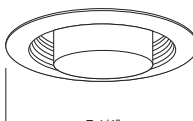


**B643RG-WH**  
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

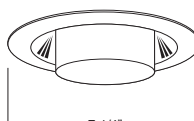


**B658CL-WH**  
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

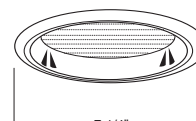


**B659CL-WH**  
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

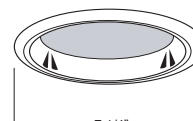

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B675W-WH**  
BAFFLE W/ PRISMATIC LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

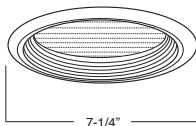


**B676W-WH**  
BAFFLE W/ FROSTED LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

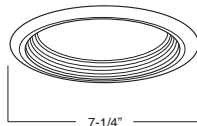


**B612WH**  
SMOOTH FROST DOME SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

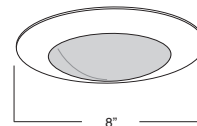


**B645WH**  
DESIGNER POINT SHOWER LENS



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

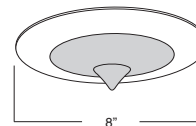


**B648WH**  
DESIGNER CONE SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

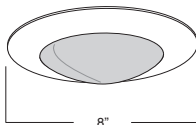


**B652WH**  
SMOOTH FROST SHOWER LENS




**LENS:**  
FROSTED


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

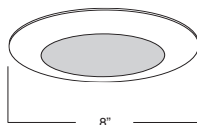

**B603CP**  
R/PAR30 OPEN TRIM

 


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

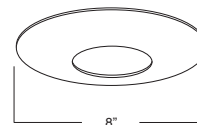

**B615WH**  
DESIGNER PINHOLE




**TRIM/RING FINISH:**  
WH, BK

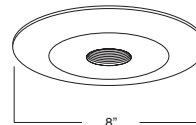

**B633WH**  
R/PAR30 SPLAY TRIM



**TRIM/RING FINISH:**  
WH, BK

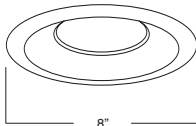


**B649RG-WH**  
PAR20 REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB,  
CP, SN


**TRIM/RING FINISH:**  
WH, BK

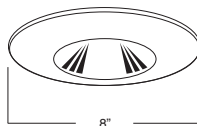

**AF633CH**  
R/PAR30 OPEN TRIM



**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

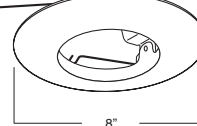


**B225WH**  
OPEN TRIM STEPPED BAFFLE




**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH

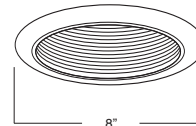


**B653W-WH**  
BAFFLE WITH BAFFLE

 


**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH, BK, SN, CP,  
CH, PB

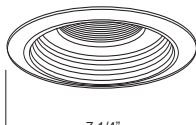


**B651P-WH**  
PAR20 STEPPED BAFFLE

 

**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK

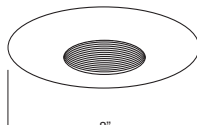


**B611W-WH**  
PAR30 BAFFLE WALL WASH



**AVAILABLE COLOR COMBINATIONS:**  
W-WH, P-WH, SN-SN,  
CP-CP, BZ-BZ

**COVER FINISH:**  
WH, BK

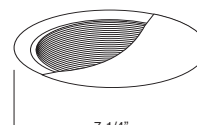


**B647P-WH**  
DESIGNER BAFFLE WALL WASH PAR20



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH

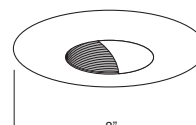

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011



# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B644RG-WH**  
DESIGNER REFLECTOR WALL WASH PAR20



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN


**TRIM/RING FINISH:**  
WH

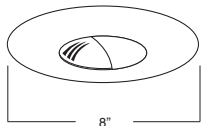

**B650WH**  
DESIGNER WALL WASH



**TRIM/RING FINISH:**  
WH

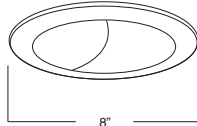


**B622RG-WH**  
R/PAR30 WALL WASH REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**COVER FINISH:**  
WH

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

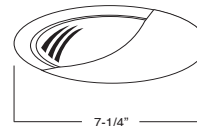


**B681CP-WH**  
SQUARE BAFFLE TRIM



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP

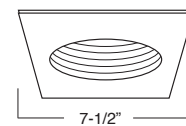


**B687CP-WH**  
SQUARE REFLECTOR TRIM



**REFLECTOR FINISH:**  
CL, RG, W, MB,  
SN, CP


**TRIM/RING FINISH:**  
WH, BK, SN, CP

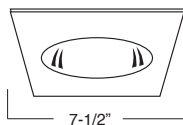

**B682WH**  
SQUARE EYEBALL TRIM




**TRIM/RING FINISH:**  
WH

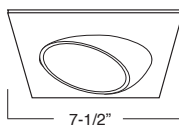

**B693WH**  
SQUARE PAR30 GIMBAL TRIM



**TRIM/RING FINISH:**  
WH

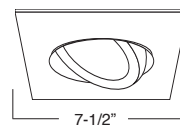


**B688WH**  
SQUARE ALBALITE SHOWER TRIM



**LENS:**  
WHITE

**TRIM/RING FINISH:**  
WH

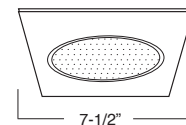


**B685WH**  
SQUARE FRESNEL SHOWER TRIM



**LENS:**  
CLEAR

**TRIM/RING FINISH:**  
WH

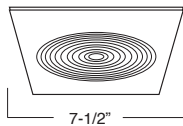


**B696WH**  
SQUARE DROP OIPAL SHOWER TRIM



**LENS:**  
WHITE

**TRIM/RING FINISH:**  
WH

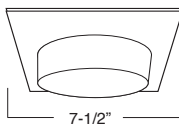


**B689WH**  
SQUARE DESIGNER CONE SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH

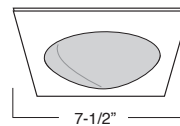


**B680WH**  
SQUARE DESIGNER POINT LENS



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH

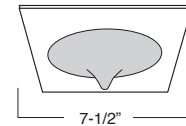

BAFFLE	REFLECTOR	TRIM RING
<b>W</b> White	<b>CL</b> Chrome	<b>WH</b> White
<b>P</b> Black	<b>RG</b> Gold	<b>BK</b> Black
<b>SN</b> Satin Nickel	<b>W</b> White	<b>SN</b> Satin Nickel
<b>CP</b> Copper	<b>MB</b> Black	<b>CP</b> Copper
<b>BZ</b> Bronze	<b>CP</b> Copper	<b>CH</b> Chrome
	<b>SN</b> Satin Nickel	<b>PB</b> Polish Brass
		<b>BZ</b> Bronze

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.


# B26RIC

## 6" Shallow IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

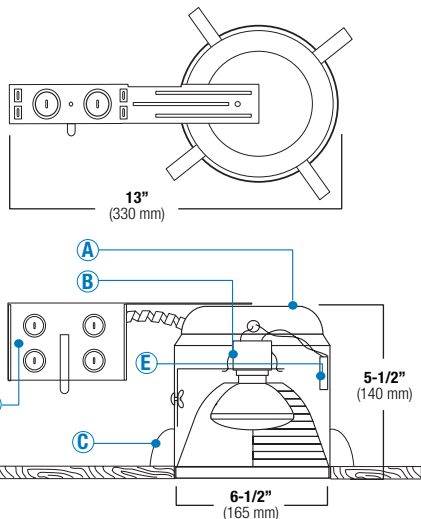

**SAME DAY**  
SHIPPING

PROUDLY  
ASSEMBLED in  
AMERICA

**UL**  
LISTED

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE					BAFFLE	REFLECTOR	TRIM/RING	GLASS
B26RIC	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630	<input type="checkbox"/> B616	<input type="checkbox"/> B642	<input type="checkbox"/> B648	<input type="checkbox"/> B644	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> Green
			<input type="checkbox"/> B620	<input type="checkbox"/> B663	<input type="checkbox"/> B641	<input type="checkbox"/> B652	<input type="checkbox"/> B650	<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> Yellow
			<input type="checkbox"/> B631	<input type="checkbox"/> B673	<input type="checkbox"/> B656	<input type="checkbox"/> B603	<input type="checkbox"/> B622	<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> Pink
			<input type="checkbox"/> AF637	<input type="checkbox"/> B683	<input type="checkbox"/> B657	<input type="checkbox"/> B615	<input type="checkbox"/> B681	<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> Brown
			<input type="checkbox"/> AF631	<input type="checkbox"/> B601	<input type="checkbox"/> B637	<input type="checkbox"/> B633	<input type="checkbox"/> B687	<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> Navy Blue
			<input type="checkbox"/> AF639	<input type="checkbox"/> B601L	<input type="checkbox"/> B643	<input type="checkbox"/> B649	<input type="checkbox"/> B682		<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> Orange
			<input type="checkbox"/> B607	<input type="checkbox"/> B605	<input type="checkbox"/> B658	<input type="checkbox"/> AF633	<input type="checkbox"/> B693		<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> Blue
			<input type="checkbox"/> B617	<input type="checkbox"/> B605L	<input type="checkbox"/> B659	<input type="checkbox"/> B225	<input type="checkbox"/> B688		<input type="checkbox"/> SHZ		<input type="checkbox"/> White
			<input type="checkbox"/> B602	<input type="checkbox"/> B606	<input type="checkbox"/> B675	<input type="checkbox"/> B653	<input type="checkbox"/> B685				<input type="checkbox"/> Red
			<input type="checkbox"/> B609	<input type="checkbox"/> B606L	<input type="checkbox"/> B676	<input type="checkbox"/> B651	<input type="checkbox"/> B696				
			<input type="checkbox"/> B619	<input type="checkbox"/> B635	<input type="checkbox"/> B612	<input type="checkbox"/> B611	<input type="checkbox"/> B689				
			<input type="checkbox"/> B646	<input type="checkbox"/> B636	<input type="checkbox"/> B645	<input type="checkbox"/> B647	<input type="checkbox"/> B680				

### Specifications:

B26RIC - - - - -  
AIR-SHUT OPTION TRIM TYPE BAFFLE REFLECTOR TRIM/RING GLASS

Sample of Catalog Number: B26RIC-AT-W-B630-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:

**elite** LIGHTING

### DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

### SPECIFICATION


**A. HOUSING** - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

**B. SOCKET** - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

**C. INSTALLATION** - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

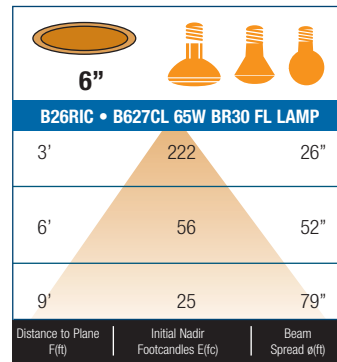

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

### FEATURES

- Thermally Protected Shallow Remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5-1/2" height allows use in 2" x 6" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

#### UL AND C-UL LISTED

- For Damp location
- For Feed-through wiring
- For Direct contact with insulation

# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B630CP-CP**  
METAL STEPPED BAFFLE R30/PAR30



**BAFFLE FINISH:**  
W, P, SN, CP, BZ


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

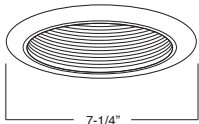


**B620-ORANGE**  
GLASS TRIM



**GLASS FINISH:**  
GREEN, YELLOW,  
PINK, BROWN, NAVY  
BLUE, ORANGE,  
WHITE, RED

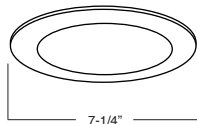


 **B631P-WH**  
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

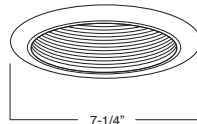

**AF637W-WH**  
SELF FLANGE AIR-SHUT BAFFLE



**AVAILABLE COLOR COMBINATIONS:**  
W-WH, P-WH, P-BK,  
SN-SN, CP-CP, BZ-BZ

**AF631W-WH**  
SELF FLANGE AIR-SHUT BAFFLE



**AVAILABLE COLOR COMBINATIONS:**  
W-WH, P-WH, P-BK,  
SN-SN, CP-CP, BZ-BZ

**AF639W-WH**  
SELF FLANGE AIR-SHUT BAFFLE



**AVAILABLE COLOR COMBINATIONS:**  
W-WH

**MATT WHITE FINISH**

**B607CP-WH**  
REFLECTOR R/PAR30



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN,  
BZ, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ




**B617CL-WH**  
SHALLOW CONE REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN,  
BZ, SHZ


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

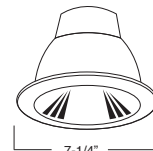

**B602SN**  
EYEBALL



**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

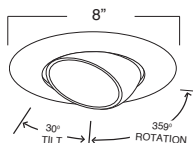


**B609W-WH**  
REGRESSED EYEBALL WITH BAFFLE



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

**EYEBALL FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

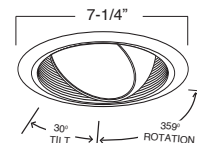


**B619RG-PB**  
REGRESSED EYEBALL WITH REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN,  
BZ, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

**EYEBALL FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

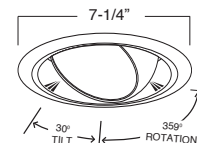


**B646P-WH**  
EYEBALL WITH BAFFLE



**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH

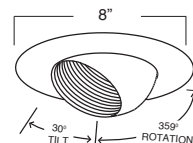


**B616W-WH**  
PAR20 REGRESSED EYEBALL W/ BAFFLE




**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ


**EYEBALL FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

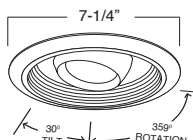


**B663PB**  
PAR30 GIMBAL RING

 

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

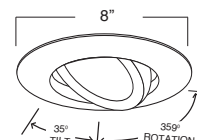


 **B673P-WH**  
PAR30 BAFFLE W/ GIMBAL RING




**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

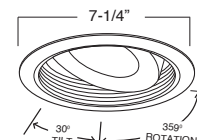


 **B683CL-WH**  
PAR30 REFLECTOR W/ GIMBAL RING



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP, SN

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

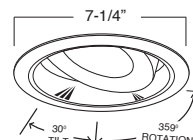

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B601CP**  
METAL ALBALITE LENS



LENS:  
ALBALITE

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

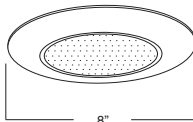


8"

**B601L**  
PLASTIC ALBALITE LENS



LENS:  
ALBALITE

TRIM/RING FINISH:  
WHITE PLASTIC

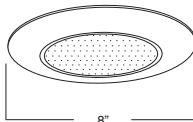


8"

**B605PB**  
METAL FRESNEL LENS



LENS:  
FRESNEL

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

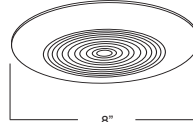


8"

**B605L**  
PLASTIC FRESNEL LENS



LENS:  
FRESNEL

TRIM/RING FINISH:  
WHITE PLASTIC

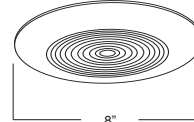


8"

**B606CP**  
METAL DROP OPAL LENS



LENS:  
DROP OPAL

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

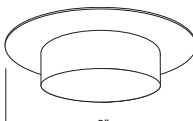


8"

**B606L**  
PLASTIC DROP OPAL LENS




LENS:  
DROP OPAL

TRIM/RING FINISH:  
WHITE PLASTIC

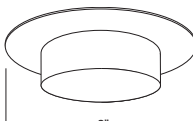


8"

**B635P-WH**  
BAFFLE W/ ALBALITE LENS

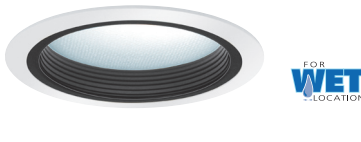

BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

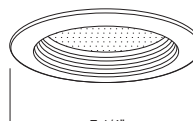


7-1/4"

**B636W-WH**  
BAFFLE W/ FRESNEL LENS



BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

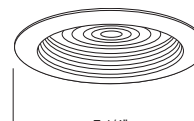


7-1/4"

**B642CL-WH**  
REFLECTOR W/ FRESNEL LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

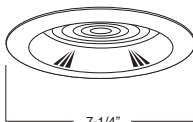


7-1/4"

**B641RG-WH**  
REFLECTOR W/ ALBALITE LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

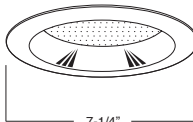


7-1/4"

**B656W-WH**  
BAFFLE W/ FROSTED DOME SHOWER LENS



BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

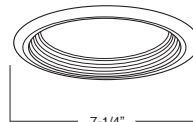

7-1/4"

**B657CL-WH**  
REFLECTOR W/ FROSTED DOME SHOWER LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ




7-1/4"

**B637W-WH**  
BAFFLE W/ DROP OPAL LENS



BAFFLE FINISH:  
W, P, SN, CP, BZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

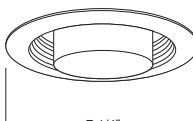


7-1/4"

**B643RG-WH**  
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

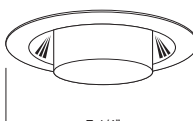


7-1/4"

**B658CL-WH**  
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

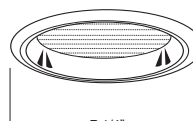


7-1/4"

**B659CL-WH**  
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:  
CL, RG, W, MB, CP,  
SN, SHZ

TRIM/RING FINISH:  
WH, BK, SN, CP, CH,  
PB, BZ

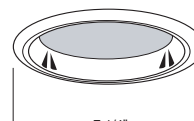

7-1/4"

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011



# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B675W-WH**  
BAFFLE W/ PRISMATIC LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

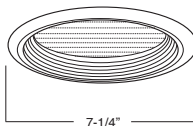


7-1/4"

**B676W-WH**  
BAFFLE W/ FROSTED LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

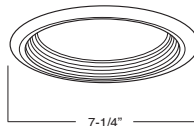


7-1/4"

**B612WH**  
SMOOTH FROST DOME SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

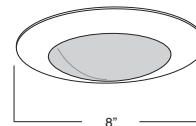


8"

**B645WH**  
DESIGNER POINT SHOWER LENS



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

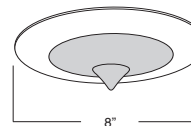


8"

**B648WH**  
DESIGNER CONE SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

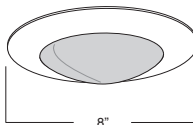


8"

**B652WH**  
SMOOTH FROST SHOWER LENS




**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

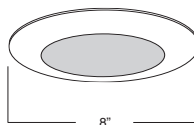


8"

 **B603CP**  
R/PAR30 OPEN TRIM



**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

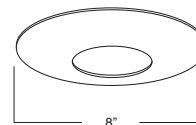


8"

**B615WH**  
DESIGNER PINHOLE



**TRIM/RING FINISH:**  
WH, BK

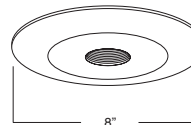


8"

**B633WH**  
R/PAR30 SPLAY TRIM



**TRIM/RING FINISH:**  
WH, BK

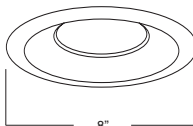


8"

**B649RG-WH**  
PAR20 REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB,  
CP, SN

**TRIM/RING FINISH:**  
WH, BK

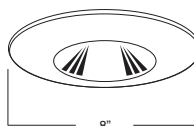


8"

**AF633CH**  
R/PAR30 OPEN TRIM



**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

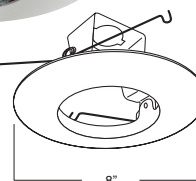


8"

**B225WH**  
OPEN TRIM STEPPED BAFFLE




**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH

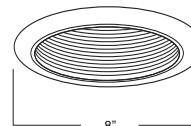


8"

 **B653W-WH**  
BAFFLE WITH BAFFLE




**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH, BK, SN, CP,  
CH, PB

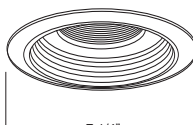


7-1/4"

 **B651P-WH**  
PAR20 STEPPED BAFFLE



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK

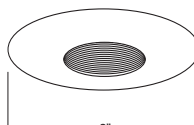


8"

**B611W-WH**  
PAR30 BAFFLE WALL WASH



**AVAILABLE COLOR COMBINATIONS:**  
W-WH, P-WH, SN-SN,  
CP-CP, BZ-BZ

**COVER FINISH:**  
WH, BK

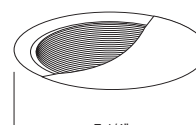


7-1/4"

**B647P-WH**  
DESIGNER BAFFLE WALL WASH PAR20



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH

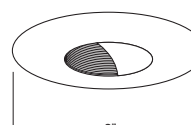

8"

**elite** LIGHTING

Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

# 6" Shallow Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


**elite** LIGHTING

**B644RG-WH**  
DESIGNER REFLECTOR WALL WASH PAR20



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN


**TRIM/RING FINISH:**  
WH

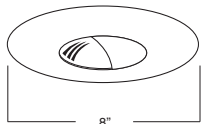

**B650WH**  
DESIGNER WALL WASH



**TRIM/RING FINISH:**  
WH

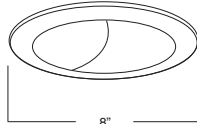


**B622RG-WH**  
R/PAR30 WALL WASH REFLECTOR



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**COVER FINISH:**  
WH

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

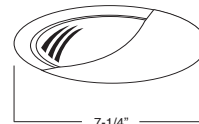


**B681CP-WH**  
SQUARE BAFFLE TRIM



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP

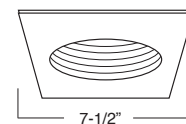


**B687CP-WH**  
SQUARE REFLECTOR TRIM



**REFLECTOR FINISH:**  
CL, RG, W, MB,  
SN, CP


**TRIM/RING FINISH:**  
WH, BK, SN, CP

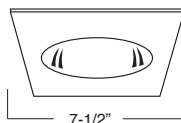

**B682WH**  
SQUARE EYEBALL TRIM




**TRIM/RING FINISH:**  
WH

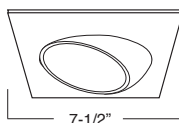

**B693WH**  
SQUARE PAR30 GIMBAL TRIM



**TRIM/RING FINISH:**  
WH

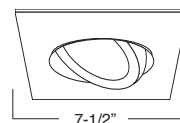


**B688WH**  
SQUARE ALBALITE SHOWER TRIM



**LENS:**  
WHITE

**TRIM/RING FINISH:**  
WH

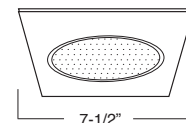


**B685WH**  
SQUARE FRESNEL SHOWER TRIM



**LENS:**  
CLEAR

**TRIM/RING FINISH:**  
WH

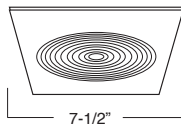


**B696WH**  
SQUARE DROP OIPAL SHOWER TRIM



**LENS:**  
WHITE

**TRIM/RING FINISH:**  
WH

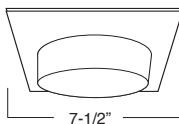


**B689WH**  
SQUARE DESIGNER CONE SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH

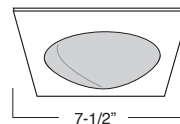


**B680WH**  
SQUARE DESIGNER POINT LENS



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH

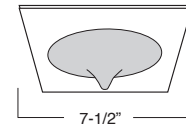

BAFFLE	REFLECTOR	TRIM RING
<b>W</b> White	<b>CL</b> Chrome	<b>WH</b> White
<b>P</b> Black	<b>RG</b> Gold	<b>BK</b> Black
<b>SN</b> Satin Nickel	<b>W</b> White	<b>SN</b> Satin Nickel
<b>CP</b> Copper	<b>MB</b> Black	<b>CP</b> Copper
<b>BZ</b> Bronze	<b>CP</b> Copper	<b>CH</b> Chrome
	<b>SN</b> Satin Nickel	<b>PB</b> Polish Brass
		<b>BZ</b> Bronze

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.