



Label and Ribbon Guide

Quick access to all the materials you need for BradyPrinter S3100, BBP[®]30, BBP[®]31, BBP[®]33, BBP[®]35 and BBP[®]37 Printers



Innovative B30/B33 materials lead the way in labeling with:




Ease of use

- Removes guesswork and prevents incorrect installation
- Changeovers in under 20 seconds save you time
- No complicated threading or wrapping around printheads or spindles



Print smart technology

- Printer reads smart chip on loaded label rolls and ribbons
- Automatically populates label size, label color and pre-printed headers
- No need to manually enter dimensions or scroll through endless screens to find your size
- Smart chip sets the appropriate print settings for optimal print quality

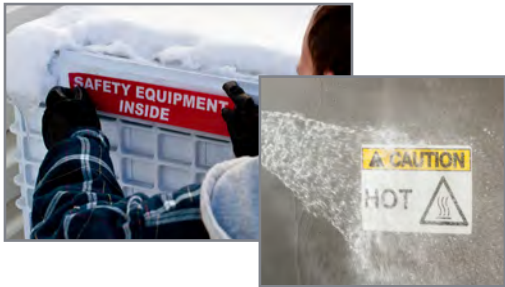

Labels that last

- In-house design and rigorous testing mean reliable and durable labels
- Nothing leaves our doors without meeting our high standards
- Designed for harsh conditions and a variety of surfaces, some labels last up to 10 years outdoors.



Application Versatility

- Hundreds of parts and dozens of label materials offer a wide range of options
- Each label is designed with your application and environment in mind for optimal performance

Reliable printers for every application

Brady's B30 and B33 label and ribbon materials are made for use in many printers. Learn more about each printer below, and visit the website for additional information.



BradyID.com/BBP30

BBP®30 Label Printer

Introductory, dependable partner in printing

When you need label making simplicity in a small footprint at the right price, the BBP30 label printer is the printer of choice.

- Simple printer for reliable labeling
- Smallest footprint
- PC-connect only



BradyID.com/S3100

BradyPrinter S3100 and BBP®31 Label Printers

Walk up, create and print

For the easiest sign and label printer available, try the BradyPrinter S3100. Ideal for multi-user areas in your facility, anyone can simply walk up, create labels right on the spot and print.

- Standalone printer with walk-up-and-print ease of use
- Intuitive and quick label creation
- Entry-level, mono-color printing (1 print color on a label)
- Hundreds of application options



BradyID.com/BBP33

BBP®33 Label Printer

Do-it-all facility identification

Whether you need hundreds of wire and cable markers, small but durable circuit board labels, or a range of safety signs and facility identification labels, this printer does it all.

- Application versatility for safety, facility, wire and product identification
- Widest variety of high-performance labels
- PC-connect only



BradyID.com/BBP37

BBP®35 and BBP®37 Multi-Color Sign and Label Printers

Color your way to an improved workplace

Brady's BBP®35 and BBP®37 sign and label printers give you the power to make signs and labels in the colors and shapes you need to make an impact.

- Multi-color printing for wider label versatility and impactful visuals
- Shape and letter-cutting capabilities (with the BBP37 printer only)
- Fastest, 5 in./sec print speed

Easily find the materials you need

This easy-to-use material guide is designed to help you find the materials for your B30 series printer that best suit applications throughout your facility. Whether you need tags, GHS labels or washdown resistant labels, you'll find a material to meet your needs.



Indoor/Outdoor Vinyl (B-595)

- For general facility and safety identification: Our best industrial vinyl yet!
- Durable, low-shrink vinyl with our most aggressive adhesive
- Conforms to irregular, curved, rough and highly textured surfaces (painted cinder blocks, uneven wood, textured plastics, paper-jacketed pipes, powder-coated surfaces)
- Adheres to “difficult” low-surface energy items (PVC piping, blow-molded equipment cases, ABS plastics, recycled plastics)

Service temp: -40°F to 180°F
 Application temp: 0°F to 180°F
 Average outdoor durability: 8–10 years
 Agency approvals: **RoHS**

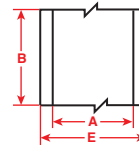


Figure 3



Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 3		B30C-500-595-WT	B-595	White	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-595-WT	B-595	White	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-595-WT	B-595	White	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-3000-595-WT	B-595	White	3.000 (76.2)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-595-WT	B-595	White	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-595-YL	B-595	Yellow	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-595-YL	B-595	Yellow	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-595-YL	B-595	Yellow	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-3000-595-YL	B-595	Yellow	3.000 (76.2)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-595-YL	B-595	Yellow	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-595-RD	B-595	Red	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-595-RD	B-595	Red	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-595-RD	B-595	Red	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-595-RD	B-595	Red	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-595-BL	B-595	Blue	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-595-BL	B-595	Blue	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-595-BL	B-595	Blue	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-595-BL	B-595	Blue	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-595-GN	B-595	Green	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-595-GN	B-595	Green	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-595-GN	B-595	Green	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-595-GN	B-595	Green	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-595-OR	B-595	Orange	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-595-OR	B-595	Orange	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-595-OR	B-595	Orange	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-595-OR	B-595	Orange	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-595-BK	B-595	Black	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-595-BK	B-595	Black	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-595-BK	B-595	Black	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-595-BK	B-595	Black	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-595-BR	B-595	Brown	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-595-BR	B-595	Brown	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-595-BR	B-595	Brown	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-595-BR	B-595	Brown	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-595-GD	B-595	Gold	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-595-GD	B-595	Gold	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-595-GD	B-595	Gold	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-595-GD	B-595	Gold	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-595-GY	B-595	Gray	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-595-GY	B-595	Gray	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-595-GY	B-595	Gray	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-595-GY	B-595	Gray	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-595-PL	B-595	Purple	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-595-PL	B-595	Purple	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-595-PL	B-595	Purple	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-595-PL	B-595	Purple	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-595-CL	B-595	Clear	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-595-CL	B-595	Clear	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-595-CL	B-595	Clear	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-595-CL	B-595	Clear	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000

U.S. Patent Nos. 5,823,689; 6,570,602. Additional Patents Pending.

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Low-Halide Polyester (B-569)

- Low-halide for labeling stainless steel pipes and surfaces
- Applies best to very smooth surfaces and ideal for mounting to rigid panels

Service temp: -40°F to 212°F Application temp: 0°F to 212°F
Average outdoor durability: 3-5 years

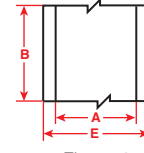


Figure 3



Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 3		B30C-500-569-WT	B-569	White	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-WT	B-569	White	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-WT	B-569	White	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-3000-569-WT	B-569	White	3.000 (76.2)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-WT	B-569	White	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-YL	B-569	Yellow	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-YL	B-569	Yellow	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-YL	B-569	Yellow	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-YL	B-569	Yellow	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-RD	B-569	Red	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-569-RD	B-569	Red	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-569-RD	B-569	Red	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-569-RD	B-569	Red	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-569-BL	B-569	Blue	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-569-BL	B-569	Blue	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-569-BL	B-569	Blue	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-569-BL	B-569	Blue	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-569-LB	B-569	Light Blue	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-LB	B-569	Light Blue	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-LB	B-569	Light Blue	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-LB	B-569	Light Blue	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-SB	B-569	Sky Blue	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-SB	B-569	Sky Blue	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-SB	B-569	Sky Blue	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-SB	B-569	Sky Blue	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-GN	B-569	Green	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-569-GN	B-569	Green	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-569-GN	B-569	Green	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-569-GN	B-569	Green	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-569-OR	B-569	Orange	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-OR	B-569	Orange	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-OR	B-569	Orange	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-OR	B-569	Orange	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-BK	B-569	Black	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-569-BK	B-569	Black	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-569-BK	B-569	Black	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-569-BK	B-569	Black	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-569-BR	B-569	Brown	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-569-BR	B-569	Brown	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-569-BR	B-569	Brown	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-569-BR	B-569	Brown	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-569-OC	B-569	Ochre	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-OC	B-569	Ochre	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-OC	B-569	Ochre	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-OC	B-569	Ochre	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-TN	B-569	Tan	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-TN	B-569	Tan	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-TN	B-569	Tan	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-TN	B-569	Tan	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-GY	B-569	Gray	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-GY	B-569	Gray	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-GY	B-569	Gray	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-GY	B-569	Gray	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-PL	B-569	Purple	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-1125-569-PL	B-569	Purple	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-2250-569-PL	B-569	Purple	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3	✂	B30C-4000-569-PL	B-569	Purple	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000-WT
Fig. 3		B30C-500-569-PK	B-569	Pink	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-PK	B-569	Pink	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-PK	B-569	Pink	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-PK	B-569	Pink	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-569-CL	B-569	Clear	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-569-CL	B-569	Clear	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-569-CL	B-569	Clear	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-569-CL	B-569	Clear	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000


All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Pre-Printed GHS /CLP Chemical Labels (B-7569)

- Blank labels with pre-printed red diamonds allow the printer to produce 2-color GHS / CLP labels in one print pass
- 4 sizes of labels with 7 diamond layouts that match templates in the printer app or in the Brady Workstation GHS App
- Indoor/outdoor vinyl and polyester material and durable inks withstand exposure to moisture, chemicals and handling

Service temp: -4°F to 180°F
 Application temp: 50°F to 180°F
 Average outdoor durability: 3-5 years

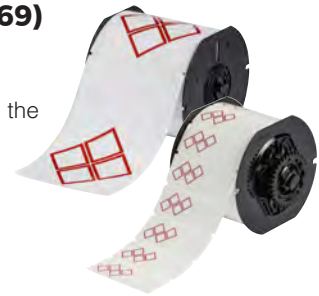

Catalog #	B#	Material	Legend	Label Height Inch (mm)	Label Width Inch (mm)	Labels Per Roll	Rec. Ribbon
B30-260-7569-CLP1	B-7569	Vinyl		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-261-7569-CLP1	B-7569	Vinyl		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-262-7569-CLP1	B-7569	Vinyl		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-260-7569-CLP2	B-7569	Vinyl		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-261-7569-CLP2	B-7569	Vinyl		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-262-7569-CLP2	B-7569	Vinyl		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-260-7569-CLP3A	B-7569	Vinyl		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-261-7569-CLP3A	B-7569	Vinyl		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-262-7569-CLP3A	B-7569	Vinyl		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-260-7569-CLP3B	B-7569	Vinyl		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-261-7569-CLP3B	B-7569	Vinyl		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-262-7569-CLP3B	B-7569	Vinyl		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-260-7569-CLP4A	B-7569	Vinyl		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-261-7569-CLP4A	B-7569	Vinyl		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-262-7569-CLP4A	B-7569	Vinyl		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-260-7569-CLP4B	B-7569	Vinyl		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-260-569-CLP4B	B-569	Polyester		2.170 (55.0)	3.350 (85.0)	340	B30-R10000
B30-261-7569-CLP4B	B-7569	Vinyl		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-261-569-CLP4B	B-569	Polyester		2.950 (75.0)	4.330 (110.0)	270	B30-R10000
B30-262-7569-CLP4B	B-7569	Vinyl		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-262-569-CLP4B	B-569	Polyester		4.130 (105.0)	6.100 (155.0)	200	B30-R10000
B30-18-7569-CLP4C	B-7569	Vinyl		1.000 (25.4)	3.000 (76.2)	1000	B30-R10000

▶ Brady WorkStation GHS Label App

- Built-in pre-formatted label layouts and approved GHS symbols
- Pre-worded hazard statements and GHS symbols that just click and drag into the layout (no need to type everything in)
- Once you create a label, the data is there and you can print any size
- Automatic "block-out" of unused diamonds on pre-printed supplies so you can inventory fewer label rolls
- Database of the most commonly used chemicals



Visit Workstation.BradyID.com for a free 30-day trial



Pre-Printed Pre-Cut Blank Sign Headers (B-595)

- Allows printer to create multicolor signs fast — in a single print pass
 - 6 headers and 2 blank label options meet NFPA 70E, OSHA 1910.145 and ASME/ANSI Z535 standards
 - Indoor/outdoor grade material conforms to rough, highly textured and difficult-to-adhere-to surfaces
- Service temp: -40°F to 180°F Application temp: 0°F to 180°F
Average outdoor durability: 8–10 years
Agency approvals: **RoHS**

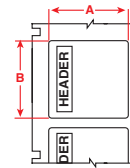


Figure 70



Diagram	Catalog #	B#	Material	Header	Label Height A Inch (mm)	Label Width B Inch (mm)	Labels Per Roll	Rec. Ribbon
Fig. 70	B30-241-595-OSHADA	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-OSHADA	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-241-595-OSHACA	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-OSHACA	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-241-595-ANSICA	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-ANSICA	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-241-595-ANSIDA	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-ANSIDA	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-241-595-ANSIWA	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-ANSIWA	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-241-595-ANSINO	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-ANSINO	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-25-595-PREC	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-25-595-PEL	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-242-595-BLNKWT	B-595	Vinyl		1.125 (28.6) *	2.750 (69.8)	300	B30-R10000
Fig. 70	B30-241-595-BLNKWT	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-219-595-BLNKWT	B-595	Vinyl		2.250 (57.5) *	3.750 (95.3)	250	B30-R10000
Fig. 70	B30-25-595-BLNKWT	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000
Fig. 70	B30-241-595-BLNKYL	B-595	Vinyl		2.250 (57.5)	3.000 (76.2)	300	B30-R10000
Fig. 70	B30-25-595-BLNKYL	B-595	Vinyl		4.000 (101.6)	6.000 (152.4)	175	B30-R10000

*Label pre-sized to fit blank rigid valve tags, but can also be used on its own as general purpose label.



Non-Adhesive Tags (B-551)

- Non-adhesive, semi-rigid tags in pre-cut and continuous styles
- Pre-cut with hole and chamfered corners
- Micro-perforated between tags to separate cleanly

Service temp: -40°F to 193°F
Average outdoor durability: up to 2 years

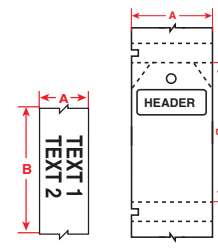


Figure 33b

Figure 69



Diagram	Catalog #	B#	Header	Tag Width A Inch (mm)	Tag Height B Inch (mm)	Tags Per Roll	Rec. Ribbon
Fig. 69	B30-255-551-ANSIDA	B-551		3.250 (82.6)	5.750 (146.1)	100	B30-R10000
Fig. 69	B30-255-551-OSHADA	B-551		3.250 (82.6)	5.750 (146.1)	100	B30-R10000
Fig. 69	B30-255-551-ANSICA	B-551		3.250 (82.6)	5.750 (146.1)	100	B30-R10000
Fig. 69	B30-255-551-WHT	B-551		3.250 (82.6)	5.750 (146.1)	100	B30-R10000
Fig. 33b	B30C-2500-551-WT	B-551		2.500 (63.5)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 33b	B30C-3250-551-WT	B-551		3.250 (82.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 33b	B30C-4250-551-WT	B-551		4.250 (107.9)	50ft. (15.2m)	1 roll (cont.)	B30-R10000

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Pre-Printed Right-To-Know Chemical Labels (B-595)

- Produce 5-color chemical labels in a single print pass
- Indoor/outdoor grade material withstands exposure to moisture, chemicals and handling

Service temp: -40°F to 180°F
 Application temp: 0°F to 180°F
 Average outdoor durability: 8-10 years
 Agency approvals: RoHS





	Catalog #	B#	Legend	Label Height Inch (mm)	Label Width Inch (mm)	Labels Per Roll	Rec. Ribbon
S3100, BBP31, 33, 35, 37	B30-244-595-NFPA	B-595		2.250 (57.5)	2.250 (57.5)	365	B30-R10000
S3100, BBP31, 33, 35, 37	B30-245-595-NFPA	B-595		2.250 (57.5)	4.000 (101.6)	240	B30-R10000
S3100, BBP31, 33, 35, 37	B30-263-595-NFPA	B-595		4.000 (101.6)	6.250 (158.8)	170	B30-R10000
S3100, BBP31, 33, 35, 37	B30-244-595-DIAM	B-595		2.250 (57.5)	2.250 (57.5)	365	B30-R10000
S3100, BBP31, 33, 35, 37	B30-161-595-DIAM	B-595		4.000 (101.6)	4.000 (101.6)	240	B30-R10000
S3100, BBP31, 33, 35, 37	B30-246-595-NFR	B-595		1.125 (28.6)	3.000 (76.2)	300	B30-R10000
S3100, BBP31, 33, 35, 37	B30-244-595-CB	B-595		2.250 (57.5)	2.250 (57.5)	365	B30-R10000
S3100, BBP31, 33, 35, 37	B30-245-595-CB	B-595		2.250 (57.5)	4.000 (101.6)	240	B30-R10000
S3100, BBP31, 33, 35, 37	B30-263-595-CB	B-595		4.000 (101.6)	6.250 (158.8)	170	B30-R10000
S3100, BBP31, 33, 35, 37	B30-244-595-HMIG	B-595		2.250 (57.5)	2.250 (57.5)	365	B30-R10000
S3100, BBP31, 33, 35, 37	B30-246-595-HMIG	B-595		1.125 (28.6)	3.000 (76.2)	300	B30-R10000



Paper Labels (B-424)

- Economical matte labels for light duty general ID
- Excellent contrast and smear resistance for barcode printing

Service temp: -40°F to 124°F
 Agency approvals: RoHS

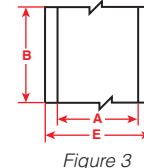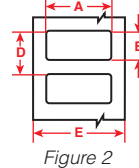

Fits Printer Model(s)	For BBP37 XY-Cutter	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Roll	Rec. Ribbon
BBP33		Fig. 2	B33-53-424	B-424	White	2.000 (50.8)	0.500 (12.7)	2500	B30-R4300
BBP33		Fig. 2	B33-17-424	B-424	White	2.000 (50.8)	1.000 (25.4)	1500	B30-R4300
BBP33		Fig. 2	B33-7-424	B-424	White	2.750 (69.9)	1.250 (31.8)	1000	B30-R4300
BBP33		Fig. 2	B33-18-424	B-424	White	3.000 (76.2)	1.000 (25.4)	1500	B30-R4300
BBP33		Fig. 2	B33-19-424	B-424	White	3.000 (76.2)	2.000 (50.8)	500	B30-R4300
BBP33		Fig. 2	B33-20-424	B-424	White	3.000 (76.2)	5.000 (127)	250	B30-R4300
BBP33		Fig. 2	B33-55-424	B-424	White	4.000 (101.6)	2.000 (50.8)	750	B30-R4300
BBP33		Fig. 2	B33-25-424	B-424	White	4.000 (101.6)	6.000 (152.4)	350	B30-R4300
S3100, BBP35, 37	✂	Fig. 3	B30C-4000-424	B-424	White	4.000 (101.6)	150 ft. (45.7m)	1 roll (cont.)	B30-R4300

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Polypropylene Labels (B-425)

- General labeling material for indoor use
- Outstanding chemical and solvent resistance and print performance
- Not recommended for prolonged outdoor use (use B-595 material for 8-10 year outdoor use)

Service temp: -94°F to 212°F

Agency approvals:

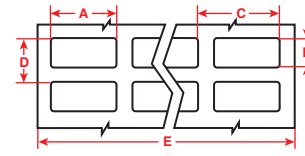


Figure 1

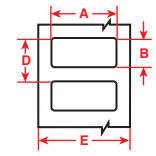


Figure 2

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 1	B33-5-425	B-425	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 2	B33-17-425	B-425	White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 2	B33-18-425	B-425	White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 2	B33-19-425	B-425	White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R4300



Retro Reflective Tape (B-584)

- Highly reflective material shines back brightly when struck by light
- Ideal for labeling outdoor utility pedestals, hard hats, jobsite equipment and roof-top equipment
- Recommended for low light or inclement weather conditions

Service temp: -40°F to 158°F

Application temp: 0°F to 158°F (yellow & orange), 50°F to 158°F (silver)

Average outdoor durability: 4-6 years


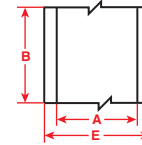


Figure 3



Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 3		B30C-1125-584-SL	B-584	Silver	1.125 (28.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-584-SL	B-584	Silver	2.250 (57.5)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-584-SL	B-584	Silver	4.000 (101.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-584-YL	B-584	Yellow	1.125 (28.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-584-YL	B-584	Yellow	2.250 (57.5)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-584-YL	B-584	Yellow	4.000 (101.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-584-OR	B-584	Orange	1.125 (28.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-584-OR	B-584	Orange	2.250 (57.5)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-584-OR	B-584	Orange	4.000 (101.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000

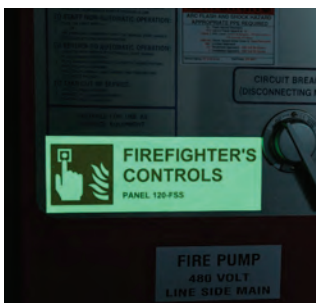

BradyGlo™ High-Intensity Photoluminescent Tape (B-526)

- For glow-in-the-dark identification up to 10 hours
- Designed for directional, evacuation, emergency utility shut-off, fire extinguisher, alarm pull and vital equipment control marking
- Complies with indoor use requirements specified in RS 6-1 and 6-1A of New York Local Law 26

Service temp: -40°F to 140°F

Application temp: 40°F to 140°F

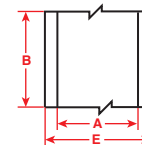


Figure 3





Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 3		B30C-1125-526	B-526	Luminous Green	1.125 (28.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-526	B-526	Luminous Green	2.250 (57.5)	50ft. (15.2m)	1 roll (cont.)	B30-R10000
Fig. 3	✂	B30C-4000-526	B-526	Luminous Green	4.000 (101.6)	50ft. (15.2m)	1 roll (cont.)	B30-R10000

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



ToughStripe® Printable Floor Marking Tape (B-483 with overlaminate)

- Revolutionary B-483 material has ultra-aggressive adhesive
- Withstands forklift and pallet jack traffic without tearing or lifting
- Each roll ships with a roll of clear overlaminate which must be applied over printed label and onto appropriate surface for best performance

Service temp: -40°F to 248°F
Agency approvals:  

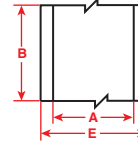


Figure 3



Fits Printer Model(s)	Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
S3100, BBP35, 37	Fig. 3		B30C-1125-483WT-KT	B-483	White	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-2250-483WT-KT	B-483	White	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-3000-483WT-KT	B-483	White	3.000 (76.2)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483WT-KT	B-483	White	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-1125-483YL-KT	B-483	Yellow	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-2250-483YL-KT	B-483	Yellow	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-3000-483YL-KT	B-483	Yellow	3.000 (76.2)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483YL-KT	B-483	Yellow	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-1125-483RD-KT	B-483	Red	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-2250-483RD-KT	B-483	Red	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483RD-KT	B-483	Red	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-1125-483BL-KT	B-483	Blue	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-2250-483BL-KT	B-483	Blue	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483BL-KT	B-483	Blue	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-1125-483GN-KT	B-483	Green	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-2250-483GN-KT	B-483	Green	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483GN-KT	B-483	Green	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-1125-483BK-KT	B-483	Black	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-2250-483BK-KT	B-483	Black	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483BK-KT	B-483	Black	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R4400-WT
S3100, BBP35, 37	Fig. 3		B30C-1125-483OR-KT	B-483	Orange	1.125 (28.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3		B30C-2250-483OR-KT	B-483	Orange	2.250 (57.5)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✂	B30C-4000-483OR-KT	B-483	Orange	4.000 (101.6)	100ft. (30.5m)	1 Roll (cont.)	B30-R6000



Printable Magnetic Supply (B-509)

- Easiest and quickest material for removing and repositioning
- Non-adhesive magnetic material that can be printed on directly

Service temp: 0°F to 158°F

Average outdoor durability: 3–5 years



Figure 33b



Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 33b		B30C-2500-509-WT	B-509	White	2.500 (63.5)	25ft (7.62m)	1 roll (cont.)	B30-R10000
Fig. 33b	✗	B30C-4250-509-WT	B-509	White	4.250 (107.8)	25ft (7.62m)	1 roll (cont.)	B30-R10000
Fig. 33b		B30C-2500-509-YL	B-509	Yellow	2.500 (63.5)	25ft (7.62m)	1 roll (cont.)	B30-R10000
Fig. 33b	✗	B30C-4250-509-YL	B-509	Yellow	4.250 (107.8)	25ft (7.62m)	1 roll (cont.)	B30-R10000



Repositionable Vinyl (B-581)

- Aggressive adhesive stays in place but removes cleanly without leaving adhesive residue
- Ideal for temporary, removable and repositionable labels, such as 5S and lean inventory labels

Service temp: -40°F to 180°F

Application temp: 50°F to 180°F

Average outdoor durability: 5 years

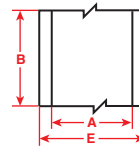


Figure 3



Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 3		B30C-500-581-WT	B-581	White	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-581-WT	B-581	White	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-581-WT	B-581	White	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✗	B30C-4000-581-WT	B-581	White	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-500-581-YL	B-581	Yellow	0.500 (12.7)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-581-YL	B-581	Yellow	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-581-YL	B-581	Yellow	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✗	B30C-4000-581-YL	B-581	Yellow	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000



Cold Temperature Application Material (B-549)

- Special adhesive permanently adheres to extremely cold surfaces
- Ideal for cold storage warehouses, coolers, freezers and short-term winter outdoor use

Service temp: -40°F to 212°F

Application temp: -10°F to 212°F

Average outdoor durability: up to 1 year

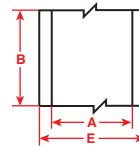


Figure 3



Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
Fig. 3		B30C-1125-549-WT	B-549	White	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-549-WT	B-549	White	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✗	B30C-4000-549-WT	B-549	White	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-1125-549-YL	B-549	Yellow	1.125 (28.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3		B30C-2250-549-YL	B-549	Yellow	2.250 (57.5)	100ft. (30.5m)	1 roll (cont.)	B30-R10000
Fig. 3	✗	B30C-4000-549-YL	B-549	Yellow	4.000 (101.6)	100ft. (30.5m)	1 roll (cont.)	B30-R10000

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



ToughWash® Washdown Resistant Labels (B-854, B-855)

- Withstands high pressure, heat, harsh chemicals and numerous washdown cycles
- Ideal for use in the food and beverage industry
- B-854 offers metal detectable layer to detect foreign debris in food stream

Service temp: -40°F to 230°F
Agency approvals: RoHS

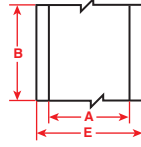


Figure 3

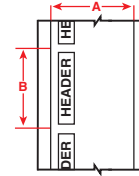


Figure 73



Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Length B Inch (mm)	Labels Per Roll	Rec. Ribbon
B-854 ToughWash™ Metal Detectable Material							
Fig. 3	B30C-4000-854-YL	B-854		4.000 (101.06)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 3	B30C-4000-854-WT	B-854		4.000 (101.06)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 73	B30-25-854-OSHADA	B-854		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-854-ANSIWA	B-854		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-854-ANSIDA	B-854		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-854-ANSICA	B-854		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-854-PEL	B-854		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-854-PREC	B-854		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
B-855 ToughWash™ Material							
Fig. 3	B30C-1125-855-YL	B-855		1.125 (28.6)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 3	B30C-2250-855-YL	B-855		2.250 (57.5)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 3	B30C-4000-855-YL	B-855		4.000 (101.06)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 3	B30C-1125-855-WT	B-855		1.125 (28.6)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 3	B30C-2250-855-WT	B-855		2.250 (57.5)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 3	B30C-4000-855-WT	B-855		4.000 (101.06)	50ft. (15.2 m)	1 roll (cont.)	B30-R6000
Fig. 73	B30-25-855-OSHADA	B-855		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-855-ANSIWA	B-855		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-855-ANSIDA	B-855		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-855-ANSICA	B-855		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-855-PEL	B-855		4.000 (101.06)	6.250 (158.8)	100	B30-R6000
Fig. 73	B30-25-855-PREC	B-855		4.000 (101.06)	6.250 (158.8)	100	B30-R6000

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.






General ID Labels for Lean 5S, Bins and Production Areas (B-483, B-484, B-498, B-499)

- Various sizes in several durable material types
- Also ideal for marking backer board, DIN rail, relays, PLCs, switches, solenoids, drive motors and other components inside panels
- All recommended materials are flexible and have high-tack adhesives for adhesion to wide variety of surfaces and components

B-483: Service temp: -40°F to 248°F
B-484: Service temp: -40°F to 240°F
B-498: Service temp: -40°F to 175°F
B-499: Service temp: -40°F to 193°F

Agency approvals:
 Agency approvals:
 Agency approvals:
 Agency approvals:

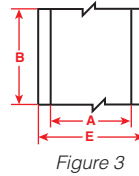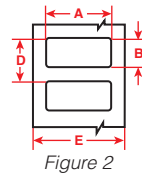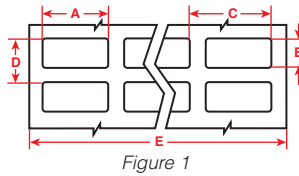

Fits Printer Model(s)	For BBP37 XY-Cutter	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Vinyl Cloth - Aggressive but repositionable adhesive (B-498):										
BBP33		Fig. 1	B33-90-498	B-498	White	0.250 (6.4)	1.437 (36.5)	6	2500	B30-R6200
BBP33		Fig. 1	B33-68-498	B-498	White	0.500 (12.7)	0.750 (19.1)	4	5000	B30-R6200
BBP33		Fig. 1	B33-87-498	B-498	White	0.500 (12.7)	1.437 (36.5)	6	2500	B30-R6200
BBP33		Fig. 1	B33-1-498	B-498	White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R6200
BBP33		Fig. 1	B33-95-498	B-498	White	0.800 (20.3)	1.437 (36.5)	3	2300	B30-R6200
BBP33		Fig. 1	B33-5-498	B-498	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6200
BBP33		Fig. 1	B33-88-498	B-498	White	1.000 (25.4)	0.750 (19.1)	2	2500	B30-R6200
BBP33		Fig. 1	B33-89-498	B-498	White	1.000 (25.4)	1.437 (36.5)	3	2300	B30-R6200
S3100, BBP35, 37		Fig. 3	B30C-4000-498	B-498	White	4.000 (101.6)	80 ft. (24.4)	1 roll (cont.)		B30-R6200
Nylon Cloth - Permanent adhesive (B-499):										
BBP33		Fig. 1	B33-68-499	B-499	White	0.500 (12.7)	0.750 (19.1)	4	1500	B30-R6000
BBP33		Fig. 1	B33-165-499	B-499	White	0.800 (20.3)	1.437 (36.5)	4	2500	B30-R6000
BBP33		Fig. 2	B33-125-499	B-499	White	0.900 (22.9)	0.500 (12.7)	1	1500	B30-R6000
BBP33		Fig. 1	B33-126-499	B-499	White	0.900 (22.9)	0.500 (12.7)	2	1500	B30-R6000
BBP33		Fig. 2	B33-163-499	B-499	White	1.000 (25.4)	0.375 (9.5)	1	1500	B30-R6000
BBP33		Fig. 1	B33-152-499	B-499	White	1.000 (25.4)	0.375 (9.5)	2	1500	B30-R6000
BBP33		Fig. 2	B33-136-499	B-499	White	1.500 (38.1)	0.750 (19.1)	1	1500	B30-R6000
BBP33		Fig. 2	B33-137-499	B-499	White	2.000 (50.8)	1.000 (25.4)	1	1100	B30-R6000
BBP33		Fig. 2	B33-125-499	B-499	White	2.000 (50.8)	0.250 (6.4)	1	1500	B30-R6000
Polyester - Ultra aggressive adhesive for highly textured and low surface energy surfaces (B-483):										
BBP33		Fig. 1	B33-149-483	B-483	White	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33		Fig. 1	B33-5-483	B-483	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33		Fig. 2	B33-17-483	B-483	White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33		Fig. 2	B33-7-483	B-483	White	2.750 (69.9)	1.250 (31.8)	1	1000	B30-R6000
BBP33		Fig. 2	B33-18-483	B-483	White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33		Fig. 2	B33-19-483	B-483	White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
BBP33		Fig. 2	B33-55-483	B-483	White	4.000 (101.6)	2.000 (50.8)	1	750	B30-R6000
Polyester - Ultra aggressive adhesive and pliable for conforming to angular surfaces (B-484):										
BBP33		Fig. 2	B33-125-484	B-484	White	0.900 (22.9)	0.500 (12.7)	1	1500	B30-R6000
BBP33		Fig. 1	B33-5-484	B-484	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33		Fig. 2	B33-136-484	B-484	White	1.500 (38.1)	0.750 (19.1)	1	1500	B30-R6000
BBP33		Fig. 2	B33-17-484	B-484	White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33		Fig. 2	B33-18-484	B-484	White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33		Fig. 2	B33-19-484	B-484	White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
S3100, BBP35, 37		Fig. 3	B30C-4000-484	B-484	White	4.000 (101.6)	150 ft. (45.7m)	1 roll (cont)		B30-R6000

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Self-Laminating Wire & Cable Labels (B-427)

- Features white printable area with clear "tail" that wraps around marker to protect text
- Superior resistance to abrasion, handling, solvents, water, oil and dirt
- Vinyl with permanent acrylic adhesive designed specifically for tightly curved surfaces

Service temp: -40°F to 158°F
Agency approvals:

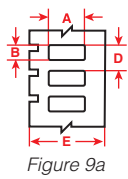


Figure 9a

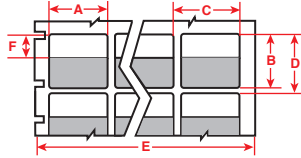


Figure 12

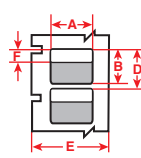


Figure 14

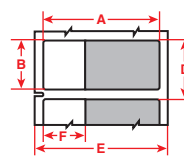


Figure 15

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Print Area Height F Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 12	B33-80-427	B-427	White	0.500 (12.7)	0.750 (19.1)	0.375 (9.5)	4	2500	B30-R4300
BBP33	Fig. 12	B33-113-427	B-427	White	0.500 (12.7)	1.000 (25.4)	0.375 (9.5)	4	2500	B30-R4300
BBP33	Fig. 12	B33-8-427	B-427	White	0.500 (12.7)	1.437 (36.5)	0.500 (12.7)	5	5000	B30-R4300
BBP33	Fig. 12	B33-56-427	B-427	White	0.750 (19.1)	0.937 (23.8)	0.375 (9.5)	4	5000	B30-R4300
BBP33	Fig. 12	B33-73-427	B-427	White	0.750 (19.1)	1.750 (44.6)	0.500 (12.7)	4	3500	B30-R4300
BBP33	Fig. 12	B33-74-427	B-427	White	0.800 (20.3)	1.437 (36.5)	0.500 (12.7)	4	4000	B30-R4300
BBP33	Fig. 12	B33-115-427	B-427	White	1.000 (25.4)	0.750 (19.1)	0.375 (9.5)	2	2500	B30-R4300
BBP33	Fig. 12	B33-116-427	B-427	White	1.000 (25.4)	1.000 (25.4)	0.375 (9.5)	2	2500	B30-R4300
BBP33	Fig. 12	B33-9-427	B-427	White	1.000 (25.4)	1.437 (36.5)	0.500 (12.7)	3	2500	B30-R4300
BBP33	Fig. 12	B33-75-427	B-427	White	1.000 (25.4)	2.250 (57.2)	0.750 (19.1)	2	1400	B30-R4300
BBP33	Fig. 15	B33-131-427	B-427	White	1.000 (25.4)	2.625 (66.7)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 12	B33-10-427	B-427	White	1.000 (25.4)	3.750 (95.3)	1.000 (25.4)	3	1200	B30-R4300
BBP33	Fig. 12	B33-81-427	B-427	White	1.000 (25.4)	6.000 (152.4)	1.500 (38.1)	2	500	B30-R4300
BBP33	Fig. 9a	B33-135-427AW	B-427	White	1.500 (38.1)	0.750 (19.1)	-	1	1500	B30-R4300
BBP33	Fig. 14	B33-118-427	B-427	White	1.500 (38.1)	1.000 (25.4)	0.375 (9.5)	1	1250	B30-R4300
BBP33	Fig. 14	B33-119-427	B-427	White	1.500 (38.1)	1.500 (38.1)	0.500 (12.7)	1	1000	B30-R4300
BBP33	Fig. 14	B33-272-427	B-427	White	1.500 (38.1)	2.250 (57.2)	0.750 (19.1)	1	700	B30-R4300
BBP33	Fig. 14	B33-120-427	B-427	White	1.750 (44.5)	1.000 (25.4)	0.375 (9.5)	1	1250	B30-R4300
BBP33	Fig. 14	B33-121-427	B-427	White	1.750 (44.5)	1.500 (38.1)	0.500 (12.7)	1	1000	B30-R4300
BBP33	Fig. 14	B33-273-427	B-427	White	1.750 (44.5)	2.250 (57.2)	0.750 (19.1)	1	500	B30-R4300
BBP33	Fig. 9a	B33-137-427AW	B-427	White	2.000 (50.8)	1.000 (25.4)	-	1	1500	B30-R4300
BBP33	Fig. 14	B33-27-427	B-427	White	2.000 (50.8)	3.750 (95.3)	1.000 (25.4)	1	400	B30-R4300
BBP33	Fig. 14	B33-26-427	B-427	White	2.500 (63.5)	2.250 (57.2)	0.750 (19.1)	1	500	B30-R4300
BBP33	Fig. 14	B33-82-427	B-427	White	2.000 (50.8)	6.000 (152.4)	1.500 (38.1)	1	200	B30-R4300



Patch Panel Adhesive Strips (B-422)

- Continuous supply in 3 widths to make labeling patch panels and other datacomm components quick and easy
- Aggressive adhesive suitable for rough, highly textured and powder-coated surfaces as well as smooth surfaces

Service temp: -40°F to 212°F
Agency approvals:

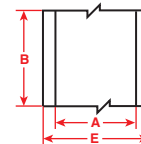


Figure 3



Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 3	B33C-312-422	B-422	White	0.312 (7.9)	85ft (25.9m)	1 roll (cont.)	B30-R6000
BBP33	Fig. 3	B33C-375-422	B-422	White	0.375 (9.5)	85ft (25.9m)	1 roll (cont.)	B30-R6000



Vinyl Cloth Adhesive Wire & Cable Labels (B-498)

- A vinyl cloth label for marking wires, cables and inside-panel components
- A highly unique adhesive and cloth construction gives excellent holding power and still allows for clean removal and reapplication
- Ideal choice for marking both ends of a wire that you may need to cut shorter before final termination

Service temp: -40°F to 175°F
Agency approvals:

 


Figure 1



Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 1	B33-90-498	B-498	White	0.250 (6.4)	1.437 (36.5)	6	2500	B30-R6200
BBP33	Fig. 1	B33-68-498	B-498	White	0.500 (12.7)	0.750 (19.1)	4	5000	B30-R6200
BBP33	Fig. 1	B33-87-498	B-498	White	0.500 (12.7)	1.437 (36.5)	6	2500	B30-R6200
BBP33	Fig. 1	B33-1-498	B-498	White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R6200
BBP33	Fig. 1	B33-91-498	B-498	White	0.750 (19.1)	0.937 (23.8)	4	2500	B30-R6200
BBP33	Fig. 1	B33-95-498	B-498	White	0.800 (20.3)	1.437 (36.5)	3	2300	B30-R6200
BBP33	Fig. 1	B33-5-498	B-498	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6200
BBP33	Fig. 1	B33-88-498	B-498	White	1.000 (25.4)	0.750 (19.1)	2	2500	B30-R6200
BBP33	Fig. 1	B33-89-498	B-498	White	1.000 (25.4)	1.437 (36.5)	3	2300	B30-R6200



Terminal Block Adhesive Strips (B-498)

- Specially designed narrow-width continuous label for alignment on terminal blocks and patch panels
- Highly unique adhesive and vinyl cloth construction gives excellent holding power and still allows for clean removal and reapplication

Service temp: -40°F to 175°F
Agency approvals:


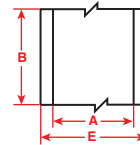


Figure 3



Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 3	B33C-312-498	B-498	White	0.312 (7.9)	85 ft. (25.9m)	1 roll (cont.)	B30-R6200
BBP33	Fig. 3	B33C-375-498	B-498	White	0.375 (9.5)	85 ft. (25.9m)	1 roll (cont.)	B30-R6200

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.

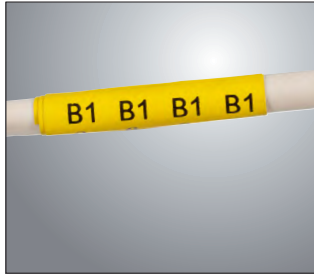

Tedlar® Adhesive Wire & Cable Labels (B-437)

- Topcoated polyvinylfluoride label for wire & cable marking where high temperature and self-extinguishing features are required
- Heavy duty performance with excellent resistance to water, oil and other fluids
- Meets MIL-M-87958 Standard

Service temp: -94°F to 275°F
Agency approvals: **RoHS**

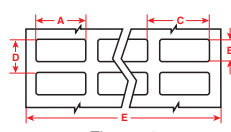


Figure 1

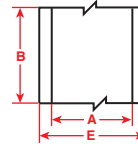


Figure 3

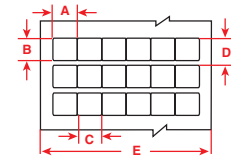


Figure 4

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 4	B33-11-437	B-437	White	0.250 (6.4)	0.250 (6.4)	12	15000	B30-R4300
BBP33	Fig. 1	B33-1-437	B-437	White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R4300
BBP33	Fig. 1	B33-2-437	B-437	White	0.900 (22.9)	0.250 (6.4)	3	5000	B30-R4300
BBP33	Fig. 1	B33-5-437	B-437	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 1	B33-29-437	B-437	White	1.250 (31.8)	0.375 (9.5)	2	5000	B30-R4300
BBP33	Fig. 1	B33-5-437YL	B-437	Yellow	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 1	B33-29-437YL	B-437	Yellow	1.250 (31.8)	0.375 (9.5)	2	5000	B30-R4300
Continuous Rolls									
BBP33	Fig. 3	B33C-1000-437	B-437	White	1.000 (25.4)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-1500-437	B-437	White	1.500 (38.1)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-2000-437	B-437	White	2.000 (50.8)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-3000-437	B-437	White	3.000 (76.2)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-1000-437YL	B-437	Yellow	1.000 (25.4)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-1500-437YL	B-437	Yellow	1.500 (38.1)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-2000-437YL	B-437	Yellow	2.000 (50.8)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-3000-437YL	B-437	Yellow	3.000 (76.2)	85ft. (25.9m)	1 roll (cont.)		B30-R4300



Polyimide High Temp Adhesive Wire & Cable Labels (B-472)

- Topcoated polyimide label for wire and cable marking where high temperature and self-extinguishing features are required
- Heavy duty performance with excellent resistance to water, oil and other fluids

Service temp: -94°F to 320°F
Agency approvals: **RoHS**

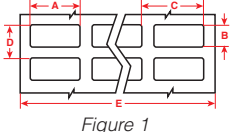


Figure 1

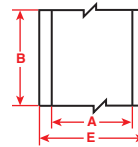


Figure 3

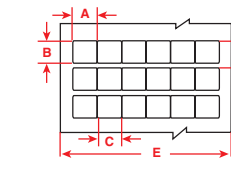


Figure 4

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
BBP33	Fig. 4	B33-11-472	B-472	White	0.250 (6.4)	0.250 (6.4)	12	15000	B30-R4300
BBP33	Fig. 1	B33-1-472	B-472	White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R4300
BBP33	Fig. 1	B33-2-472	B-472	White	0.900 (22.9)	0.250 (6.4)	3	5000	B30-R4300
BBP33	Fig. 1	B33-5-472	B-472	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 1	B33-29-472	B-472	White	1.250 (31.8)	0.375 (9.5)	2	5000	B30-R4300
BBP33	Fig. 1	B33-5-472YL	B-472	Yellow	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 1	B33-29-472YL	B-472	Yellow	1.250 (31.8)	0.375 (9.5)	2	5000	B30-R4300
Continuous Rolls									
BBP33	Fig. 3	B33C-1000-472	B-472	White	1.000 (25.4)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-1500-472	B-472	White	1.500 (38.1)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-2000-472	B-472	White	2.000 (50.8)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-3000-472	B-472	White	3.000 (76.2)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-1000-472YL	B-472	Yellow	1.000 (25.4)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-1500-472YL	B-472	Yellow	1.500 (38.1)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-2000-472YL	B-472	Yellow	2.000 (50.8)	85ft. (25.9m)	1 roll (cont.)		B30-R4300
BBP33	Fig. 3	B33C-3000-472YL	B-472	Yellow	3.000 (76.2)	85ft. (25.9m)	1 roll (cont.)		B30-R4300

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



PermaSleeve® LSZH Low Smoke Zero Halogen Polyolefin Wire Marking Sleeves (B-7641)

Military/Industrial Grade. 2:1 Shrink ratio.

- Low halogen wire marking sleeves offer outstanding fire safety properties and minimal smoke emission
- Meets the following industry specifications:
 - SAE-AS-81531 - MIL-STD-202
 - Tested per ASTM E162, ASTM E662

Service temp: -22°F to 221°F RoHS

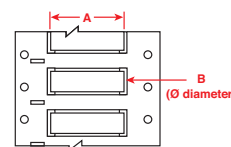


Figure 20

Fits Printer Model	Diagram	Catalog #	Material	Color	For Wire Diameters Inch (mm)	Supplied Diameter B Inch (mm)	Recovered Diameter Inch (mm)	Recovered Wall Thickness Inch (mm)	Sleeves Per Row	Sleeves Per Roll	Rec. Ribbon
3:1 Shrink ratio double-side printable, 2" sleeve width (dimension A):					Min.	Max.					
BBP33	Fig. 20	B33D-94-2-7641	B-7641	White	0.047 (1.2) - 0.080 (2.0)	0.094 (2.4)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R6000
BBP33	Fig. 20	B33D-125-2-7641	B-7641	White	0.062 (1.6) - 0.110 (2.8)	0.125 (3.2)	0.063 (1.6)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R6000
BBP33	Fig. 20	B33D-187-2-7641	B-7641	White	0.094 (2.4) - 0.151 (3.8)	0.187 (4.8)	0.094 (2.4)	.020 (0.5) +/- .003 (0.07)	1	450	B30-R6000
BBP33	Fig. 20	B33D-250-2-7641	B-7641	White	0.125 (3.2) - 0.215 (5.5)	0.250 (6.4)	0.126 (3.2)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R6000
BBP33	Fig. 20	B33D-375-2-7641	B-7641	White	0.188 (4.8) - .0320 (8.1)	0.375 (9.5)	0.189 (4.8)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R6000
BBP33	Fig. 20	B33D-500-2-7641	B-7641	White	0.250 (6.4) - 0.450 (11.4)	0.500 (12.7)	0.252 (6.4)	.025 (0.6) +/- .003 (0.07)	1	225	B30-R6000
BBP33	Fig. 20	B33D-750-2-7641	B-7641	White	0.375 (9.5) - 0.700 (17.8)	0.750 (19.0)	0.374 (9.5)	.030 (0.8) +/- .003 (0.07)	1	150	B30-R6000
BBP33	Fig. 20	B33D-1000-2-7641	B-7641	White	0.450 (11.4) - 0.950 (24.1)	1.000 (25.4)	0.500 (12.7)	.035 (0.9) +/- .005 (0.1)	1	150	B30-R6000
BBP33	Fig. 20	B33D-1500-2-7641	B-7641	White	0.750 (19.0) - 1.400 (35.6)	1.500 (38.1)	0.752 (19.1)	.040 (1.0) +/- .006 (0.2)	1	50	B30-R6000
BBP33	Fig. 20	B33D-94-2-7641Y	B-7641	Yellow	0.047 (1.2) - 0.080 (2.0)	0.094 (2.4)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R6000
BBP33	Fig. 20	B33D-125-2-7641Y	B-7641	Yellow	0.062 (1.6) - 0.110 (2.8)	0.125 (3.2)	0.063 (1.6)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R6000
BBP33	Fig. 20	B33D-187-2-7641Y	B-7641	Yellow	0.094 (2.4) - 0.151 (3.8)	0.187 (4.8)	0.094 (2.4)	.020 (0.5) +/- .003 (0.07)	1	450	B30-R6000
BBP33	Fig. 20	B33D-250-2-7641Y	B-7641	Yellow	0.125 (3.2) - 0.215 (5.5)	0.250 (6.4)	0.126 (3.2)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R6000
BBP33	Fig. 20	B33D-375-2-7641Y	B-7641	Yellow	0.188 (4.8) - .0320 (8.1)	0.375 (9.5)	0.189 (4.8)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R6000
BBP33	Fig. 20	B33D-500-2-7641Y	B-7641	Yellow	0.250 (6.4) - 0.450 (11.4)	0.500 (12.7)	0.252 (6.4)	.025 (0.6) +/- .003 (0.07)	1	225	B30-R6000
BBP33	Fig. 20	B33D-750-2-7641Y	B-7641	Yellow	0.375 (9.5) - 0.700 (17.8)	0.750 (19.0)	0.374 (9.5)	.030 (0.8) +/- .003 (0.07)	1	150	B30-R6000
BBP33	Fig. 20	B33D-1000-2-7641Y	B-7641	Yellow	0.450 (11.4) - 0.950 (24.1)	1.000 (25.4)	0.500 (12.7)	.035 (0.9) +/- .005 (0.1)	1	150	B30-R6000
BBP33	Fig. 20	B33D-1500-2-7641Y	B-7641	Yellow	0.750 (19.0) - 1.400 (35.6)	1.500 (38.1)	0.752 (19.1)	.040 (1.0) +/- .006 (0.2)	1	50	B30-R6000

PermaSleeve® HX Polyolefin Wire Marking Sleeves (B-7642)

Military/Industrial Grade. 2:1 Shrink ratio.

- Flame retardant and high-temp rated but not as high temp as B-345 "HT" sleeves
- Meets the following industry specifications:
 - SAE-AMS-DTL-23053/5 (class 1 and 3) - SAE-AS-81531
 - MIL-STD-202 - Tested per ASTM E162, ASTM E662

Service temp: -40°F to 248°F (short burst max temp: 5 min at 464°F, 24 hrs at 320°F) RoHS

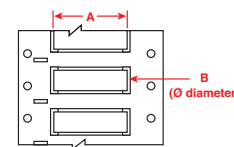


Figure 20

Fits Printer Model	Diagram	Catalog #	Material	Color	For Wire Gauge (approx.)	For Wire Diameters Inch (mm)	Supplied Diameter B Inch (mm)	Recovered Diameter Inch (mm)	Recovered Wall Thickness Inch (mm)	Sleeves Per Row	Sleeves Per Roll	Rec. Ribbon
3:1 Shrink ratio single-side printable, 2" sleeve width (dimension A):						Min.	Max.					
BBP33	Fig. 20	B33-94-2-7642	B-7642	White	24 to 20	0.047 (1.2) - 0.080 (2.0)	0.094 (2.4)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	B33-125-2-7642	B-7642	White	20 to 16	0.062 (1.6) - 0.110 (2.8)	0.125 (3.2)	0.063 (1.6)	.020 (0.5) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	B33-187-2-7642	B-7642	White	16 to 10	0.094 (2.4) - 0.151 (3.8)	0.187 (4.8)	0.094 (2.4)	.020 (0.5) +/- .003 (0.07)	1	450	B30-R4300
BBP33	Fig. 20	B33-250-2-7642	B-7642	White	12 to 8	0.125 (3.2) - 0.215 (5.5)	0.250 (6.4)	0.126 (3.2)	.025 (0.6) +/- .003 (0.07)	1	400	B30-R4300
BBP33	Fig. 20	B33-375-2-7642	B-7642	White	8 to 4	0.188 (4.8) - .0320 (8.1)	0.375 (9.5)	0.189 (4.8)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	B33-500-2-7642	B-7642	White	6 to 1	0.250 (6.4) - 0.450 (11.4)	0.500 (12.7)	0.252 (6.4)	.025 (0.6) +/- .003 (0.07)	1	225	B30-R4300
BBP33	Fig. 20	B33-750-2-7642	B-7642	White	2 to 4/0	0.375 (9.5) - 0.700 (17.8)	0.750 (19.0)	0.374 (9.5)	.030 (0.8) +/- .003 (0.07)	1	150	B30-R4300
BBP33	Fig. 20	B33-1000-2-7642	B-7642	White	2/0 to 0.950 dia	0.450 (11.4) - 0.950 (24.1)	1.000 (25.4)	0.500 (12.7)	.035 (0.9) +/- .005 (0.1)	1	150	B30-R4300
BBP33	Fig. 20	B33-1500-2-7642	B-7642	White	N/A	0.750 (19.0) - 1.400 (35.6)	1.500 (38.1)	0.752 (19.1)	.040 (1.0) +/- .006 (0.2)	1	50	B30-R4300
BBP33	Fig. 20	B33-2000-2-7642	B-7642	White	N/A	1.000 (25.4) - 1.900 (48.3)	2.000 (50.8)	1.000 (25.4)	.045 (1.1) +/- .007 (0.2)	1	50	B30-R4300
3:1 Shrink ratio double-side printable, 2" sleeve width (dimension A):												
BBP33	Fig. 20	B33D-94-2-7642	B-7642	White	24 to 20	0.047 (1.2) - 0.080 (2.0)	0.094 (2.4)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	B33D-125-2-7642	B-7642	White	20 to 16	0.062 (1.6) - 0.110 (2.8)	0.125 (3.2)	0.063 (1.6)	.020 (0.5) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	B33D-187-2-7642	B-7642	White	16 to 10	0.094 (2.4) - 0.151 (3.8)	0.187 (4.8)	0.094 (2.4)	.020 (0.5) +/- .003 (0.07)	1	450	B30-R4300
BBP33	Fig. 20	B33D-250-2-7642	B-7642	White	12 to 8	0.125 (3.2) - 0.215 (5.5)	0.250 (6.4)	0.126 (3.2)	.025 (0.6) +/- .003 (0.07)	1	400	B30-R4300
BBP33	Fig. 20	B33D-375-2-7642	B-7642	White	8 to 4	0.188 (4.8) - 0.0320 (8.1)	0.375 (9.5)	0.189 (4.8)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	B33D-500-2-7642	B-7642	White	6 to 1	0.250 (6.4) - 0.450 (11.4)	0.500 (12.7)	0.252 (6.4)	.025 (0.6) +/- .003 (0.07)	1	225	B30-R4300
BBP33	Fig. 20	B33D-750-2-7642	B-7642	White	2 to 4/0	0.375 (9.5) - 0.700 (17.8)	0.750 (19.0)	0.374 (9.5)	.030 (0.8) +/- .003 (0.07)	1	150	B30-R4300
BBP33	Fig. 20	B33D-1000-2-7642	B-7642	White	2/0 to 0.950 dia	0.450 (11.4) - 0.950 (24.1)	1.000 (25.4)	0.500 (12.7)	.035 (0.9) +/- .005 (0.1)	1	150	B30-R4300
BBP33	Fig. 20	B33D-1500-2-7642	B-7642	White	N/A	0.750 (19.0) - 1.400 (35.6)	1.500 (38.1)	0.752 (19.1)	.040 (1.0) +/- .006 (0.2)	1	50	B30-R4300
BBP33	Fig. 20	B33D-2000-2-7642	B-7642	White	N/A	1.000 (25.4) - 1.900 (48.3)	2.000 (50.8)	1.000 (25.4)	.045 (1.1) +/- .007 (0.2)	1	50	B30-R4300

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



PermaSleeve® FR Fluid Resistant Wire Marking Sleeves (B-344) Military/Industrial Grade. 3:1 Shrink ratio.

- Designed for labeling wires in applications where they will be exposed to fuels, lubricants and harsh chemicals
- Resistant to harsh chemicals including JP8 Jet Fuel, Skydrol® and DOT 3 brake fluid
- Meets the following industry specifications:
 - SAE-AMS-DTL-23053/6 (class 1)
 - MIL-STD-202G method 215K

Service temp: -94°F to 267°F
Agency Approvals for: **RoHS**

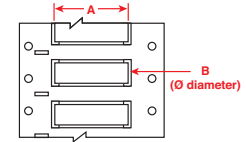


Figure 20

Fits Printer Model	Diagram	Catalog #	Material	Color	For Wire Gauge (approx.)	For Wire Diameters Inch (mm) Min. Max.	Supplied Diameter B Inch (mm)	Recovered Diameter Inch (mm)	Recovered Wall Thickness Inch (mm)	Sleeves Per Row	Sleeves Per Roll	Rec. Ribbon
3:1 Shrink ratio double-side printable, 2" sleeve width (dimension A):												
BBP33	Fig. 20	* B33D-94-2-344	B-344	White	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	0.024 (0.6) +/- 0.003 (0.1)	1	1000	B30-R6600
BBP33	Fig. 20	* B33D-125-2-344	B-344	White	22 to 16	0.046 (1.2) - 0.111 (2.8)	0.125 (3.1)	0.047 (1.2)	0.020 (0.5) +/- 0.003 (0.1)	1	1000	B30-R6600
BBP33	Fig. 20	* B33D-187-2-344	B-344	White	20 to 10	0.062 (1.6) - 0.15 (3.81)	0.187 (4.8)	0.062 (1.6)	0.020 (0.5) +/- 0.003 (0.1)	1	750	B30-R6600
BBP33	Fig. 20	* B33D-250-2-344	B-344	White	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.35)	0.093 (2.4)	0.025 (0.6) +/- 0.003 (0.1)	1	500	B30-R6600
BBP33	Fig. 20	* B33D-375-2-344	B-344	White	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.2)	0.025 (0.6) +/- 0.003 (0.1)	1	500	B30-R6600
BBP33	Fig. 20	* B33D-500-2-344	B-344	White	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.119 (3.0)	0.025 (0.6) +/- 0.003 (0.1)	1	350	B30-R6600
BBP33	Fig. 20	* B33D-750-2-344	B-344	White	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.05)	0.250 (6.35)	0.025 (0.6) +/- 0.003 (0.1)	1	250	B30-R6600
BBP33	Fig. 20	* B33D-1000-2-344	B-344	White	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	0.036 (0.9) +/- 0.003 (0.1)	1	250	B30-R6600
BBP33	Fig. 20	* B33D-1500-2-344	B-344	White	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	0.035 (0.9) +/- 0.003 (0.1)	1	150	B30-R6600
BBP33	Fig. 20	* B33D-94-2-344YL	B-344	Yellow	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	0.024 (0.6) +/- 0.003 (0.1)	1	1000	B30-R6600
BBP33	Fig. 20	* B33D-125-2-344YL	B-344	Yellow	22 to 16	0.046 (1.2) - 0.111 (2.8)	0.125 (3.1)	0.047 (1.2)	0.020 (0.5) +/- 0.003 (0.1)	1	1000	B30-R6600
BBP33	Fig. 20	* B33D-187-2-344YL	B-344	Yellow	20 to 10	0.062 (1.6) - 0.15 (3.81)	0.187 (4.8)	0.062 (1.6)	0.020 (0.5) +/- 0.003 (0.1)	1	750	B30-R6600
BBP33	Fig. 20	* B33D-250-2-344YL	B-344	Yellow	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.35)	0.093 (2.4)	0.025 (0.6) +/- 0.003 (0.1)	1	500	B30-R6600
BBP33	Fig. 20	* B33D-375-2-344YL	B-344	Yellow	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.2)	0.025 (0.6) +/- 0.003 (0.1)	1	500	B30-R6600
BBP33	Fig. 20	* B33D-500-2-344YL	B-344	Yellow	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.119 (3.0)	0.025 (0.6) +/- 0.003 (0.1)	1	350	B30-R6600
BBP33	Fig. 20	* B33D-750-2-344YL	B-344	Yellow	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.05)	0.250 (6.35)	0.025 (0.6) +/- 0.003 (0.1)	1	250	B30-R6600
BBP33	Fig. 20	* B33D-1000-2-344YL	B-344	Yellow	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	0.036 (0.9) +/- 0.003 (0.1)	1	250	B30-R6600
BBP33	Fig. 20	* B33D-1500-2-344YL	B-344	Yellow	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	0.035 (0.9) +/- 0.003 (0.1)	1	150	B30-R6600
BBP33	Fig. 20	* B33D-94-2-344BK	B-344	Black	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	0.024 (0.6) +/- 0.003 (0.1)	1	1000	B30-R6700-WT
BBP33	Fig. 20	* B33D-125-2-344BK	B-344	Black	22 to 16	0.046 (1.2) - 0.111 (2.8)	0.125 (3.1)	0.047 (1.2)	0.020 (0.5) +/- 0.003 (0.1)	1	1000	B30-R6700-WT
BBP33	Fig. 20	* B33D-187-2-344BK	B-344	Black	20 to 10	0.062 (1.6) - 0.15 (3.81)	0.187 (4.8)	0.062 (1.6)	0.020 (0.5) +/- 0.003 (0.1)	1	750	B30-R6700-WT
BBP33	Fig. 20	* B33D-250-2-344BK	B-344	Black	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.35)	0.093 (2.4)	0.025 (0.6) +/- 0.003 (0.1)	1	500	B30-R6700-WT
BBP33	Fig. 20	* B33D-375-2-344BK	B-344	Black	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.2)	0.025 (0.6) +/- 0.003 (0.1)	1	500	B30-R6700-WT
BBP33	Fig. 20	* B33D-500-2-344BK	B-344	Black	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.119 (3.0)	0.025 (0.6) +/- 0.003 (0.1)	1	350	B30-R6700-WT
BBP33	Fig. 20	* B33D-750-2-344BK	B-344	Black	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.05)	0.250 (6.35)	0.025 (0.6) +/- 0.003 (0.1)	1	250	B30-R6700-WT
BBP33	Fig. 20	* B33D-1000-2-344BK	B-344	Black	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	0.036 (0.9) +/- 0.003 (0.1)	1	250	B30-R6700-WT
BBP33	Fig. 20	* B33D-1500-2-344BK	B-344	Black	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	0.035 (0.9) +/- 0.003 (0.1)	1	150	B30-R6700-WT

* **Warning:** Cancer www.P65Warnings.ca.gov

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



PermaSleeve® HT High Temp. PVDF Wire Marking Sleeves (B-345)

High temperature, low outgassing. 2:1 Shrink ratio.

- A 2:1 shrink ratio wire marker sleeve specifically designed for high temperature and low vacuum outgassing applications
- Fade-resistant and flame-retardant
- Meets the following industry specifications:
 - NASA SP-R-0022A Outgassing Performance
 - Tested per ASTM E162, ASTM E662, SAE-AMS-DTL-23053/18 (class 2)
 - MIL-STD-202
 - SAE-AS-81531

Service temp: -67°F to 437°F Agency Approvals for HT and HX Sleeves: **RoHS**


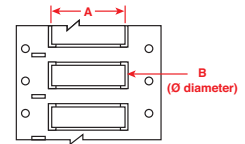


Figure 20

Fits Printer Model	Diagram	Catalog #	Material	Color	For Wire Gauge (approx.)	For Wire Diameters Inch (mm) Min. Max.	Supplied Diameter B Inch (mm)	Recovered Diameter Inch (mm)	Recovered Wall Thickness Inch (mm)	Sleeves Per Row	Per Roll	Rec. Ribbon
3:1 Shrink ratio double-side printable, 2" sleeve width (dimension A):												
BBP33	Fig. 20	B33D-94-2-345	B-345	White	26 to 20	0.031 (0.8) - 0.080 (2.0)	0.094 (2.4)	0.031 (0.8)	.015 (0.4) +/- .003 (0.07)	1	1000	B30-R6000
BBP33	Fig. 20	B33D-94-2-345BK	B-345	Black	26 to 20	0.031 (0.8) - 0.080 (2.0)	0.094 (2.4)	0.031 (0.8)	.015 (0.4) +/- .003 (0.07)	1	1000	B30-R4400-WT
2:1 Shrink ratio double-side printable, 2" sleeve width (dimension A):												
BBP33	Fig. 20	B33D-125-2-345	B-345	White	20 to 16	0.063 (1.6) - 0.110 (2.8)	0.125 (3.2)	0.062 (1.6)	.015 (0.4) +/- .003 (0.07)	1	1000	B30-R6000
BBP33	Fig. 20	B33D-187-2-345	B-345	White	16 to 10	0.094 (2.4) - 0.150 (3.8)	0.187 (4.7)	0.093 (2.4)	.015 (0.4) +/- .003 (0.07)	1	750	B30-R6000
BBP33	Fig. 20	B33D-250-2-345	B-345	White	12 to 8	0.125 (3.2) - 0.215 (5.5)	0.250 (6.4)	0.125 (3.2)	.015 (0.4) +/- .003 (0.07)	1	500	B30-R6000
BBP33	Fig. 20	B33D-375-2-345	B-345	White	8 to 4	0.187 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.187 (4.7)	.015 (0.4) +/- .003 (0.07)	1	500	B30-R6000
BBP33	Fig. 20	B33D-500-2-345	B-345	White	6 to 1	0.250 (6.4) - 0.450 (11.4)	0.500 (12.7)	0.250 (6.4)	.015 (0.4) +/- .003 (0.07)	1	350	B30-R6000
BBP33	Fig. 20	B33D-750-2-345	B-345	White	2 to 4/0	0.375 (9.5) - 0.700 (17.8)	0.750 (19.0)	0.375 (9.5)	.015 (0.4) +/- .003 (0.07)	1	250	B30-R6000
BBP33	Fig. 20	B33D-1000-2-345	B-345	White	2/0 to 0.950 dia	0.450 (11.4) - 0.950 (24.1)	1.000 (25.4)	0.500 (12.7)	.017 (0.4) +/- .004 (0.1)	1	250	B30-R6000
BBP33	Fig. 20	B33D-1500-2-345	B-345	White	N/A	0.750 (19.1) - 1.400 (35.6)	1.500 (38.1)	0.750 (19.1)	.024 (0.6) +/- .004 (0.1)	1	150	B30-R6000
BBP33	Fig. 20	B33D-125-2-345BK	B-345	Black	20 to 16	0.063 (1.6) - 0.110 (2.8)	0.125 (3.2)	0.062 (1.6)	.015 (0.4) +/- .003 (0.07)	1	1000	B30-R4400-WT
BBP33	Fig. 20	B33D-187-2-345BK	B-345	Black	16 to 10	0.094 (2.4) - 0.150 (3.8)	0.187 (4.7)	0.093 (2.4)	.015 (0.4) +/- .003 (0.07)	1	750	B30-R4400-WT
BBP33	Fig. 20	B33D-250-2-345BK	B-345	Black	12 to 8	0.125 (3.2) - 0.215 (5.5)	0.250 (6.4)	0.125 (3.2)	.015 (0.4) +/- .003 (0.07)	1	500	B30-R4400-WT
BBP33	Fig. 20	B33D-375-2-345BK	B-345	Black	8 to 4	0.187 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.187 (4.7)	.015 (0.4) +/- .003 (0.07)	1	500	B30-R4400-WT
BBP33	Fig. 20	B33D-500-2-345BK	B-345	Black	6 to 1	0.250 (6.4) - 0.450 (11.4)	0.500 (12.7)	0.250 (6.4)	.015 (0.4) +/- .003 (0.07)	1	350	B30-R4400-WT
BBP33	Fig. 20	B33D-750-2-345BK	B-345	Black	3 to 4/0	0.375 (9.5) - 0.700 (17.8)	0.750 (19.0)	0.375 (9.5)	.015 (0.4) +/- .003 (0.07)	1	250	B30-R4400-WT
BBP33	Fig. 20	B33D-1000-2-345BK	B-345	Black	2/0 to 0.950 dia	0.450 (11.4) - 0.950 (24.1)	1.000 (25.4)	0.500 (12.7)	.017 (0.4) +/- .004 (0.1)	1	250	B30-R4400-WT
BBP33	Fig. 20	B33D-1500-2-345BK	B-345	Black	N/A	0.750 (19.1) - 1.400 (35.6)	1.500 (38.1)	0.750 (19.1)	.024 (0.6) +/- .004 (0.1)	1	150	B30-R4400-WT

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.

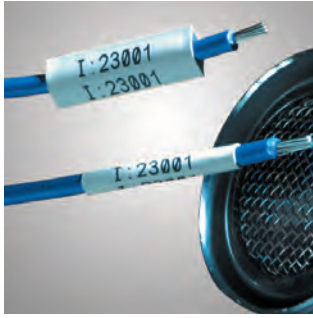

PermaSleeve® PS Polyolefin Wire Marking Sleeves (B-342)

Standard Military/Industrial Grade. 3:1 Shrink ratio.

- A 3:1 heat shrinkable wire marker sleeve that fits snugly around wires
- Fade-resistant and flame-retardant
- Meets the following insulating and physical property specifications:
 - SAE-AMS-DTL-23053/5C (class 1)
 - SAE-AS-81531
 - MIL-STD-202
 - Tested per ASTM E162, ASTM E662

Service temp: -40°F to 267°F
 (short burst max temp: 5 min at 500°F, 24 hrs at 350°F)
 Agency approvals:

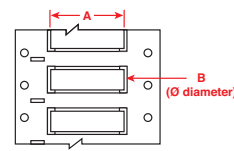


Figure 20

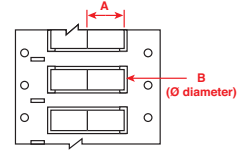


Figure 20-2

Fits Printer Model	Diagram	Catalog #	Material	Color	For Wire Gauge (approx.)	For Wire Diameters Inch (mm) Min. Max.	Supplied Diameter B Inch (mm)	Recovered Diameter Inch (mm)	Recovered Wall Thickness Inch (mm)	Sleeves Per Row	Per Roll	Rec. Ribbon
3:1 Shrink ratio single-side printable, 2" sleeve width (dimension A):												
BBP33	Fig. 20	* B33-94-2-342	B-342	White	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33-125-2-342	B-342	White	22 to 16	0.046 (1.2) - 1.110 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33-187-2-342	B-342	White	20 to 10	0.062 (1.6) - 0.150 (3.8)	0.187 (4.7)	0.062 (1.6)	.020 (0.5) +/- .003 (0.07)	1	750	B30-R4300
BBP33	Fig. 20	* B33-250-2-342	B-342	White	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.4)	0.093 (2.4)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33-375-2-342	B-342	White	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.1)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33-500-2-342	B-342	White	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.187 (4.7)	.025 (0.6) +/- .003 (0.07)	1	350	B30-R4300
BBP33	Fig. 20	* B33-750-2-342	B-342	White	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.0)	0.250 (6.4)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33-1000-2-342	B-342	White	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33-1500-2-342	B-342	White	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	1	150	B30-R4300
BBP33	Fig. 20	* B33-94-2-342YL	B-342	Yellow	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33-125-2-342YL	B-342	Yellow	22 to 16	0.046 (1.2) - 1.110 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33-187-2-342YL	B-342	Yellow	20 to 10	0.062 (1.6) - 0.150 (3.8)	0.187 (4.7)	0.062 (1.6)	.020 (0.5) +/- .003 (0.07)	1	750	B30-R4300
BBP33	Fig. 20	* B33-250-2-342YL	B-342	Yellow	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.4)	0.093 (2.4)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33-375-2-342YL	B-342	Yellow	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.1)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33-500-2-342YL	B-342	Yellow	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.187 (4.7)	.025 (0.6) +/- .003 (0.07)	1	350	B30-R4300
BBP33	Fig. 20	* B33-750-2-342YL	B-342	Yellow	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.0)	0.250 (6.4)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33-1000-2-342YL	B-342	Yellow	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33-1500-2-342YL	B-342	Yellow	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	1	150	B30-R4300
BBP33	Fig. 20	* B33-1500-2-342BK	B-342	Black	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	1	150	B30-R4500-SV
3:1 Shrink ratio single-side printable, 1" sleeve width in "2-up pre-cut" configuration (dimension A):												
BBP33	Fig. 20-2	* B33-94-2-342-2	B-342	White	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	2	2000	B30-R4300
BBP33	Fig. 20-2	* B33-125-2-342-2	B-342	White	22 to 16	0.046 (1.2) - 0.111 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	2	2000	B30-R4300
BBP33	Fig. 20-2	* B33-187-2-342-2	B-342	White	20 to 10	0.062 (1.6) - 0.150 (3.8)	0.187 (4.7)	0.062 (1.6)	.020 (0.5) +/- .003 (0.07)	2	1500	B30-R4300
BBP33	Fig. 20-2	* B33-250-2-342-2	B-342	White	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.4)	0.093 (2.4)	.025 (0.6) +/- .003 (0.07)	2	1000	B30-R4300
BBP33	Fig. 20-2	* B33-375-2-342-2	B-342	White	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.1)	.025 (0.6) +/- .003 (0.07)	2	1000	B30-R4300
BBP33	Fig. 20-2	* B33-500-2-342-2	B-342	White	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.119 (3.0)	.025 (0.6) +/- .003 (0.07)	2	700	B30-R4300
BBP33	Fig. 20-2	* B33-750-2-342-2	B-342	White	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.1)	0.250 (6.35)	.025 (0.6) +/- .003 (0.07)	2	500	B30-R4300
BBP33	Fig. 20-2	* B33-1000-2-342-2	B-342	White	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	2	500	B30-R4300
BBP33	Fig. 20-2	* B33-1500-2-342-2	B-342	White	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	2	150	B30-R4300
BBP33	Fig. 20-2	* B33-94-2-342YL-2	B-342	Yellow	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	2	2000	B30-R4300
BBP33	Fig. 20-2	* B33-125-2-342YL-2	B-342	Yellow	22 to 16	0.046 (1.2) - 0.111 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	2	2000	B30-R4300
BBP33	Fig. 20-2	* B33-187-2-342YL-2	B-342	Yellow	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.1)	0.250 (6.35)	.025 (0.6) +/- .003 (0.07)	2	500	B30-R4300
BBP33	Fig. 20-2	* B33-500-2-342YL-2	B-342	Yellow	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.119 (3.0)	.025 (0.6) +/- .003 (0.07)	2	700	B30-R4300
BBP33	Fig. 20-2	* B33-1000-2-342YL-2	B-342	Yellow	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	2	500	B30-R4300
BBP33	Fig. 20-2	* B33-1500-2-342YL-2	B-342	Yellow	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	2	300	B30-R4300

* **Warning:** Cancer www.P65Warnings.ca.gov

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.

PermaSleeve® PS Polyolefin Wire Marking Sleeves (Continued)

Fits Printer Model	Diagram	Catalog #	Material	Color	For Wire Gauge (approx.)	For Wire Diameters Inch (mm) Min. Max.	Supplied Diameter B Inch (mm)	Recovered Diameter Inch (mm)	Recovered Wall Thickness Inch (mm)	Sleeves Per Row	Per Roll	Rec. Ribbon
3:1 Shrink ratio double-side printable, 2" sleeve width (dimension A):												
BBP33	Fig. 20	* B33D-94-2-342	B-342	White	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33D-125-2-342	B-342	White	22 to 16	0.046 (1.2) - 1.110 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33D-125-2-342-2	B-342	White	22 to 16	0.046 (1.2) - 1.110 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	2	2000	B30-R4300
BBP33	Fig. 20	* B33D-187-2-342	B-342	White	20 to 10	0.062 (1.6) - 0.150 (3.8)	0.187 (4.7)	0.062 (1.6)	.020 (0.5) +/- .003 (0.07)	1	750	B30-R4300
BBP33	Fig. 20	* B33D-250-2-342	B-342	White	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.4)	0.093 (2.4)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33D-375-2-342	B-342	White	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.1)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33D-500-2-342	B-342	White	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.187 (4.7)	.025 (0.6) +/- .003 (0.07)	1	350	B30-R4300
BBP33	Fig. 20	* B33D-750-2-342	B-342	White	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.0)	0.250 (6.4)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33D-1000-2-342	B-342	White	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33D-1500-2-342	B-342	White	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	1	150	B30-R4300
BBP33	Fig. 20	* B33D-94-2-342YL	B-342	Yellow	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33D-125-2-342YL	B-342	Yellow	22 to 16	0.046 (1.2) - 1.110 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R4300
BBP33	Fig. 20	* B33D-187-2-342YL	B-342	Yellow	20 to 10	0.062 (1.6) - 0.150 (3.8)	0.187 (4.7)	0.062 (1.6)	.020 (0.5) +/- .003 (0.07)	1	750	B30-R4300
BBP33	Fig. 20	* B33D-250-2-342YL	B-342	Yellow	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.4)	0.093 (2.4)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33D-375-2-342YL	B-342	Yellow	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.1)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4300
BBP33	Fig. 20	* B33D-500-2-342YL	B-342	Yellow	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.187 (4.7)	.025 (0.6) +/- .003 (0.07)	1	350	B30-R4300
BBP33	Fig. 20	* B33D-750-2-342YL	B-342	Yellow	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.0)	0.250 (6.4)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33D-1000-2-342YL	B-342	Yellow	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	1	250	B30-R4300
BBP33	Fig. 20	* B33D-1500-2-342YL	B-342	Yellow	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	1	150	B30-R4300
BBP33	Fig. 20	* B33D-94-2-342BK	B-342	Black	28 to 20	0.023 (0.6) - 0.080 (2.0)	0.094 (2.4)	0.024 (0.6)	.024 (0.6) +/- .003 (0.07)	1	1000	B30-R4500-SV
BBP33	Fig. 20	* B33D-125-2-342BK	B-342	Black	22 to 16	0.046 (1.2) - 1.110 (2.8)	0.125 (3.2)	0.047 (1.2)	.020 (0.5) +/- .003 (0.07)	1	1000	B30-R4500-SV
BBP33	Fig. 20	* B33D-187-2-342BK	B-342	Black	20 to 10	0.062 (1.6) - 0.150 (3.8)	0.187 (4.7)	0.062 (1.6)	.020 (0.5) +/- .003 (0.07)	1	750	B30-R4500-SV
BBP33	Fig. 20	* B33D-250-2-342BK	B-342	Black	16 to 8	0.094 (2.4) - 0.215 (5.5)	0.250 (6.4)	0.093 (2.4)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4500-SV
BBP33	Fig. 20	* B33D-375-2-342BK	B-342	Black	12 to 4	0.125 (3.2) - 0.320 (8.1)	0.375 (9.5)	0.125 (3.1)	.025 (0.6) +/- .003 (0.07)	1	500	B30-R4500-SV
BBP33	Fig. 20	* B33D-500-2-342BK	B-342	Black	8 to 1	0.187 (4.8) - 0.450 (11.4)	0.500 (12.7)	0.187 (4.7)	.025 (0.6) +/- .003 (0.07)	1	350	B30-R4500-SV
BBP33	Fig. 20	* B33D-750-2-342BK	B-342	Black	6 to 4/0	0.250 (6.4) - 0.700 (17.8)	0.750 (19.0)	0.250 (6.4)	.025 (0.6) +/- .003 (0.07)	1	250	B30-R4500-SV
BBP33	Fig. 20	* B33D-1000-2-342BK	B-342	Black	2 to 0.950 dia	0.333 (8.5) - 0.950 (24.1)	1.000 (25.4)	0.375 (9.5)	.036 (0.9) +/- .003 (0.07)	1	250	B30-R4500-SV
BBP33	Fig. 20	* B33D-1500-2-342BK	B-342	Black	n/a	0.500 (12.7) - 1.400 (35.6)	1.500 (38.1)	0.500 (12.7)	.035 (0.9) +/- .003 (0.07)	1	150	B30-R4500-SV

*  **Warning:** Cancer www.P65Warnings.ca.gov



Rectangular Style Raised Profile Labels/ Engraved Plate Substitutes Labels (B-593)

- High-gloss, polyester label with thick raised profile and ultra-aggressive adhesive (0.70mm thick)
- High-performance, low-cost substitute for engraved plates
- 10-year outdoor durability rating
- Print out in approximately 4 seconds

Service temp: -4°F to 212°F
 Application temp: 50°F to 212°F
 Average outdoor durability: up to 10 years
 Agency approvals:

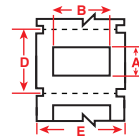



Figure 18c



Diagram	Catalog #	B#	Color	Label Height A Inch (mm)	Label Width B Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Roll	Rec. Ribbon
Fig. 18c	B30EP-171-593-WT	B-593	White	0.490 (12.5)	1.060 (26.9)	0.750 (19.1)	1.375 (34.9)	500	B30-R6000
Fig. 18c	B30EP-172-593-WT	B-593	White	0.590 (15.0)	1.770 (45.0)	0.850 (21.6)	2.500 (63.5)	450	B30-R6000
Fig. 18c	B30EP-175-593-WT	B-593	White	0.750 (19.1)	3.000 (76.2)	1.000 (25.4)	3.250 (82.6)	375	B30-R6000
Fig. 18c	B30EP-173-593-WT	B-593	White	1.000 (25.4)	2.000 (50.8)	1.250 (31.8)	2.500 (63.5)	300	B30-R6000
Fig. 18c	B30EP-174-593-WT	B-593	White	1.000 (25.4)	4.000 (101.6)	1.250 (31.8)	4.250 (108.0)	300	B30-R6000
Fig. 18c	B30EP-176-593-WT	B-593	White	1.000 (25.4)	3.000 (76.2)	1.250 (31.8)	3.250 (82.6)	300	B30-R6000
Fig. 18c	B30EP-177-593-WT	B-593	White	2.500 (63.5)	3.000 (76.2)	2.750 (69.9)	3.250 (82.6)	125	B30-R6000
Fig. 18c	B30EP-171-593-YL	B-593	Yellow	0.490 (12.5)	1.060 (26.9)	0.750 (19.1)	1.375 (34.9)	500	B30-R6000
Fig. 18c	B30EP-172-593-YL	B-593	Yellow	0.590 (15.0)	1.770 (45.0)	0.850 (21.6)	2.500 (63.5)	450	B30-R6000
Fig. 18c	B30EP-175-593-YL	B-593	Yellow	0.750 (19.1)	3.000 (76.2)	1.000 (25.4)	3.250 (82.6)	375	B30-R6000
Fig. 18c	B30EP-173-593-YL	B-593	Yellow	1.000 (25.4)	2.000 (50.8)	1.250 (31.8)	2.500 (63.5)	300	B30-R6000
Fig. 18c	B30EP-174-593-YL	B-593	Yellow	1.000 (25.4)	4.000 (101.6)	1.250 (31.8)	4.250 (108.0)	300	B30-R6000
Fig. 18c	B30EP-176-593-YL	B-593	Yellow	1.000 (25.4)	3.000 (76.2)	1.250 (31.8)	3.250 (82.6)	300	B30-R6000
Fig. 18c	B30EP-177-593-YL	B-593	Yellow	2.500 (63.5)	3.000 (76.2)	2.750 (69.9)	3.250 (82.6)	125	B30-R6000
Fig. 18c	B30EP-171-593-BK	B-593	Black	0.490 (12.5)	1.060 (26.9)	0.750 (19.1)	1.375 (34.9)	500	B30-R4400-WT
Fig. 18c	B30EP-172-593-BK	B-593	Black	0.590 (15.0)	1.770 (45.0)	0.850 (21.6)	2.500 (63.5)	450	B30-R4400-WT
Fig. 18c	B30EP-175-593-BK	B-593	Black	0.750 (19.1)	3.000 (76.2)	1.000 (25.4)	3.250 (82.6)	375	B30-R4400-WT
Fig. 18c	B30EP-173-593-BK	B-593	Black	1.000 (25.4)	2.000 (50.8)	1.250 (31.8)	2.500 (63.5)	300	B30-R4400-WT
Fig. 18c	B30EP-174-593-BK	B-593	Black	1.000 (25.4)	4.000 (101.6)	1.250 (31.8)	4.250 (108.0)	300	B30-R4400-WT
Fig. 18c	B30EP-176-593-BK	B-593	Black	1.000 (25.4)	3.000 (76.2)	1.250 (31.8)	3.250 (82.6)	300	B30-R4400-WT
Fig. 18c	B30EP-177-593-BK	B-593	Black	2.500 (63.5)	3.000 (76.2)	2.750 (69.9)	3.250 (82.6)	125	B30-R4400-WT
Fig. 18c	B30EP-171-593-GN	B-593	Green	0.490 (12.5)	1.060 (26.9)	0.750 (19.1)	1.375 (34.9)	500	B30-R4400-WT
Fig. 18c	B30EP-172-593-GN	B-593	Green	0.590 (15.0)	1.770 (45.0)	0.850 (21.6)	2.500 (63.5)	450	B30-R4400-WT
Fig. 18c	B30EP-175-593-GN	B-593	Green	0.750 (19.1)	3.000 (76.2)	1.000 (25.4)	3.250 (82.6)	375	B30-R4400-WT
Fig. 18c	B30EP-173-593-GN	B-593	Green	1.000 (25.4)	2.000 (50.8)	1.250 (31.8)	2.500 (63.5)	300	B30-R4400-WT
Fig. 18c	B30EP-174-593-GN	B-593	Green	1.000 (25.4)	4.000 (101.6)	1.250 (31.8)	4.250 (108.0)	300	B30-R4400-WT
Fig. 18c	B30EP-176-593-GN	B-593	Green	1.000 (25.4)	3.000 (76.2)	1.250 (31.8)	3.250 (82.6)	300	B30-R4400-WT
Fig. 18c	B30EP-177-593-GN	B-593	Green	2.500 (63.5)	3.000 (76.2)	2.750 (69.9)	3.250 (82.6)	125	B30-R4400-WT
Fig. 18c	B30EP-171-593-RD	B-593	Red	0.490 (12.5)	1.060 (26.9)	0.750 (19.1)	1.375 (34.9)	500	B30-R4400-WT
Fig. 18c	B30EP-172-593-RD	B-593	Red	0.590 (15.0)	1.770 (45.0)	0.850 (21.6)	2.500 (63.5)	450	B30-R4400-WT
Fig. 18c	B30EP-173-593-RD	B-593	Red	1.000 (25.4)	2.000 (50.8)	1.250 (31.8)	2.500 (63.5)	300	B30-R4400-WT
Fig. 18c	B30EP-174-593-RD	B-593	Red	1.000 (25.4)	4.000 (101.6)	1.250 (31.8)	4.250 (108.0)	300	B30-R4400-WT
Fig. 18c	B30EP-171-593-SL	B-593	Silver	0.490 (12.5)	1.060 (26.9)	0.750 (19.1)	1.375 (34.9)	500	B30-R6000
Fig. 18c	B30EP-172-593-SL	B-593	Silver	0.590 (15.0)	1.770 (45.0)	0.850 (21.6)	2.500 (63.5)	450	B30-R6000
Fig. 18c	B30EP-173-593-SL	B-593	Silver	1.000 (25.4)	2.000 (50.8)	1.250 (31.8)	2.500 (63.5)	300	B30-R6000
Fig. 18c	B30EP-174-593-SL	B-593	Silver	1.000 (25.4)	4.000 (101.6)	1.250 (31.8)	4.250 (108.0)	300	B30-R6000

U.S. Patent Nos. US8475914B2; US9005729B2.

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.

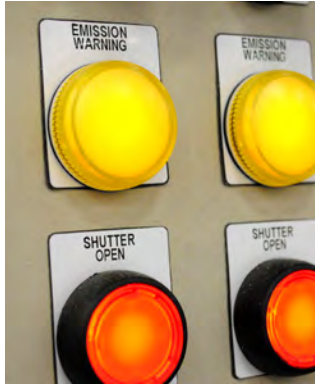

Push Button Style Raised Profile Labels/ Engraved Plate Substitutes Labels (B-593)

- High-gloss, polyester label with thick raised profile and ultra-aggressive adhesive (0.70mm thick)
- 10-year outdoor durability rating
- 5 push button sizes (including keyed and non-keyed 22.5mm and 30.5mm hole diameter keyed)

Service temp: -4°F to 212°F
 Application temp: 50°F to 212°F
 Average outdoor durability: up to 10 years
 Agency approvals:

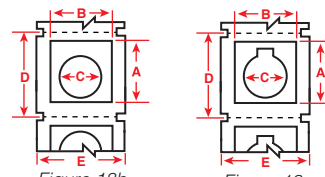


Figure 18b
(Without key hole)

Figure 18a

Diagram	Catalog #	B#	Color	Label Height A Inch (mm)	Label Width B Inch (mm)	Hole Diameter C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Fig. 18a	B30EP-167-593-WT	B-593	White	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
Fig. 18b	B30EP-167U-593-WT	B-593	White	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
Fig. 18a	B30EP-169-593-WT	B-593	White	1.800 (45.7)	1.800 (45.7)	1.200 (30.5)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R6000
Fig. 18a	B30EP-168-593-WT	B-593	White	1.900 (48.3)	1.200 (30.5)	0.885 (22.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R6000
Fig. 18a	B30EP-170-593-WT	B-593	White	2.400 (60.9)	2.400 (60.9)	1.200 (30.5)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R6000
Fig. 18a	B30EP-167-593-YL	B-593	Yellow	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
Fig. 18b	B30EP-167U-593-YL	B-593	Yellow	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
Fig. 18a	B30EP-169-593-YL	B-593	Yellow	1.800 (45.7)	1.800 (45.7)	1.200 (30.5)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R6000
Fig. 18a	B30EP-168-593-YL	B-593	Yellow	1.900 (48.3)	1.200 (30.5)	0.885 (22.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R6000
Fig. 18a	B30EP-170-593-YL	B-593	Yellow	2.400 (60.9)	2.400 (60.9)	1.200 (30.5)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R6000
Fig. 18a	B30EP-167-593-BK	B-593	Black	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
Fig. 18b	B30EP-167U-593-BK	B-593	Black	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
Fig. 18a	B30EP-169-593-BK	B-593	Black	1.800 (45.7)	1.800 (45.7)	1.200 (30.5)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R4400-WT
Fig. 18a	B30EP-168-593-BK	B-593	Black	1.900 (48.3)	1.200 (30.5)	0.885 (22.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R4400-WT
Fig. 18a	B30EP-170-593-BK	B-593	Black	2.400 (60.9)	2.400 (60.9)	1.200 (30.5)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R4400-WT
Fig. 18a	B30EP-167-593-GN	B-593	Green	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
Fig. 18b	B30EP-167U-593-GN	B-593	Green	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
Fig. 18a	B30EP-169-593-GN	B-593	Green	1.800 (45.7)	1.800 (45.7)	1.200 (30.5)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R4400-WT
Fig. 18a	B30EP-168-593-GN	B-593	Green	1.900 (48.3)	1.200 (30.5)	0.885 (22.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R4400-WT
Fig. 18a	B30EP-170-593-GN	B-593	Green	2.400 (60.9)	2.400 (60.9)	1.200 (30.5)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R4400-WT
Fig. 18a	B30EP-167-593-RD	B-593	Red	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
Fig. 18b	B30EP-167U-593-RD	B-593	Red	1.500 (38.1)	1.200 (30.5)	0.885 (22.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
Fig. 18a	B30EP-169-593-RD	B-593	Red	1.800 (45.7)	1.800 (45.7)	1.200 (30.5)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R4400-WT
Fig. 18a	B30EP-168-593-RD	B-593	Red	1.900 (48.3)	1.200 (30.5)	0.885 (22.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R4400-WT
Fig. 18a	B30EP-170-593-RD	B-593	Red	2.400 (60.9)	2.400 (60.9)	1.200 (30.5)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R4400-WT

U.S. Patent Nos. US8475914B2; US9005729B2.

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Polyester Labels (B-422, B-423, B-430, B-432, B483, B-484, B-489)

- For general purpose industrial ID applications, bin and shelf labeling in production areas, and PC board component ID

B-423, B-483, B-489: Service temp: -94°F to 248°F
Agency approvals:

B-430, B-432: Service temp: -40°F to 212°F
Agency approvals:

B-484: Service temp: -40°F to 240°F
Agency approvals:

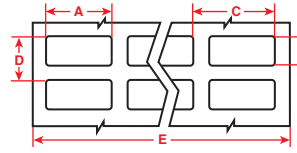


Figure 1

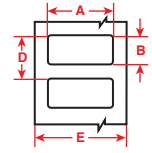


Figure 2

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Standard adhesive (B-423 gloss white):									
BBP33	Fig. 4	B33-11-423	B-423	Gloss White	0.250 (6.4)	0.250 (6.4)	12	15000	B30-R6000
BBP33	Fig. 1	B33-38-423	B-423	Gloss White	0.375 (9.5)	0.375 (9.5)	9	5000	B30-R6000
BBP33	Fig. 1	B33-149-423	B-423	Gloss White	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33	Fig. 1	B33-1-423	B-423	Gloss White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R6000
BBP33	Fig. 2	B33-46-423	B-423	Gloss White	0.750 (19.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-49-423	B-423	Gloss White	0.900 (22.9)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-103-423	B-423	Gloss White	1.000 (25.4)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 1	B33-3-423	B-423	Gloss White	1.000 (25.4)	0.375 (9.5)	3	5000	B30-R6000
BBP33	Fig. 1	B33-5-423	B-423	Gloss White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 2	B33-43-423	B-423	Gloss White	1.250 (31.8)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 1	B33-29-423	B-423	Gloss White	1.250 (31.8)	0.375 (9.5)	2	5000	B30-R6000
BBP33	Fig. 2	B33-45-423	B-423	Gloss White	1.500 (38.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-72-423	B-423	Gloss White	1.750 (44.5)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-53-423	B-423	Gloss White	2.000 (50.8)	0.500 (12.7)	1	2500	B30-R6000
BBP33	Fig. 2	B33-17-423	B-423	Gloss White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-18-423	B-423	Gloss White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-423	B-423	Gloss White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
BBP33	Fig. 2	B33-55-423	B-423	Gloss White	4.000 (101.6)	2.000 (50.8)	1	750	B30-R6000
Standard adhesive (B-430 clear):									
BBP33	Fig. 1	B33-5-430	B-430	Clear	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 2	B33-17-430	B-430	Clear	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-18-430	B-430	Clear	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
Stronger adhesive for textured surfaces (B-422 gloss white):									
BBP33	Fig. 1	B33-149-422	B-422	White	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33	Fig. 1	B33-5-422	B-422	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 1	B33-147-422	B-422	White	1.500 (38.1)	0.375 (9.5)	2	2500	B30-R6000
BBP33	Fig. 2	B33-102-422	B-422	White	1.500 (38.1)	0.375 (9.5)	1	2500	B30-R6000
BBP33	Fig. 2	B33-136-422	B-422	White	1.500 (38.1)	0.750 (19.1)	1	1500	B30-R6000
BBP33	Fig. 2	B33-17-422	B-422	White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-18-422	B-422	White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-422	B-422	White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
BBP33	Fig. 2	B33-76-422	B-422	White	4.000 (101.6)	3.000 (76.2)	1	500	B30-R6000
Stronger adhesive for textured surfaces (B-432 clear):									
BBP33	Fig. 1	B33-149-432	B-432	Clear	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33	Fig. 1	B33-5-432	B-432	Clear	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 2	B33-17-432	B-432	Clear	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-18-432	B-432	Clear	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-432	B-432	Clear	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
Ultra aggressive adhesive for highly textured surfaces (B-483 gloss white):									
BBP33	Fig. 1	B33-149-483	B-483	Gloss White	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33	Fig. 1	B33-5-483	B-483	Gloss White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 2	B33-17-483	B-483	Gloss White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-7-483	B-483	Gloss White	2.750 (69.9)	1.250 (31.8)	1	1000	B30-R6000
BBP33	Fig. 2	B33-18-483	B-483	Gloss White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-483	B-483	Gloss White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
BBP33	Fig. 2	B33-55-483	B-483	Gloss White	4.000 (101.6)	2.000 (50.8)	1	750	B30-R6000
Ultra aggressive adhesive for highly textured surfaces (B-489 matte white):									
BBP33	Fig. 1	B33-5-489	B-489	Matte White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 2	B33-17-489	B-489	Matte White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 2	B33-18-489	B-489	Matte White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 2	B33-19-489	B-489	Matte White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R4300
Polyester - Ultra-aggressive adhesive and pliable for conforming to angular surfaces (B-484):									
BBP33	Fig. 2	B33-125-484	B-484	White	0.900 (22.9)	0.500 (12.7)	1	1500	B30-R6000
BBP33	Fig. 1	B33-5-484	B-484	White	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 2	B33-136-484	B-484	White	1.500 (38.1)	0.750 (19.1)	1	1500	B30-R6000
BBP33	Fig. 2	B33-17-484	B-484	White	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-18-484	B-484	White	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-484	B-484	White	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Metallized Polyester Labels (B-428, B-434, B-438, B-486, B-565)

- For product labeling, asset tracking and general industrial ID
- Ideal for serial number plates and rating plates with name-plate quality and metal-looking finish

B-428: Service temp: -40°F to 293°F Agency approvals:

B-434: Service temp: -40°F to 194°F Agency approvals:

B-438: Service temp: -40°F to 104°F Agency approvals:

B-486: Service temp: -40°F to 248°F Agency approvals:

B-565: Service temp: -40°F to 240°F Agency approvals:

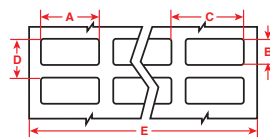


Figure 1

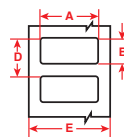


Figure 2

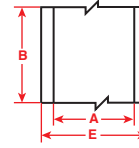


Figure 3

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Standard adhesive for smooth surfaces (B-428 matte):									
BBP33	Fig. 1	B33-5-428	B-428	Matte Silver	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 2	B33-53-428	B-428	Matte Silver	2.000 (50.8)	0.500 (12.7)	1	2500	B30-R4300
BBP33	Fig. 2	B33-17-428	B-428	Matte Silver	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 2	B33-18-428	B-428	Matte Silver	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R4300
BBP33	Fig. 2	B33-19-428	B-428	Matte Silver	3.000 (76.2)	2.000 (50.8)	1	500	B30-R4300
BBP33	Fig. 3	B33C-3000-428	B-428	Matte Silver	3.000 (76.2)	85 ft (25.9m)		1 roll (cont.)	B30-R4300
Standard adhesive for smooth surfaces (B-565 matte):									
All	Fig. 3	B30C-1125-565-SL	B-565	Matte Silver	1.125 (28.6)	100 ft. (30.5m)		1 roll (cont.)	B30-R4300
All	Fig. 3	B30C-2250-565-SL	B-565	Matte Silver	2.250 (57.5)	100ft. (30.5m)		1 roll (cont.)	B30-R4300
All	Fig. 3	B30C-4000-565-SL	B-565	Matte Silver	4.000 (101.6)	100ft. (30.5m)		1 roll (cont.)	B30-R4300
Standard adhesive for smooth surfaces (B-435 glossy):									
BBP33	Fig. 2	B33-18-435	B-435	Gloss Silver	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-435	B-435	Gloss Silver	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
BBP33	Fig. 2	B33-55-435	B-435	Gloss Silver	4.000 (101.6)	2.000 (50.8)	1	750	B30-R6000
Stronger adhesive for rougher surfaces (B-434 glossy):									
BBP33	Fig. 1	B33-5-434	B-434	Gloss Silver	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R6000
BBP33	Fig. 2	B33-136-434	B-434	Gloss Silver	1.500 (38.1)	0.750 (19.1)	1	1500	B30-R6000
BBP33	Fig. 2	B33-17-434	B-434	Gloss Silver	2.000 (50.8)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-18-434	B-434	Gloss Silver	3.000 (76.2)	1.000 (25.4)	1	1500	B30-R6000
BBP33	Fig. 2	B33-19-434	B-434	Gloss Silver	3.000 (76.2)	2.000 (50.8)	1	500	B30-R6000
BBP33	Fig. 2	B33-55-434	B-434	Gloss Silver	4.000 (101.6)	2.000 (50.8)	1	750	B30-R6000
Ultra aggressive adhesive for highly textured, powder coated and low surface energy surfaces (B-486 matte):									
BBP33	Fig. 2	B33-59-486	B-486	Matte Silver	1.000 (25.4)	0.500 (12.7)	1	2500	B30-R4300
BBP33	Fig. 1	B33-5-486	B-486	Matte Silver	1.000 (25.4)	0.500 (12.7)	3	5000	B30-R4300
BBP33	Fig. 2	B33-53-486	B-486	Matte Silver	2.000 (50.8)	0.500 (12.7)	1	2500	B30-R4300
BBP33	Fig. 2	B33-17-486	B-486	Matte Silver	2.000 (50.8)	1.000 (25.4)	1	1300	B30-R4300
BBP33	Fig. 2	B33-7-486	B-486	Matte Silver	2.750 (69.9)	1.250 (31.8)	1	1000	B30-R4300
BBP33	Fig. 2	B33-18-486	B-486	Matte Silver	3.000 (76.2)	1.000 (25.4)	1	1300	B30-R4300
BBP33	Fig. 2	B33-19-486	B-486	Matte Silver	3.000 (76.2)	2.000 (50.8)	1	500	B30-R4300
BBP33	Fig. 2	B33-76-486	B-486	Matte Silver	4.000 (101.6)	3.000 (76.2)	1	500	B30-R4300
BBP33	Fig. 2	B33-161-486	B-486	Matte Silver	4.000 (101.6)	4.000 (101.6)	1	250	B30-R4300

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.




Standard Polyimide Labels (B-724, B-727)

- Top or bottom-side component ID or board ID labels that withstand the various processes, fluxes and cleaning solvents encountered in the manufacture of printed circuit boards

B-727: Service temp: -94°F to 212°F (short burst max temp: 80 sec at 572°F, 5 min at 500°F, 2 hrs at 338°F)
Agency approvals: RoHS

B-724: Service temp: -94°F to 518°F (short burst max temp: 80 sec at 626°F, 5 min at 536°F)
Agency approvals: RoHS

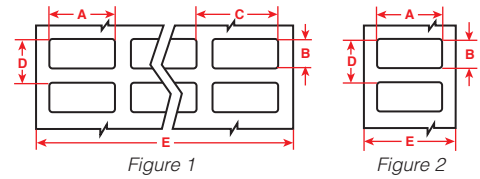


Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Standard temperature (B-727 gloss white):									
BBP33	Fig. 1	B33-11-727	B-727	Gloss White	0.250 (6.35)	0.250 (6.4)	12	5000	B30-R6000
BBP33	Fig. 1	B33-38-727	B-727	Gloss White	0.375 (9.5)	0.375 (9.5)	9	5000	B30-R6000
BBP33	Fig. 1	B33-149-727	B-727	Gloss White	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33	Fig. 1	B33-1-727	B-727	Gloss White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R6000
BBP33	Fig. 2	B33-49-727	B-727	Gloss White	0.900 (22.9)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 1	B33-2-727	B-727	Gloss White	0.900 (22.9)	0.250 (6.4)	3	5000	B30-R6000
BBP33	Fig. 2	B33-103-727	B-727	Gloss White	1.000 (25.4)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-58-727	B-727	Gloss White	1.000 (25.4)	0.375 (9.5)	1	4000	B30-R6000
BBP33	Fig. 2	B33-59-727	B-727	Gloss White	1.000 (25.4)	0.500 (12.7)	1	2500	B30-R6000
BBP33	Fig. 2	B33-43-727	B-727	Gloss White	1.250 (31.8)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-44-727	B-727	Gloss White	1.375 (34.9)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-45-727	B-727	Gloss White	1.500 (38.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	B33-72-727	B-727	Gloss White	1.750 (44.5)	0.250 (6.4)	1	5000	B30-R6000
Extremely high temperature (B-724 matte amber):									
BBP33	Fig. 1	B33-149-724	B-724	Matte Amber	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R4300
BBP33	Fig. 2	B33-46-724	B-724	Matte Amber	0.750 (19.1)	0.250 (6.4)	1	5000	B30-R4300
BBP33	Fig. 1	B33-1-724	B-724	Matte Amber	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R4300
BBP33	Fig. 1	B33-2-724	B-724	Matte Amber	0.900 (22.9)	0.250 (6.4)	3	5000	B30-R4300
BBP33	Fig. 2	B33-43-724	B-724	Matte Amber	1.250 (31.8)	0.250 (6.4)	1	5000	B30-R4300
BBP33	Fig. 1	B33-4-724	B-724	Matte Amber	1.500 (38.1)	0.250 (6.4)	2	5000	B30-R4300



Static Dissipative Polyimide Labels (B-717, B-718, B-719)

- Circuit board and electronic component ID with static dissipative adhesive and release liner with surface resistivity values recommended for dissipative ESD packaging
- Complies with EIA-541 Packaging Material Standards for ESD Sensitive Items
- For top or bottom-side component or board identification

All: Service temp: -94°F to 212°F (short burst max temp: 80 sec at 572°F, 5 min at 500°F, 2 hrs at 338°F)
Agency approvals: RoHS

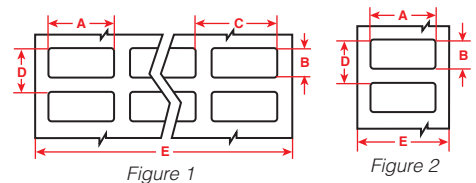

Fits Printer Model(s)	Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Standard thickness (B-717 gloss white):									
BBP33	Fig. 2	* B33-46-717	B-717	Gloss White	0.750 (19.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-103-717	B-717	Gloss White	1.000 (25.4)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-43-717	B-717	Gloss White	1.250 (31.8)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-45-717	B-717	Gloss White	1.500 (38.1)	0.250 (6.4)	1	5000	B30-R6000
Low profile label (B-718 gloss white):									
BBP33	Fig. 4	* B33-11-718	B-718	Gloss White	0.250 (6.4)	0.250 (6.4)	12	1500	B30-R6000
BBP33	Fig. 1	* B33-38-718	B-718	Gloss White	0.375 (9.5)	0.375 (9.5)	9	5000	B30-R6000
BBP33	Fig. 1	* B33-149-718	B-718	Gloss White	0.500 (12.7)	0.500 (12.7)	4	5000	B30-R6000
BBP33	Fig. 1	* B33-1-718	B-718	Gloss White	0.750 (19.1)	0.250 (6.4)	4	5000	B30-R6000
BBP33	Fig. 2	* B33-46-718	B-718	Gloss White	0.750 (19.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-49-718	B-718	Gloss White	0.900 (22.9)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-43-718	B-718	Gloss White	1.250 (31.8)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-45-718	B-718	Gloss White	1.500 (38.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 2	* B33-72-718	B-718	Gloss White	1.750 (44.5)	0.250 (6.4)	1	5000	B30-R6000
Low profile label - Matte white to prevent sticking of solder balls (B-719 matte white):									
BBP33	Fig. 1	* B33-38-719	B-719	Matte White	0.375 (9.5)	0.375 (9.5)	9	5000	B30-R6000
BBP33	Fig. 2	* B33-46-719	B-719	Matte White	0.750 (19.1)	0.250 (6.4)	1	5000	B30-R6000
BBP33	Fig. 1	* B33-2-719	B-719	Matte White	0.900 (22.9)	0.250 (6.4)	3	5000	B30-R6000
BBP33	Fig. 2	* B33-43-719	B-719	Matte White	1.250 (31.8)	0.250 (6.4)	1	5000	B30-R6000

* **Warning:** Cancer www.P65Warnings.ca.gov

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.



Product ID Materials

- A variety of polyester and specialty materials in wide 4.0" format rolls designed for shape cutting multiple labels out of a single continuous roll
- Ideal for smaller volume custom Product ID and general ID labels
- Proven materials with agency approvals for Product ID and asset tracking applications

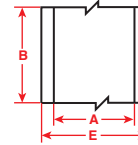


Figure 3



- B-424:** Paper
- B-423:** Polyester w/ standard adhesive
- B-428:** Metallized polyester w/standard adhesive for smooth surfaces
- B-432:** Polyester w/ stronger adhesive
- B-434:** Metallized polyester w/stronger adhesive for textured surfaces
- B-437:** Tedlar® for high-temp labeling & cable wraps
- B-480:** Non-metal polyester with rubber-based adhesive for oily/greasy surfaces
- B-483:** Polyester w/ ultra-aggressive adhesive for rough surfaces
- B-484:** Polyester w/ ultra-aggressive adhesive and pliability for angular surfaces
- B-489:** Polyester w/ ultra-aggressive adhesive for rough surfaces
- B-488:** Polyester w/ standard adhesive and chemical resistance
- B-486:** Metallized polyester w/ ultra-aggressive adhesive for rougher surfaces
- B-498:** Vinyl cloth
- B-565:** Metallized polyester w/ standard adhesive
- B-595:** Indoor/outdoor vinyl
- B-724:** Polyimide label for extremely high temperatures
- B-727:** Polyimide label for standard temperatures
- B-787:** Polyvinylflouride tape

- Matte bright white Service temp: -40°F to 124°F RoHS
- Gloss white Service temp: -94°F to 248°F RoHS
- Matte silver Service temp: -40°F to 293°F RoHS
- Clear Service temp: -40°F to 212°F RoHS
- Gloss silver Service temp: -40°F to 194°F RoHS
- Satin light gray Service temp: -94°F to 275°F RoHS
- Gloss white Service temp: -94°F to 248°F RoHS
- Gloss white Service temp: -40°F to 240°F RoHS
- Matte white Service temp: -94°F to 248°F RoHS
- Matte white Service temp: -40°F to 280°F RoHS
- Matte silver Service temp: -40°F to 248°F RoHS
- Semi-gloss white Service temp: -40°F to 175°F RoHS
- Matte silver Service temp: -40°F to 240°F RoHS
- Semi-gloss white Service temp: -40°F to 180°F RoHS
- Matte amber Service temp: -94°F to 518°F RoHS
- Gloss white Service temp: -94°F to 212°F RoHS
- Gloss white Service temp: -94°F to 212°F RoHS

Fits Printer Model(s)	Diagram	For BBP37 XY-Cutter	Catalog #	B#	Color	Label Width A Inch (mm)	Roll Length B Feet (m)	Labels Per Roll	Rec. Ribbon
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-423	B-423	White	4.000 (101.6)	150 ft. (45.7 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-424	B-424	White	4.000 (101.6)	150 ft. (45.7 m)	1 roll (cont.)	B30-R4300
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-432	B-432	Clear	4.000 (101.6)	120 ft. (36.6 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-437	B-437	White	4.000 (101.6)	150 ft. (45.7 m)	1 roll (cont.)	B30-R4300
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-483	B-483	White	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-484	B-484	White	4.000 (101.6)	150 ft. (45.7 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-488	B-488	White	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R4300
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-489	B-489	White	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R4300
All	Fig. 3	✗	B30C-4000-595-WT	B-595	White	4.000 (101.6)	100 ft. (30.4 m)	1 roll (cont.)	B30-R10000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-727	B-727	White	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-498	B-498	White	4.000 (101.6)	80 ft. (24.4)	1 roll (cont.)	B30-R6200
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-787	B-787	White	4.000 (101.6)	60 ft. (18.3 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-724	B-724	Amber	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R4300
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-480	B-480	Light Gray	4.000 (101.6)	115 ft. (35.1 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-428	B-428	Silver	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R4300
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-434	B-434	Silver	4.000 (101.6)	130 ft. (39.6 m)	1 roll (cont.)	B30-R6000
S3100, BBP35, 37	Fig. 3	✗	B30C-4000-486	B-486	Silver	4.000 (101.6)	115 ft. (35.1 m)	1 roll (cont.)	B30-R4300
All	Fig. 3	✗	B30C-4000-565-SL	B-565	Silver	4.000 (101.6)	100 ft. (30.4 m)	1 roll (cont.)	B30-R10000



Tamper-Evident Asset ID Labels (B-438)

- Leaves checkerboard footprint on surface and on label if removed to prevent re-use

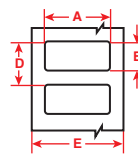


Figure 2

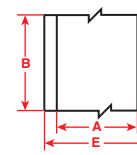


Figure 3



Diagram	Catalog #	B#	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Roll	Rec. Ribbon
Fig. 2	B30-17-438	B-438	Matte Silver	2.000 (50.8)	1.000 (25.4)	1225	B30-R4300
Fig. 2	B30-18-438	B-438	Matte Silver	3.000 (76.2)	1.000 (25.4)	1225	B30-R4300
Fig. 2	B30-222-438	B-438	Matte Silver	3.000 (76.2)	2.000 (50.8)	650	B30-R4300
Fig. 3	B30C-3000-438-SL	B-438	Matte Silver	3.000 (76.2)	100 ft. (30.5m)	1 roll (cont.)	B30-R4300

All labels shown are compatible with the BradyPrinter S3100, BBP30, BBP31, BBP33, BBP35 and BBP37 printers unless otherwise noted.

B30 Series Supply Starter Kits

Get started right, and save a little too, with a Brady supply starter kit! Packages of most commonly used labels and ribbons for the most common labeling applications. Just enough supplies to ensure you have what you need to get going on your project.

All kits compatible with the S3100, BBP30, 31, 33, 35 and 37 printers.




Basic Supply Starter Kit

Kit Includes:

- (1) B30C-4000-595-YL - 4" Yellow Vinyl
- (1) B30C-4000-595-WT - 4" White Vinyl
- (1) B30C-2250-595-RD - 2.25" Red Vinyl
- (1) B30-R10000 - Black Print Ribbon
- (1) B30-R10000-WT - White Print Ribbon

Printer sold separately.

Catalog #	Description
146069	Basic Supply Starter Kit - Small

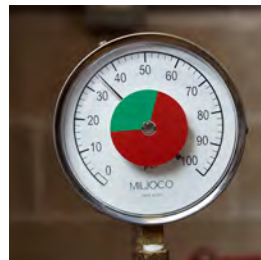

Gauge Label Supply Kit for BBP37 Printer*

Kit Includes:

- (2) B30C-4000-595-WT - 4" White Vinyl
- (2) B30-R10000-GR-8 - Green & Red Pannelled Print Ribbon - 8" Panel length

BBP37 model needed to print cut gauge label supplies. Printer sold separately.

Catalog #	Description
146070	Gauge Label Supply Kit - Small



Arc Flash Supply Kit

LARGE Kit Includes:

- (2) B30-25-595-ANSIWA - 4" x 6" B-595 ANSI Warning Header
- (1) B30-241-595-ANSIWA - 2.25" x 3" B-595 ANSI Warning Header
- (1) B30EP-174-593-WT - 1" x 4" B-593 White Raised Panel Label
- (1) B30C-2250-595-OR - 2.25" B-595 Orange Vinyl
- (3) B30-R10000 - Black Print Ribbon

SMALL Kit Includes:

- (2) B30-25-595-ANSIWA - 4" x 6" ANSI Warning Header Roll
- (1) B30-R10000 - Black Print Ribbon

Printer sold separately unless otherwise noted.

Catalog #	Description
142061	Arc Flash Warning Supply Kit - Large
146071	Arc Flash Warning Supply Kit - Small
3100W-ARC-KIT	BBP31 Printer with Large Arc Flash Warning Supply Kit



GHS Supply Kit

LARGE Kit Includes:

- (1) B30-262-7569-CLP4B - 4" x 6" GHS label w/L4B four-diamond
- (2) B30-261-7569-CLP4B - 3" x 4" GHS label w/L4B four-diamond
- (1) B30-260-7569-CLP4B - 2" x 3" GHS label w/L4B four-diamond
- (3) B30-R10000 - Black Print Ribbon

SMALL Kit Includes:

- (2) B30-262-7569-CLP4B - 4" x 6" GHS label w/L4B four-diamond
- (1) B30-R10000 - Black Print Ribbon

Printer sold separately.

Catalog #	Description
146072	GHS Supply Kit - Large
146073	GHS Supply Kit - Small
S3100W-GHS-KIT	BBP31 Printer with GHS Supply Kit

All kits compatible with the S3100, BBP30, 31, 33, 35 and 37 printers.




Safety & Compliance Supply Kit

Kit Includes:

- (1) B30-25-595-ANSIDA - 4" x 6" B-595 ANSI Danger Header
- (1) B30-25-595-ANSIWA - 4" x 6" B-595 ANSI Warning Header
- (1) B30-25-595-ANSICA - 4" x 6" B-595 ANSI Caution Header
- (1) B30-25-595-ANSINO - 4" x 6" B-595 ANSI Notice Header
- (1) B30C-4000-526 - 4" B-526 Photoluminescent
- (1) B30-263-595-NFPA - 4" x 6" B-595 RTK NFPA
- (2) B30-R10000 - Black Print Ribbon
- (1) B30-R10000-RD - Red Print Ribbon

Printer sold separately unless otherwise noted.

Catalog #	Description
142062	Safety & Compliance Supply Kit - Large
S3100W-SAFE-KIT	S3100 Printer w/ Safety & Compliance Supply Kit

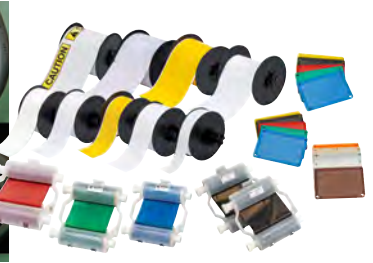

5S Visual Workplace Supply Kit

Kit Includes:

- (1) B30C-4000-595-WT - 4" B-595 White Vinyl
- (1) B30C-2250-595-WT - 2.25" B-595 White Vinyl
- (1) B30C-4000-595-YL - 4" B-595 Yellow Vinyl
- (1) B30C-2250-595-YL - 2.25" B-595 Yellow Vinyl
- (1) B30C-2250-581-WT - 2.25" B-581 Repositionable Vinyl
- (1) B30C-1125-581-WT - 1.125" B-581 Repositionable Vinyl
- (1) B30C-2500-509-WT - 2.25" Magnetic Vinyl
- (1) 142133 - Blank Valve Tag Variety Pack
- (1) B30-219-595-BLNKWT - Die Cut Labels for Valve Tags
- (1) B30-25-595-ANSIWA - 4" x 6" B-595 Caution Header
- (2) B30-R10000 - Black Print Ribbon
- (1) B30-R10000-RD - Red Print Ribbon
- (1) B30-R10000-GN - Green Print Ribbon
- (1) B30-R10000-BL - Blue Print Ribbon

Printer sold separately unless otherwise noted.

Catalog #	Description
142063	5S Visual Workplace Supply Kit - Large
S3100W-LEAN-KIT	S3100 Printer w/ 5S Visual Workplace Supply Kit



Pipe Identification Supply Kit

Kit Includes:

- (1) B30C-4000-595-YL - 4" B-595 Yellow Vinyl
- (1) B30C-2250-595-YL - 2.25" B-595 Yellow Vinyl
- (1) B30C-1125-595-YL - 1.125" B-595 Yellow Vinyl
- (1) B30C-4000-595-GN - 4" B-595 Green Vinyl
- (1) B30C-2250-595-GN - 2.25" B-595 Green Vinyl
- (1) B30C-1125-595-GN - 1.125" B-595 Green Vinyl
- (1) B30C-1125-595-BL - 1.125" B-595 Blue Vinyl
- (1) B30C-2250-595-RD - 2.25" B-595 Red Vinyl
- (1) B30C-1125-595-RD - 1.125" B-595 Red Vinyl
- (1) B30EP-174-593-BK - 1" x 4" B-593 Black Raised Panel
- (1) 142133 - Blank Valve Tag Variety Pack
- (1) B30-242-595-BLNKWT - Small Die Cut Labels for Valve Tags
- (3) B30-R10000 - Black Print Ribbon
- (2) B30-R10000-WT - White Print Ribbon

Printer sold separately unless otherwise noted.

Catalog #	Description
142064	Pipe ID Supply Kit - Large
S3100W-PIPE-KIT	S3100 Printer w/ Pipe ID Supply Kit



General Industrial & 5S Supply Kit

Kit Includes:

- (1) B30C-4000-595-WT - 4" B-595 White
- (1) B30C-2250-595-WT - 2.25" B-595 White
- (1) B30C-1125-595-WT - 1.125" B-595 White Vinyl
- (1) B30C-4000-595-YL - 4" B-595 Yellow Vinyl
- (1) B30C-2250-595-YL - 2.25" B-595 Yellow Vinyl
- (1) B30C-1125-595-YL - 1.125" B-595 Yellow Vinyl
- (1) B30EP-177-593-BK - 2.5" x 3" B-593 Black Raised Panel
- (1) B30-25-595-ANSIDA - 4" x 6" B-595 ANSI Danger Header
- (1) B30-25-595-ANSICA - 4" x 6" B-595 ANSI Caution Header
- (1) B30C-2250-584-YL - 2.25" Reflective Yellow
- (1) B30C-4250-551-WT - 4.25" White Tag Stock
- (2) B30-R10000 - Black Print Ribbon
- (1) B30-R10000-WT - White Print Ribbon
- (1) B30-R10000-RD - Red Print Ribbon

Printer sold separately unless otherwise noted.

Catalog #	Description
142065	General Industrial & 5S Supply Kit - Large
S3100W-GEN-KIT	S3100 Printer w/ General Industrial 5S Supply Kit



Print Ribbons

for S3100, BBP®30, BBP®31, BBP®33, BBP®35 & BBP®37

“Drop & Click” print ribbons for 5-second ribbon supply changes

- Tough, smear-proof ribbons that produce long-lasting printed text and withstand years in industrial areas and outdoor conditions
- Self-contained cartridges drop straight into printer with a “click”
- No calibrating, no threading, no wasted feeding, no hassles and the ink will always be facing the right direction!
- Printer notifies user if installed ribbon is not recommended for installed labels



Ribbon installs in 5 seconds...snaps into place!

Print Ribbon / Label Material Compatibility

B-#	Material	B30-R4300 (Black)	B30-R6000 (Black)	B30-R6200 (Black)	B30-R6400 (Black)	B30-R6600 (Black)	B30-R10000 (Black)	B30-R4500-SV* (Silver)	B30-R4400-WT (White)	B30-R6700-WT* (White)	B30-R10000-WT (White)	B30-R10000-YL (Yellow)	B30-R10000-YL2 (Yellow)	B30-R10000 (Colors)
B-342	Permasleeves	●	-	-	-	-	-	●*	-	-	-	-	-	-
B-344	Permasleeves	-	-	-	-	●	-	-	-	●*	-	-	-	-
B-345	Permasleeves	-	●	-	-	-	-	-	●	-	-	-	-	-
B-423	Glossy White Polyester	-	●	●	-	-	-	-	-	-	-	-	-	-
B-424	Matte White Paper	●	-	-	-	-	-	-	-	-	-	-	-	-
B-425	Polypropylene	●	-	-	●	-	-	-	-	-	-	-	-	-
B-428	Metallized Polyester	●	-	-	-	-	-	-	-	-	-	-	-	-
B-432	Glossy Clear Polyester	-	●	-	-	-	-	-	●	-	-	-	-	-
B-434	Glossy Metallized Polyester	-	●	-	-	-	-	-	-	-	-	-	-	-
B-437	Tedlar®	●	-	-	-	-	-	-	-	-	-	-	-	-
B-438	Tamper Evident Metallized Polyester	●	-	-	-	-	-	-	-	-	-	-	-	-
B-480	Polyester Rubber-Based Adhesive	-	●	-	-	-	-	-	●	-	-	-	-	-
B-483	Glossy White Polyester	-	●	-	-	-	-	-	-	-	-	-	-	-
B-483	ToughStripe®	-	●	-	-	-	-	-	●	-	-	-	-	-
B-484	Glossy White Polyester	-	●	-	-	-	-	-	-	-	-	-	-	-
B-486	Matte Metallized Polyester	●	-	-	-	-	-	-	-	-	-	-	-	-
B-488	Matte White Polyester	●	-	-	-	-	-	-	-	-	-	-	-	-
B-489	Matte White Polyester	●	-	-	-	-	-	-	-	-	-	-	-	-
B-509	Printable Magnetic	-	-	-	-	-	●	-	-	-	-	-	-	●**
B-526	Photoluminescent Polyester	-	-	-	-	-	●	-	-	-	-	-	-	●**
B-549	Cold Temperature Polyester	-	-	-	-	-	●	-	-	-	●	-	-	●**
B-551	Non-Adhesive Tag	-	-	-	-	-	●	-	-	-	-	-	-	●**
B-565	Metallized Polyester	-	-	-	-	-	●	-	-	-	-	-	-	-
B-569	Low-Halide Polyester	-	-	-	-	-	●	-	-	-	●	-	-	●**
B-581	Repositionable Vinyl	-	-	-	-	-	●	-	-	-	●	-	-	●**
B-584	Retro Reflective	-	-	-	-	-	●	-	-	-	-	-	-	●**
B-593	Raised Panel	-	●	-	-	-	-	-	●	-	-	-	-	-
B-595	Outdoor Vinyl	-	-	-	-	-	●	-	-	-	●	●***	●***	●**
B-854	Toughwash™ Metal Detectable	-	●	-	-	-	-	-	-	-	-	-	-	-
B-855	Toughwash™	-	●	-	-	-	-	-	-	-	-	-	-	-
B-724	Matte Amber Polyimide	●	-	-	-	-	-	-	-	-	-	-	-	-
B-727	Glossy White Polyimide	-	●	-	-	-	-	-	-	-	-	-	-	-
B-787	Glossy White Polyvinyl Fluoride	-	●	-	-	-	-	-	-	-	-	-	-	-
B-7569	Vinyl Film	-	-	-	-	-	●	-	-	-	-	-	-	-
B-7642	Permasleeves	●	-	-	●	-	-	-	-	-	-	-	-	-

Refer to the corresponding Tech Data Sheets for complete material information at BradyID.com/techdata.

* B30-R4500-SV ribbon for use with B-342 black PermaSleeves® only; B30-R6700-WT ribbon for use with B-345 black PermaSleeves® only.

** Colored ribbons optimized for use on white material. Test use on other material colors for suitability to your application.

*** Use B30-R10000-YL for printing yellow onto white. Use B30-R10000-YL2 for printing yellow onto other colors of B-595.

Single Color Print Ribbons

- Solid color ribbons for printing a single color onto a label
- Can be swapped out for printing multi-color labels on BBP35 or BBP37 printer if a paneled multi-color ribbon is not on hand



Catalog #	Color	Size Inch (mm)	Length Feet (m)
B30-R10000	Black	4.330 (109.9)	200 ft. (60.9 m)
B30-R6000	Black	4.330 (109.9)	200 ft. (60.9 m)
B30-R6200	Black	4.330 (109.9)	200 ft. (60.9 m)
B30-R6400	Black	4.330 (109.9)	200 ft. (60.9 m)
B30-R6600	Black	4.330 (109.9)	200 ft. (60.9 m)
B30-R4300	Black	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-WT	White	4.330 (109.9)	200 ft. (60.9 m)
B30-R4400-WT	White	4.330 (109.9)	200 ft. (60.9 m)
B30-R6700-WT	White*	4.330 (109.9)	200 ft. (60.9 m)
B30-R4500-SV	Silver*	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-RD	Red	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-GN	Green	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-BL	Blue	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-YL	Yellow**	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-YL2	Yellow**	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-OR	Orange	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-MA	Magenta	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-PRCCY	Process Cyan***	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-PRCYEL	Process Yellow***	4.330 (109.9)	200 ft. (60.9 m)
B30-R10000-PRCMAG	Process Magenta***	4.330 (109.9)	200 ft. (60.9 m)


* B30-R4500-SV ribbon for use with B-342 black PermaSleeves® only; B30-R6700-WT ribbon for use with B-345 black PermaSleeves® only.

** B30-R10000-YL for printing yellow onto white. B30-R10000-YL2 for printing yellow onto other colors of B-595.

*** Process ribbons print a much lighter shade — designed to be used together with other process ribbons and black ribbon to lay down a dot pattern for printing "blended" colors and process color objects with the BBP35 or BBP37 printers.

BBP®35 & BBP®37 Multi-Color "Paneled" Print Ribbons

- Ribbons have panels of 2 or 4 different colors for printing multiple colors onto a label
- Use CMYK ribbon for printing blended colors. Blended colors are not as saturated as solid or spot color paneled ribbons, but do offer a broader palette of available colors and shades
- Print multiple colors without having to swap in multiple ribbons

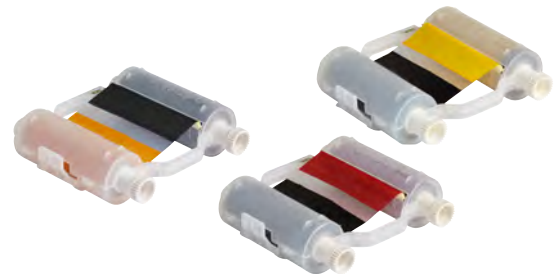

Two Color Print Ribbons

Fits Printer Model(s)	Catalog #	Color	Size Inch (mm)	Length Feet (m)
8" panel length - Typical yield: 100 panel sets per roll				
BBP35, 37	B30-R10000-KR-8	Black and Red	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KY-8	Black and Yellow	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KB-8	Black and Blue	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KO-8	Black and Orange	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KG-8	Black and Green	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-GR-8	Green and Red	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
16" panel length - Typical yield: 60 panel sets per roll				
BBP35, 37	B30-R10000-KR-16	Black and Red	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KY-16	Black and Yellow	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KB-16	Black and Blue	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KO-16	Black and Orange	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KG-16	Black and Green	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-RB-16	Red and Blue	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)

Four Color Print Ribbons

Fits Printer Model(s)	Catalog #	Color	Size Inch (mm)	Length Feet (m)
8" panel length - Typical yield: 50 panel sets per roll				
BBP35, 37	B30-R10000-KRGB-8	Black, Red, Green and Blue	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KRYG-8	Black, Red, Yellow and Green	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KRYB-8	Black, Red, Yellow and Blue	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KRBO-8	Black, Red, Blue and Orange	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-CMYK-8	Process Cyan, Mgnta, Yell, Blk	4.330 (101.9) x 8.000 (203.2) Panels	200 ft. (60.9 m)
16" panel length - Typical yield: 30 panel sets per roll				
BBP35, 37	B30-R10000-KRGB-16	Black, Red, Green and Blue	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-KRYB-16	Black, Red, Yellow and Blue	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)
BBP35, 37	B30-R10000-CMYK-16	Black, Cyan, Magenta, Yellow **	4.330 (101.9) x 16.000 (406.4) Panels	200 ft. (60.9 m)

** Process ribbons print a much lighter shade — designed to be used together with other process ribbons and black ribbon to lay down a dot pattern for printing "blended" colors and process color objects.



Y4646305 MS4646305

© 2018 Brady Worldwide Inc. ALL RIGHTS RESERVED

USA
Customer Service: 1-888-272-3946
BradyID.com

Canada
Customer Service: 1-800-263-6179
BradyCanada.ca

Mexico
Customer Service: 1-800-262-7777
Inside Sales: 1-800-262-7777 ext 177
BradyLatinAmerica.com

