

- Unique Guide-Rite Fastener provides for fast and easy installation.
- Fasteners will rotate 360°.
- Simply installed with a hammer and pliers.


## Guide-Rite™ Conduit To Beam Fasteners



| UPC/Part Number | Catalog Number        | Conduit Size | Flange Thickness | Box Qty. |
|-----------------|-----------------------|--------------|------------------|----------|
| 78101118450     | <b>BG-6-U-2-4*</b>    | 3/8"         | 1/8" - 1/4"      | 100      |
| 78101118455     | <b>BG-6-U-5-8*</b>    | 3/8"         | 5/16" - 1/2"     | 100      |
| 78101118460     | <b>BG-6-U-9-12*</b>   | 3/8"         | 9/16" - 3/4"     | 100      |
| 78101118525     | <b>BG-8-12-U-2-4</b>  | 1/2", 3/4"   | 1/8" - 1/4"      | 100      |
| 78101118530     | <b>BG-8-12-U-5-8</b>  | 1/2", 3/4"   | 5/16" - 1/2"     | 100      |
| 78101118535     | <b>BG-8-12-U-9-12</b> | 1/2", 3/4"   | 9/16" - 3/4"     | 100      |
| 78101118625     | <b>BG-16-U-2-4</b>    | 1"           | 1/8" - 1/4"      | 100      |
| 78101118630     | <b>BG-16-U-5-8</b>    | 1"           | 5/16" - 1/2"     | 100      |
| 78101118635     | <b>BG-16-U-9-12</b>   | 1"           | 9/16" - 3/4"     | 100      |
| 78101118680     | <b>BG-20-U-2-4</b>    | 1 1/4"       | 1/8" - 1/4"      | 100      |
| 78101118685     | <b>BG-20-U-5-8</b>    | 1 1/4"       | 5/16" - 1/2"     | 100      |
| 78101118690     | <b>BG-20-U-9-12</b>   | 1 1/4"       | 9/16" - 3/4"     | 100      |
| 78101118720     | <b>BG-24-U-2-4</b>    | 1 1/2"       | 1/8" - 1/4"      | 50       |
| 78101118725     | <b>BG-24-U-5-8</b>    | 1 1/2"       | 5/16" - 1/2"     | 50       |
| 78101118730     | <b>BG-24-U-9-12</b>   | 1 1/2"       | 9/16" - 3/4"     | 50       |
| 78101118760     | <b>BG-32-U-2-4</b>    | 2"           | 1/8" - 1/4"      | 50       |
| 78101118765     | <b>BG-32-U-5-8</b>    | 2"           | 5/16" - 1/2"     | 50       |
| 78101118770     | <b>BG-32-U-9-12</b>   | 2"           | 9/16" - 3/4"     | 50       |

Patent #4958792

\* BG-6 will accept the following range  $\varnothing.420 - \varnothing.675$ : 14/2 thru 10/4 MC/AC cable and 5/16" or 3/8" flexible conduit

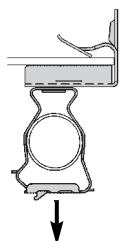

**Static Load Capacity**

75 Lbs.

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.