

Specifications

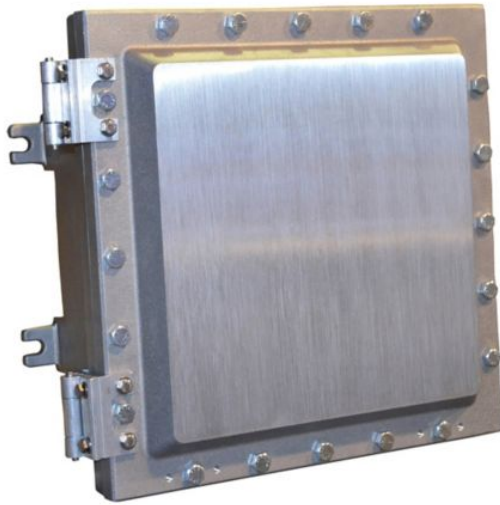


Photo is representative

Eaton ECP122408

Eaton Crouse-Hinds series ECP enclosure,
Square cover, 8-15/16" depth, 12" x 24" x 8",
Copper-free aluminum, Tap-in mounting feet

General specifications

PRODUCT NAME	Eaton Crouse-Hinds series ECP enclosure
CATALOG NUMBER	ECP122408
UPC	662276322066
PRODUCT LENGTH/DEPTH	17.25 in
PRODUCT HEIGHT	29.25 in
PRODUCT WIDTH	11.63 in
PRODUCT WEIGHT	164 lb



Certifications and compliances

AREA CLASSIFICATION	Hazardous/Classified Locations
---------------------	--------------------------------

Product specifications

ENCLOSURE SIZE	12" x 24" x 8"
----------------	----------------

STANDARDS TYPE	NEC/CEC
NEC HAZARDOUS RATING	Class I, Division 1
	Class I, Division 2
	Class II, Division 1
	Class II, Division 2
	Class III
NEMA RATING	3
	3R
	4
	7
	9

COVER TYPE	Square
DEPTH	8-15/16 in
MATERIAL	Copper-free aluminum
SPECIAL FEATURES	Tap-in mounting feet

Resources

3D CAD DRAWING PACKAGE	Eaton Crouse-Hinds ECP122408 3D drawing
BROCHURES	Crouse-Hinds series ECP Enclosures Brochure
CATALOGS	Crouse-Hinds series ECP catalog page
CERTIFICATION REPORTS	ECP Explosionproof Enclosures UL certification
	Intertek EC-Type Examination Certificate
	IECEX Certificate of Conformity
INSTALLATION INSTRUCTIONS	IF 1107 - Mounting Plate Kit
	IF 1639 - ECP Explosionproof Enclosures
SPECIFICATIONS AND DATASHEETS	ECP Enclosures Eaton Specification Sheet - ECP122408

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc

Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights
Reserved.

Eaton is a registered trademark.

All other trademarks are property of
their respective owners.

Follow us on social media to get the latest
product and support information.

