

Specifications

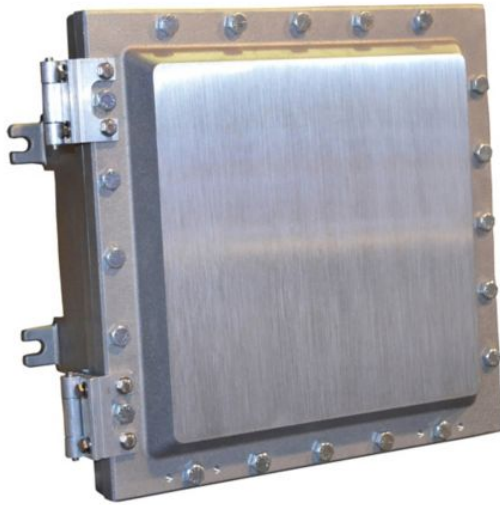


Photo is representative

Eaton ECP123608

Eaton Crouse-Hinds series ECP enclosure, Square cover, 8-15/16" depth, 12" x 36" x 8", Copper-free aluminum, Tap-in mounting feet

General specifications

PRODUCT NAME	Eaton Crouse-Hinds series ECP enclosure
CATALOG NUMBER	ECP123608
UPC	662276322042
PRODUCT LENGTH/DEPTH	17 in
PRODUCT HEIGHT	41.05 in
PRODUCT WIDTH	11.92 in
PRODUCT WEIGHT	247 lb



Certifications and compliances

AREA CLASSIFICATION Hazardous/Classified Locations

Product specifications

ENCLOSURE SIZE 12" x 36" x 8"

STANDARDS TYPE	NEC/CEC
NEC HAZARDOUS RATING	Class I, Division 1 Class I, Division 2 Class II, Division 1 Class II, Division 2 Class III
NEMA RATING	3 3R 4 7 9

COVER TYPE	Square
DEPTH	8-15/16 in
MATERIAL	Copper-free aluminum
SPECIAL FEATURES	Tap-in mounting feet

Resources

3D CAD DRAWING PACKAGE [Eaton Crouse-Hinds ECP123608 3D drawing](#)

BROCHURES [Crouse-Hinds series ECP Enclosures Brochure](#)

CATALOGS [Crouse-Hinds series ECP catalog page](#)

CERTIFICATION REPORTS [ECP Explosionproof Enclosures UL certification](#)

[IECEX Certificate of Conformity](#)

[Intertek EC-Type Examination Certificate](#)

INSTALLATION INSTRUCTIONS [IF 1639 - ECP Explosionproof Enclosures](#)

[IF 1107 - Mounting Plate Kit](#)

SPECIFICATIONS AND DATASHEETS [Eaton Specification Sheet - ECP123608](#)

[ECP Enclosures](#)

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.



Specifications

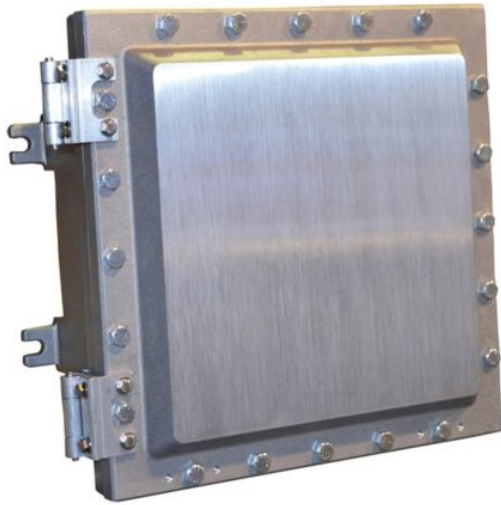


Photo is representative

Eaton ECP123608

Eaton Crouse-Hinds series ECP enclosure, Square cover, 8-15/16" depth, 12" x 36" x 8", Copper-free aluminum, Tap-in mounting feet

General specifications

PRODUCT NAME	Eaton Crouse-Hinds series ECP enclosure
CATALOG NUMBER	ECP123608
UPC	662276322042
PRODUCT LENGTH/DEPTH	17 in
PRODUCT HEIGHT	41.05 in
PRODUCT WIDTH	11.92 in
PRODUCT WEIGHT	247 lb



Certifications and compliances

AREA CLASSIFICATION Hazardous/Classified Locations

Product specifications

ENCLOSURE SIZE 12" x 36" x 8"

STANDARDS TYPE	NEC/CEC
NEC HAZARDOUS RATING	Class I, Division 1 Class I, Division 2 Class II, Division 1 Class II, Division 2 Class III
NEMA RATING	3 3R 4 7 9

COVER TYPE	Square
DEPTH	8-15/16 in
MATERIAL	Copper-free aluminum
SPECIAL FEATURES	Tap-in mounting feet

Resources

3D CAD DRAWING PACKAGE [Eaton Crouse-Hinds ECP123608 3D drawing](#)

BROCHURES [Crouse-Hinds series ECP Enclosures Brochure](#)

CATALOGS [Crouse-Hinds series ECP catalog page](#)

CERTIFICATION REPORTS [ECP Explosionproof Enclosures UL certification](#)

[IECEX Certificate of Conformity](#)

[Intertek EC-Type Examination Certificate](#)

INSTALLATION INSTRUCTIONS [IF 1639 - ECP Explosionproof Enclosures](#)

[IF 1107 - Mounting Plate Kit](#)

SPECIFICATIONS AND DATASHEETS [Eaton Specification Sheet - ECP123608](#)

[ECP Enclosures](#)

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

Follow us on social media to get the latest product and support information.

All other trademarks are property of their respective owners.

