

Specifications

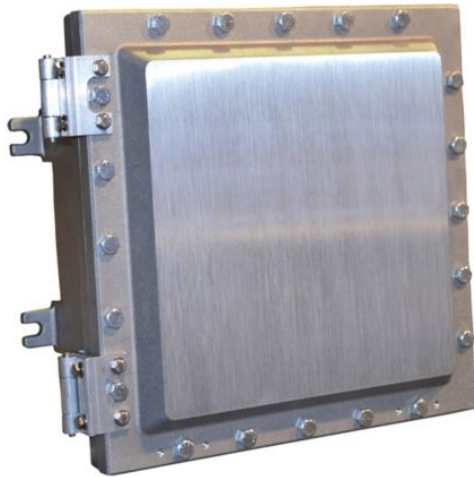


Photo is representative

Eaton ECP123608

Eaton Crouse-Hinds series ECP enclosure, Square cover, 8-15/16" depth, 12" x 36" x 8", Copper-free aluminum, Tap-in mounting feet

General specifications

PRODUCT NAME	Eaton Crouse-Hinds series ECP enclosure
CATALOG NUMBER	ECP123608
UPC	662276322042
PRODUCT LENGTH/DEPTH	17 in
PRODUCT HEIGHT	41.05 in
PRODUCT WIDTH	11.92 in
PRODUCT WEIGHT	247 lb

Certifications and compliances

AREA CLASSIFICATION	Hazardous/Classified Locations
STANDARDS TYPE	NEC/CEC
NEC HAZARDOUS RATING	Class I, Division 1 Class I, Division 2 Class II, Division 1 Class II, Division 2 Class III
NEMA RATING	3 3R 4 7 9

Resources

3D CAD DRAWING PACKAGE	Eaton Crouse-Hinds ECP123608 3D drawing
BROCHURES	Crouse-Hinds series ECP Enclosures Brochure
CATALOGS	Crouse-Hinds series ECP catalog page
CERTIFICATION REPORTS	ECP Explosionproof Enclosures UL certification IECEX Certificate of Conformity Intertek EC-Type Examination Certificate
INSTALLATION INSTRUCTIONS	IF 1639 - ECP Explosionproof Enclosures IF 1107 - Mounting Plate Kit
SPECIFICATIONS AND DATASHEETS	ECP Enclosures Eaton Specification Sheet - ECP123608

Product specifications

ENCLOSURE SIZE	12" x 36" x 8"
COVER TYPE	Square
DEPTH	8-15/16 in
MATERIAL	Copper-free aluminum
SPECIAL FEATURES	Tap-in mounting feet

PROJECT NAME:
PROJECT NUMBER:
PREPARED BY:
DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights Reserved.

Follow us on social media to get the latest product and support information.

