

4-INCH INCANDESCENT NEW CONSTRUCTION ICAT




H99ICAT

FEATURES

- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Slide-N-Side™ wire traps
- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

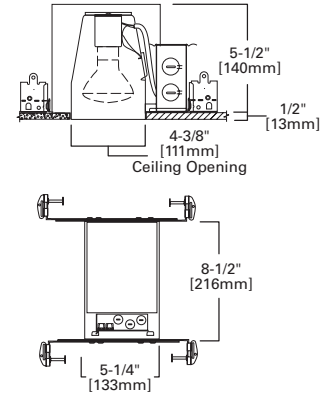

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^Δ

SAMPLE NUMBER: H99ICAT - 993W

Housing	Trims	Accessories
<p>H99ICAT=4" Aperture, Shallow Ceiling, IC AIR-TITE™, 120V Line Voltage</p>	<p>Adjustables</p> <p>996 Adjustable Eyeball - 15° Tilt, 50W PAR20, OD: 5-1/16" [129mm] 996P=White Trim with White Eyeball 996SN=Satin Nickel Trim with Satin Nickel Eyeball 996TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p> <p>998 Adjustable Eyeball - 30° Tilt, 40W R16, OD: 5-1/16" [129mm] 998P=White Trim with White Eyeball 998PB=Polished Brass Trim with Polished Brass Eyeball 998SN=Satin Nickel Trim with Satin Nickel Eyeball 998TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p> <p>Baffles</p> <p>953 Metal Baffle, 30W R20, 35W PAR20, With H1999 Socket Extender 50W PAR20, OD: 5-1/16" [129mm] 953P=White Trim with Black Baffle 953SN=Satin Nickel Trim with Satin Nickel Baffle 953TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle 953W=White Trim with White Baffle</p> <p>993 Coilex® Baffle, 30W R20, 35W PAR20, With H1999 Socket Extender 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 993P=White Trim with Black Baffle 993PB=Polished Brass Trim with Black Baffle 993SN=Satin Nickel Trim with Black Baffle 993TBZ=Tuscan Bronze Trim with Black Baffle 993W=White Trim with White Baffle</p> <p>ERT413 Metal Baffle, 40W A19, 50W R20 (ERT413WHT only), 45W R20, 50W PAR 20, OD: 5-1/16" [129mm] ERT413=High Gloss Appliance White Trim Ring with Black Baffle ERT413WHT=High Gloss Appliance White Trim Ring with White Baffle</p> <p>Decorative</p> <p>945 Metropolitan Ice Lite, 30W R20, OD: 5-1/16" [129mm] 945=Frosted Glass 945BLUE=Frosted Blue Glass</p> <p>946 Metropolitan Deco, 30W R20, OD: 5-5/8" [143mm] 946BC=Black Chrome Accent with Translucent Rings 946PB=Polished Brass Accent with Translucent Rings</p> <p>Reflectors</p> <p>999 Reflector, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 999H=White Trim with Haze Reflector 999MB=White Trim with Specular Black Reflector 999P=White Trim with Specular Clear Reflector 999RG=White Trim with Residential Gold Reflector 999SN=Satin Nickel Trim with Satin Nickel Reflector 999TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector 999W=White Trim with White Reflector</p> <p>Showerlight</p> <p>952 Frosted Dome Lens Showerlight, 30W R20, 35W PAR20, With H1999 Socket Extender 50W PAR20, OD: 5-1/16" [129mm] 952PS=White Trim Ring, Frost Dome Glass Lens Showerlight</p> <p>955 Showerlight, 30W R20, 35W PAR20, OD: 5-1/16" [129mm] 955PS=White Trim Ring, Prismatic Glass Lens Showerlight</p>	<p>Socket Extender</p> <p>H1999=Socket Extender, for Use with Select Trims and Housings, Extends Lamp 1" (25mm)</p>

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.


4-INCH INCANDESCENT REMODEL NON - IC

FEATURES

- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pryouts and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, IP Rated, AIR-TITE™ Certified ASTM E283

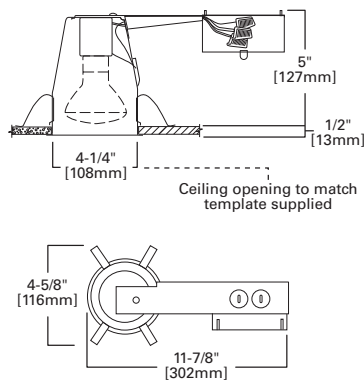

H99RTAT

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^A

SAMPLE NUMBER: H99RTAT - 993W

Housing	Trims
H99RTAT=4" Aperture, Shallow Ceiling, Remodel, Non-IC AIR-TITE™, 120V Line Voltage	<p>Adjustables</p> <p>998 Adjustable Eyeball - 30° Tilt, 40W R16, 60W PAR16, OD: 5-1/16" [129mm]</p> <p>998P=White Trim with White Eyeball</p> <p>998PB=Polished Brass Trim with Polished Brass Eyeball</p> <p>998SN=Satin Nickel Trim with Satin Nickel Eyeball</p> <p>998TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p>
	<p>Baffles</p> <p>953 Metal Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>953P=White Trim with Black Baffle</p> <p>953SN=Satin Nickel Trim with Satin Nickel Baffle</p> <p>953TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle</p> <p>953W=White Trim with White Baffle</p>
	<p>990 Pinhole Trim, 40W A19, 40W R16, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>990P=White Pinhole Trim</p> <p>990SN=Satin Nickel Pinhole Trim</p> <p>990TBZ=Tuscan Bronze Pinhole Trim</p>
	<p>993 Coilex® Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>993P=White Trim with Black Baffle</p> <p>993PB=Polished Brass Trim with Black Baffle</p> <p>993SN=Satin Nickel Trim with Black Baffle</p> <p>993TBZ=Tuscan Bronze Trim with Black Baffle</p> <p>993W=White Trim with White Baffle</p>
	<p>ERT413 Metal Baffle, 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20, OD: 5-1/16" [129mm]</p> <p>ERT413=High Gloss Appliance White Trim Ring with Black Baffle</p> <p>ERT413WHT=High Gloss Appliance White Trim Ring with White Baffle</p>
	<p>Decorative</p> <p>945 Metropolitan Ice Lite, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>945=Frosted Glass</p> <p>945BLUE=Frosted Blue Glass</p>
	<p>946 Metropolitan Deco, 50W PAR20, 50W R20, OD: 5-5/8 [143mm]</p> <p>946BC=Black Chrome Accent with Translucent Rings</p> <p>946PB=Polished Brass Accent with Translucent Rings</p>
	<p>Reflectors</p> <p>999 Reflector, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>999H=White Trim with Haze Reflector</p> <p>999MB=White Trim with Specular Black Reflector</p> <p>999P=White Trim with Specular Clear Reflector</p> <p>999RG=White Trim with Residential Gold Reflector</p> <p>999SN=Satin Nickel Trim with Satin Nickel Reflector</p> <p>999TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector</p> <p>999W=White Trim with White Reflector</p>
	<p>Showerlight</p> <p>951 Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>951PS=White Trim with Full Reflector and Prismatic Glass Lens</p> <p>951SNS=Satin Nickel Trim with Full Reflector and Prismatic Glass Lens</p> <p>951TBZS=Tuscan Bronze Trim with Full Reflector and Prismatic Glass Lens</p>
	<p>952 Frosted Dome Lens Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>952PS=White Trim Ring, Frost Dome Glass Lens Showerlight</p>
<p>955 Showerlight, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>955PS=White Trim Ring, Prismatic Glass Lens Showerlight</p>	
<p>Wall Wash</p> <p>992 Wall Wash with Baffle, 40W R16, 40W A19, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>992P=White Trim and Eyelid, Black Baffle</p> <p>992SN=Satin Nickel Trim and Eyelid, Satin Nickel Baffle</p> <p>992TBZ=Tuscan Bronze Trim and Eyelid, Tuscan Bronze Baffle</p> <p>992W=White Trim and Eyelid, White Baffle</p>	

NOTES: ^A UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

4-INCH INCANDESCENT NEW CONSTRUCTION NON - IC




H99TAT

FEATURES

- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Slide-N-Side™ wire traps
- Quick Connect™ wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated, AIR-TITE™ Certified ASTM E283

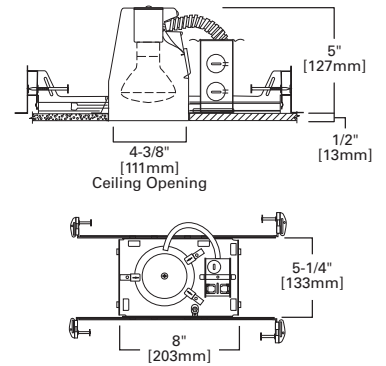

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^A

SAMPLE NUMBER: H99TAT - 993W

Housing	Trims
H99TAT =4" Aperture, Shallow Ceiling, Non-IC AIR-TITE™, 120V Line Voltage	Adjustables 996 Adjustable Eyeball - 15° Tilt, 50W PAR20, OD: 5-1/16" [129mm] 996P=White Trim with White Eyeball 996SN=Satin Nickel Trim with Satin Nickel Eyeball 996TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball 998 Adjustable Eyeball - 30° Tilt, 40W R16, 60W PAR16, OD: 5-1/16" [129mm] 998P=White Trim with White Eyeball 998PB=Polished Brass Trim with Polished Brass Eyeball 998SN=Satin Nickel Trim with Satin Nickel Eyeball 998TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball
	Baffles 953 Metal Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 953P=White Trim with Black Baffle 953SN=Satin Nickel Trim with Satin Nickel Baffle 953TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle 953W=White Trim with White Baffle 990 Pinhole Trim, 40W A19, 40W R16, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 990P=White Pinhole Trim 990SN=Satin Nickel Pinhole Trim 990TBZ=Tuscan Bronze Pinhole Trim
	993 Coilex® Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 993P=White Trim with Black Baffle 993PB=Polished Brass Trim with Black Baffle 993SN=Satin Nickel Trim with Black Baffle 993TBZ=Tuscan Bronze Trim with Black Baffle 993W=White Trim with White Baffle
	ERT413 Metal Baffle, 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20, OD: 5-1/16" [129mm] ERT413=High Gloss Appliance White Trim Ring with Black Baffle ERT413WHT=High Gloss Appliance White Trim Ring with White Baffle
	Decorative 945 Metropolitan Ice Lite, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 945=Frosted Glass 945BLUE=Frosted Blue Glass 946 Metropolitan Deco, 50W PAR20, 50W R20, OD: 5-5/8" [143mm] 946BC=Black Chrome Accent with Translucent Rings 946PB=Polished Brass Accent with Translucent Rings
	Reflectors 999 Reflector, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 999H=White Trim with Haze Reflector 999MB=White Trim with Specular Black Reflector 999P=White Trim with Specular Clear Reflector 999RG=White Trim with Residential Gold Reflector 999SN=Satin Nickel Trim with Satin Nickel Reflector 999TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector 999W=White Trim with White Reflector
	Showerlight 951 Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 951PS=White Trim with Full Reflector and Prismatic Glass Lens 951SNS=Satin Nickel Trim with Full Reflector and Prismatic Glass Lens 951TBZS=Tuscan Bronze Trim with Full Reflector and Prismatic Glass Lens 952 Frosted Dome Lens Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 952PS=White Trim Ring, Frost Dome Glass Lens Showerlight 955 Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 955PS=White Trim Ring, Prismatic Glass Lens Showerlight
	Wall Wash 992 Wall Wash with Baffle, 40W R16, 40W A19, 50W R20, OD: 5-1/16" [129mm] 992P=White Trim and Eyelid, Black Baffle 992SN=Satin Nickel Trim and Eyelid, Satin Nickel Baffle 992TBZ=Tuscan Bronze Trim and Eyelid, Tuscan Bronze Baffle 992W=White Trim and Eyelid, White Baffle

NOTES: ^A UL/cUL Listed for Wet Location with select trims.

 
Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

945 4" Metropolitan Ice Lite



945 Frosted Glass

945BLUE Frosted Blue Glass




HOUSING / LAMP:

H99ICAT: 30W R20
H99RTAT: 50W PAR20, 50W R20
H99TAT: 50W PAR20, 50W R20


DIMENSIONS: Aperture: 2-1/8" [54mm],
Outside Dimensions: 5-5/16" [135mm]

946 4" Metropolitan Deco

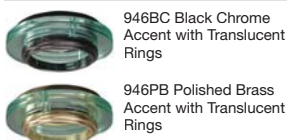

946BC Black Chrome Accent with Translucent Rings

 946PB Polished Brass Accent with Translucent Rings



HOUSING / LAMP:

H99ICAT: 30W R20
H99RTAT: 50W PAR20, 50W R20
H99TAT: 50W PAR20, 50W R20

DIMENSIONS: Height: 1-5/8" [41mm],
Outside Diameter: 5-5/8" [143mm]


951 4" Showerlight



951PS White Trim with Full Reflector and Glass Prismatic Lens

951SNS Satin Nickel Trim with Full Reflector and Glass Prismatic Lens

951TBZ Tuscan Bronze Trim with Full Reflector and Glass Prismatic Lens

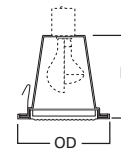


HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20 with H1999 Socket Extender
H99RTAT: 40W A19, 50W PAR20, 50W R20
H99TAT: 40W A19, 50W PAR20, 50W R20


DIMENSIONS: Height: 4-1/2" [114mm],
Outside Diameter: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

 952 4" Frosted Dome Lens Showerlight



 952PS White Trim Ring, Frost Dome Glass Lens Showerlight



HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20 with H1999 Socket Extender
H99RTAT: 40W A19, 50W PAR20, 50W R20
H99TAT: 40W A19, 50W PAR20, 50W R20

DIMENSIONS: Height: 2-5/8" [66mm],
Outside Diameter: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

953 4" Metal Baffle

 


953W White Trim with White Baffle

953P White Trim with Black Baffle

953SN Satin Nickel Trim with Satin Nickel Baffle

953TBZ Tuscan Bronze Trim with Tuscan Bronze Baffle




HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20 with H1999 Socket Extender
H99RTAT: 40W R16, 50W R20, 50W PAR20
H99TAT: 40W R16, 50W R20, 50W PAR20


DIMENSIONS: Height: 2-5/8" [67mm], OD: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

 955 4" Showerlight



955PS White Trim Ring, Prismatic Glass Lens Showerlight

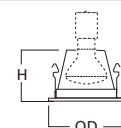

HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99RTAT: 40W A19, 50W PAR20, 50W R20
H99TAT: 40W A19, 50W PAR20, 50W R20

DIMENSIONS: Height: 2-5/8" [67mm], OD: 5-1/16" [129mm]

 
990 4" Pinhole Trim



990P White Pinhole Trim

990SN Satin Nickel Pinhole Trim

990TBZ Tuscan Bronze Pinhole Trim



HOUSING / LAMP:

H99RTAT: 40W A19, 40W R16, 50W PAR20, 50W R20
H99TAT: 40W A19, 40W R16, 50W PAR20, 50W R20

 
DIMENSIONS: Height: 1-3/4" [44mm], OD: 5-1/16" (129mm)

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

992 4" Wall Wash with Baffle



- 992W White Trim and Eyelid, White Baffle
- 992P White Trim and Eyelid, Black Baffle
- 992SN Satin Nickel Trim and Eyelid, Satin Nickel Baffle
- 992TBZ Tuscan Bronze Trim and Eyelid, Tuscan Bronze Baffle




HOUSING / LAMP:
H99RTAT: 40W R16, 40W A19, 50W R20, 50W PAR20
H99TAT: 40W R16, 40W A19, 50W R20

DIMENSIONS: Height: 1-1/4" [32mm], OD: 5-1/16" [129mm]

993 4" Coilex® Baffle



- 993P White Trim with Black Baffle
- 993W White Trim with White Baffle
- 993SN Satin Nickel Trim with Black Baffle
- 993TBZ Tuscan Bronze Trim with Black Baffle
- 993PB Polished Brass Trim with Black Baffle

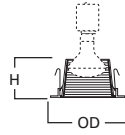

HOUSING / LAMP:
H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20, 50W R20 with H1999 Socket Extender
H99TAT: 40W R16, 50W R20, 50W PAR20
H99RTAT: 40W R16, 50W R20, 50W PAR20

 
DIMENSIONS: Height: 2-1/2" [63mm], OD: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

996 4" Adjustable Eyeball 15° Tilt



- 996P White Trim with White Eyeball
- 996SN Satin Nickel Trim with Satin Nickel Eyeball
- 996TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball




HOUSING / LAMP:
H99ICAT: 50W PAR20
H99TAT: 50W PAR20

DIMENSIONS: Aperture: 3-11/16 [94mm], Height: 3-7/16" [88mm], OD: 5-1/16" [129mm]

998 4" Adjustable Eyeball 30° Tilt



 - 998P White Trim with White Eyeball
- 998SN Satin Nickel Trim with Satin Nickel Eyeball
- 998PB Polished Brass Trim with Polished Brass Eyeball
- 998TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball




HOUSING / LAMP:
H99ICAT: 40W R16
H99RTAT: 40W R16, 60W PAR16
H99TAT: 40W R16, 60W PAR16

DIMENSIONS: Aperture: 2-3/16" [56mm], Height: 3-1/4" [83mm], OD: 5-1/16" [129mm]

999 4" Reflector



 - 999W White Trim with White Reflector
- 999MB White Trim with Specular Black Reflector
- 999P White Trim with Specular Clear Reflector
- 999H White Trim with Haze Reflector
- 999RG White Trim with Residential Gold Reflector
- 999SN Satin Nickel Trim with Satin Nickel Reflector
- 999TBZ Tuscan Bronze Trim with Tuscan Bronze Reflector




HOUSING / LAMP:
H99ICAT: 40W R16, 50W R20, 50W PAR20
H99RTAT: 40W R16, 50W R20, 50W PAR20
H99TAT: 40W R16, 50W R20, 50W PAR20

DIMENSIONS: Height: 2-5/8" [67mm], OD: 5-1/16" [129mm]

ERT413 Metal Baffle



- ERT413WHT High Gloss Appliance White Trim Ring with White Baffle
- ERT413 High Gloss Appliance White Trim Ring with Black Baffle

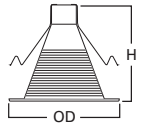

HOUSING / LAMP:
H99ICAT: 40W A19, 50W R20 (ERT413WHT only), 45W R20, 50W PAR 20
H99RTAT: 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20
H99TAT: 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20

DIMENSIONS: Height: 4-1/2" [114mm]; OD: 5-1/6" [129mm]



H1999

Description

SOCKET EXTENDER

For use with selected trims and housings. Extends lamp 1" (25mm).

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

4-INCH INCANDESCENT NEW CONSTRUCTION ICAT




H99ICAT

FEATURES

- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Slide-N-Side™ wire traps
- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

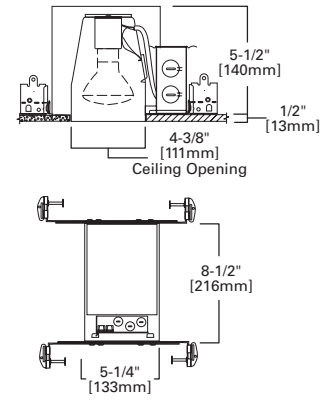

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^A

SAMPLE NUMBER: H99ICAT - 993W

Housing	Trims	Accessories
<p>H99ICAT=4" Aperture, Shallow Ceiling, IC AIR-TITE™, 120V Line Voltage</p>	<p>Adjustables</p> <p>996 Adjustable Eyeball - 15° Tilt, 50W PAR20, OD: 5-1/16" [129mm] 996P=White Trim with White Eyeball 996SN=Satin Nickel Trim with Satin Nickel Eyeball 996TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p> <p>998 Adjustable Eyeball - 30° Tilt, 40W R16, OD: 5-1/16" [129mm] 998P=White Trim with White Eyeball 998PB=Polished Brass Trim with Polished Brass Eyeball 998SN=Satin Nickel Trim with Satin Nickel Eyeball 998TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p> <p>Baffles</p> <p>953 Metal Baffle, 30W R20, 35W PAR20, With H1999 Socket Extender 50W PAR20, OD: 5-1/16" [129mm] 953P=White Trim with Black Baffle 953SN=Satin Nickel Trim with Satin Nickel Baffle 953TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle 953W=White Trim with White Baffle</p> <p>993 Coilex® Baffle, 30W R20, 35W PAR20, With H1999 Socket Extender 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 993P=White Trim with Black Baffle 993PB=Polished Brass Trim with Black Baffle 993SN=Satin Nickel Trim with Black Baffle 993TBZ=Tuscan Bronze Trim with Black Baffle 993W=White Trim with White Baffle</p> <p>ERT413 Metal Baffle, 40W A19, 50W R20 (ERT413WHT only), 45W R20, 50W PAR 20, OD: 5-1/16" [129mm] ERT413=High Gloss Appliance White Trim Ring with Black Baffle ERT413WHT=High Gloss Appliance White Trim Ring with White Baffle</p> <p>Decorative</p> <p>945 Metropolitan Ice Lite, 30W R20, OD: 5-1/16" [129mm] 945=Frosted Glass 945BLUE=Frosted Blue Glass</p> <p>946 Metropolitan Deco, 30W R20, OD: 5-5/8" [143mm] 946BC=Black Chrome Accent with Translucent Rings 946PB=Polished Brass Accent with Translucent Rings</p> <p>Reflectors</p> <p>999 Reflector, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 999H=White Trim with Haze Reflector 999MB=White Trim with Specular Black Reflector 999P=White Trim with Specular Clear Reflector 999RG=White Trim with Residential Gold Reflector 999SN=Satin Nickel Trim with Satin Nickel Reflector 999TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector 999W=White Trim with White Reflector</p> <p>Showerlight</p> <p>952 Frosted Dome Lens Showerlight, 30W R20, 35W PAR20, With H1999 Socket Extender 50W PAR20, OD: 5-1/16" [129mm] 952PS=White Trim Ring, Frost Dome Glass Lens Showerlight</p> <p>955 Showerlight, 30W R20, 35W PAR20, OD: 5-1/16" [129mm] 955PS=White Trim Ring, Prismatic Glass Lens Showerlight</p>	<p>Socket Extender</p> <p>H1999=Socket Extender, for Use with Select Trims and Housings, Extends Lamp 1" (25mm)</p>

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.


4-INCH INCANDESCENT REMODEL NON - IC

FEATURES

- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pryouts and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, IP Rated, AIR-TITE™ Certified ASTM E283

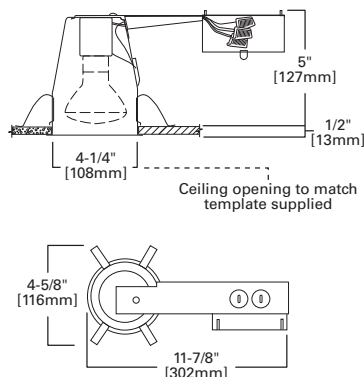

H99RTAT

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^A

SAMPLE NUMBER: H99RTAT - 993W

Housing	Trims
H99RTAT=4" Aperture, Shallow Ceiling, Remodel, Non-IC AIR-TITE™, 120V Line Voltage	<p>Adjustables</p> <p>998 Adjustable Eyeball - 30° Tilt, 40W R16, 60W PAR16, OD: 5-1/16" [129mm]</p> <p>998P=White Trim with White Eyeball</p> <p>998PB=Polished Brass Trim with Polished Brass Eyeball</p> <p>998SN=Satin Nickel Trim with Satin Nickel Eyeball</p> <p>998TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p> <p>Baffles</p> <p>953 Metal Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>953P=White Trim with Black Baffle</p> <p>953SN=Satin Nickel Trim with Satin Nickel Baffle</p> <p>953TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle</p> <p>953W=White Trim with White Baffle</p> <p>990 Pinhole Trim, 40W A19, 40W R16, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>990P=White Pinhole Trim</p> <p>990SN=Satin Nickel Pinhole Trim</p> <p>990TBZ=Tuscan Bronze Pinhole Trim</p> <p>993 Coilex® Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>993P=White Trim with Black Baffle</p> <p>993PB=Polished Brass Trim with Black Baffle</p> <p>993SN=Satin Nickel Trim with Black Baffle</p> <p>993TBZ=Tuscan Bronze Trim with Black Baffle</p> <p>993W=White Trim with White Baffle</p> <p>ERT413 Metal Baffle, 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20, OD: 5-1/16" [129mm]</p> <p>ERT413=High Gloss Appliance White Trim Ring with Black Baffle</p> <p>ERT413WHT=High Gloss Appliance White Trim Ring with White Baffle</p> <p>Decorative</p> <p>945 Metropolitan Ice Lite, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>945=Frosted Glass</p> <p>945BLUE=Frosted Blue Glass</p> <p>946 Metropolitan Deco, 50W PAR20, 50W R20, OD: 5-5/8 [143mm]</p> <p>946BC=Black Chrome Accent with Translucent Rings</p> <p>946PB=Polished Brass Accent with Translucent Rings</p> <p>Reflectors</p> <p>999 Reflector, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>999H=White Trim with Haze Reflector</p> <p>999MB=White Trim with Specular Black Reflector</p> <p>999P=White Trim with Specular Clear Reflector</p> <p>999RG=White Trim with Residential Gold Reflector</p> <p>999SN=Satin Nickel Trim with Satin Nickel Reflector</p> <p>999TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector</p> <p>999W=White Trim with White Reflector</p> <p>Showerlight</p> <p>951 Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>951PS=White Trim with Full Reflector and Prismatic Glass Lens</p> <p>951SNS=Satin Nickel Trim with Full Reflector and Prismatic Glass Lens</p> <p>951TBZS=Tuscan Bronze Trim with Full Reflector and Prismatic Glass Lens</p> <p>952 Frosted Dome Lens Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm]</p> <p>952PS=White Trim Ring, Frost Dome Glass Lens Showerlight</p> <p>955 Showerlight, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>955PS=White Trim Ring, Prismatic Glass Lens Showerlight</p> <p>Wall Wash</p> <p>992 Wall Wash with Baffle, 40W R16, 40W A19, 50W R20, 50W PAR20, OD: 5-1/16" [129mm]</p> <p>992P=White Trim and Eyelid, Black Baffle</p> <p>992SN=Satin Nickel Trim and Eyelid, Satin Nickel Baffle</p> <p>992TBZ=Tuscan Bronze Trim and Eyelid, Tuscan Bronze Baffle</p> <p>992W=White Trim and Eyelid, White Baffle</p>

NOTES: ^A UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

4-INCH INCANDESCENT NEW CONSTRUCTION NON - IC




H99TAT

FEATURES

- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Slide-N-Side™ wire traps
- Quick Connect™ wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated, AIR-TITE™ Certified ASTM E283

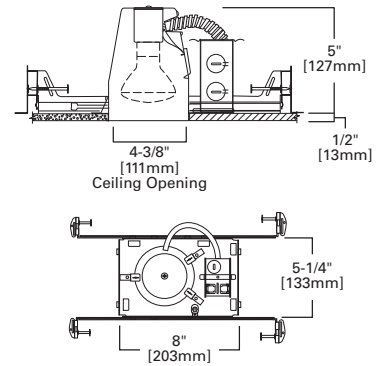

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^A

SAMPLE NUMBER: H99TAT - 993W

Housing	Trims	
H99TAT =4" Aperture, Shallow Ceiling, Non-IC AIR-TITE™, 120V Line Voltage	Adjustables 996 Adjustable Eyeball - 15° Tilt, 50W PAR20, OD: 5-1/16" [129mm] 996P=White Trim with White Eyeball 996SN=Satin Nickel Trim with Satin Nickel Eyeball 996TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball 998 Adjustable Eyeball - 30° Tilt, 40W R16, 60W PAR16, OD: 5-1/16" [129mm] 998P=White Trim with White Eyeball 998PB=Polished Brass Trim with Polished Brass Eyeball 998SN=Satin Nickel Trim with Satin Nickel Eyeball 998TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball	Showerlight 951 Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 951PS=White Trim with Full Reflector and Prismatic Glass Lens 951SNS=Satin Nickel Trim with Full Reflector and Prismatic Glass Lens 951TBZS=Tuscan Bronze Trim with Full Reflector and Prismatic Glass Lens 952 Frosted Dome Lens Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 952PS=White Trim Ring, Frost Dome Glass Lens Showerlight 955 Showerlight, 40W A19, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 955PS=White Trim Ring, Prismatic Glass Lens Showerlight
	Baffles 953 Metal Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 953P=White Trim with Black Baffle 953SN=Satin Nickel Trim with Satin Nickel Baffle 953TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle 953W=White Trim with White Baffle	Wall Wash 992 Wall Wash with Baffle, 40W R16, 40W A19, 50W R20, OD: 5-1/16" [129mm] 992P=White Trim and Eyelid, Black Baffle 992SN=Satin Nickel Trim and Eyelid, Satin Nickel Baffle 992TBZ=Tuscan Bronze Trim and Eyelid, Tuscan Bronze Baffle 992W=White Trim and Eyelid, White Baffle
	990 Pinhole Trim, 40W A19, 40W R16, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 990P=White Pinhole Trim 990SN=Satin Nickel Pinhole Trim 990TBZ=Tuscan Bronze Pinhole Trim	
	993 Coilex® Baffle, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 993P=White Trim with Black Baffle 993PB=Polished Brass Trim with Black Baffle 993SN=Satin Nickel Trim with Black Baffle 993TBZ=Tuscan Bronze Trim with Black Baffle 993W=White Trim with White Baffle	
	ERT413 Metal Baffle, 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20, OD: 5-1/16" [129mm] ERT413=High Gloss Appliance White Trim Ring with Black Baffle ERT413WHT=High Gloss Appliance White Trim Ring with White Baffle	
	Decorative 945 Metropolitan Ice Lite, 50W PAR20, 50W R20, OD: 5-1/16" [129mm] 945=Frosted Glass 945BLUE=Frosted Blue Glass	
	946 Metropolitan Deco, 50W PAR20, 50W R20, OD: 5-5/8" [143mm] 946BC=Black Chrome Accent with Translucent Rings 946PB=Polished Brass Accent with Translucent Rings	
	Reflectors 999 Reflector, 40W R16, 50W R20, 50W PAR20, OD: 5-1/16" [129mm] 999H=White Trim with Haze Reflector 999MB=White Trim with Specular Black Reflector 999P=White Trim with Specular Clear Reflector 999RG=White Trim with Residential Gold Reflector 999SN=Satin Nickel Trim with Satin Nickel Reflector 999TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector 999W=White Trim with White Reflector	

NOTES: ^A UL/cUL Listed for Wet Location with select trims.

 
Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

945 4" Metropolitan Ice Lite



945 Frosted Glass

945BLUE Frosted Blue Glass



HOUSING / LAMP:

H99ICAT: 30W R20
H99RTAT: 50W PAR20, 50W R20
H99TAT: 50W PAR20, 50W R20

 
DIMENSIONS: Aperture: 2-1/8" [54mm],
Outside Dimensions: 5-5/16" [135mm]

946 4" Metropolitan Deco



946BC Black Chrome Accent with Translucent Rings

946PB Polished Brass Accent with Translucent Rings



HOUSING / LAMP:

H99ICAT: 30W R20
H99RTAT: 50W PAR20, 50W R20
H99TAT: 50W PAR20, 50W R20

DIMENSIONS: Height: 1-5/8" [41mm],
Outside Diameter: 5-5/8" [143mm]

 
951 4" Showerlight



951PS White Trim with Full Reflector and Glass Prismatic Lens

951SNS Satin Nickel Trim with Full Reflector and Glass Prismatic Lens

951TBZ Tuscan Bronze Trim with Full Reflector and Glass Prismatic Lens



HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20 with H1999 Socket Extender
H99RTAT: 40W A19, 50W PAR20, 50W R20
H99TAT: 40W A19, 50W PAR20, 50W R20

 
DIMENSIONS: Height: 4-1/2" [114mm],
Outside Diameter: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

952 4" Frosted Dome Lens Showerlight



952PS White Trim Ring, Frost Dome Glass Lens Showerlight



HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20 with H1999 Socket Extender
H99RTAT: 40W A19, 50W PAR20, 50W R20
H99TAT: 40W A19, 50W PAR20, 50W R20

DIMENSIONS: Height: 2-5/8" [66mm],
Outside Diameter: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

953 4" Metal Baffle




953W White Trim with White Baffle

953P White Trim with Black Baffle

953SN Satin Nickel Trim with Satin Nickel Baffle

953TBZ Tuscan Bronze Trim with Tuscan Bronze Baffle

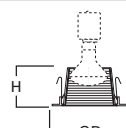

HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20 with H1999 Socket Extender
H99RTAT: 40W R16, 50W R20, 50W PAR20
H99TAT: 40W R16, 50W R20, 50W PAR20

 
DIMENSIONS: Height: 2-5/8" [67mm], OD: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

955 4" Showerlight



955PS White Trim Ring, Prismatic Glass Lens Showerlight



HOUSING / LAMP:

H99ICAT: 30W R20, 35W PAR20
H99RTAT: 40W A19, 50W PAR20, 50W R20
H99TAT: 40W A19, 50W PAR20, 50W R20

DIMENSIONS: Height: 2-5/8" [67mm], OD: 5-1/16" [129mm]

 
990 4" Pinhole Trim



990P White Pinhole Trim

990SN Satin Nickel Pinhole Trim

990TBZ Tuscan Bronze Pinhole Trim



HOUSING / LAMP:

H99RTAT: 40W A19, 40W R16, 50W PAR20, 50W R20
H99TAT: 40W A19, 40W R16, 50W PAR20, 50W R20

 
DIMENSIONS: Height: 1-3/4" [44mm], OD: 5-1/16" [129mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

992 4" Wall Wash with Baffle



- 992W White Trim and Eyelid, White Baffle
- 992P White Trim and Eyelid, Black Baffle
- 992SN Satin Nickel Trim and Eyelid, Satin Nickel Baffle
- 992TBZ Tuscan Bronze Trim and Eyelid, Tuscan Bronze Baffle




HOUSING / LAMP:
H99RTAT: 40W R16, 40W A19, 50W R20, 50W PAR20
H99TAT: 40W R16, 40W A19, 50W R20

DIMENSIONS: Height: 1-1/4" [32mm], OD: 5-1/16" [129mm]

993 4" Coilex® Baffle



- 993P White Trim with Black Baffle
- 993W White Trim with White Baffle
- 993SN Satin Nickel Trim with Black Baffle
- 993TBZ Tuscan Bronze Trim with Black Baffle
- 993PB Polished Brass Trim with Black Baffle

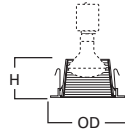

HOUSING / LAMP:
H99ICAT: 30W R20, 35W PAR20
H99ICAT: 50W PAR20, 50W R20 with H1999 Socket Extender
H99TAT: 40W R16, 50W R20, 50W PAR20
H99RTAT: 40W R16, 50W R20, 50W PAR20

 
DIMENSIONS: Height: 2-1/2" [63mm], OD: 5-1/16" [129mm]

ACCESSORIES: H1999 Socket Extender

996 4" Adjustable Eyeball 15° Tilt



- 996P White Trim with White Eyeball
- 996SN Satin Nickel Trim with Satin Nickel Eyeball
- 996TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball




HOUSING / LAMP:
H99ICAT: 50W PAR20
H99TAT: 50W PAR20

DIMENSIONS: Aperture: 3-11/16 [94mm], Height: 3-7/16" [88mm], OD: 5-1/16" [129mm]

998 4" Adjustable Eyeball 30° Tilt



 - 998P White Trim with White Eyeball
- 998SN Satin Nickel Trim with Satin Nickel Eyeball
- 998PB Polished Brass Trim with Polished Brass Eyeball
- 998TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball




HOUSING / LAMP:
H99ICAT: 40W R16
H99RTAT: 40W R16, 60W PAR16
H99TAT: 40W R16, 60W PAR16

DIMENSIONS: Aperture: 2-3/16" [56mm], Height: 3-1/4" [83mm], OD: 5-1/16" [129mm]

999 4" Reflector



 - 999W White Trim with White Reflector
- 999MB White Trim with Specular Black Reflector
- 999P White Trim with Specular Clear Reflector
- 999H White Trim with Haze Reflector
- 999RG White Trim with Residential Gold Reflector
- 999SN Satin Nickel Trim with Satin Nickel Reflector
- 999TBZ Tuscan Bronze Trim with Tuscan Bronze Reflector




HOUSING / LAMP:
H99ICAT: 40W R16, 50W R20, 50W PAR20
H99RTAT: 40W R16, 50W R20, 50W PAR20
H99TAT: 40W R16, 50W R20, 50W PAR20

DIMENSIONS: Height: 2-5/8" [67mm], OD: 5-1/16" [129mm]

ERT413 Metal Baffle



- ERT413WHT High Gloss Appliance White Trim Ring with White Baffle
- ERT413 High Gloss Appliance White Trim Ring with Black Baffle

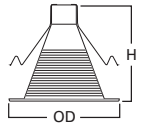

HOUSING / LAMP:
H99ICAT: 40W A19, 50W R20 (ERT413WHT only), 45W R20, 50W PAR 20
H99RTAT: 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20
H99TAT: 40W A19, 50W R20 (ERT413WHT only), 50W PAR 20

DIMENSIONS: Height: 4-1/2" [114mm]; OD: 5-1/6" [129mm]



H1999

Description

SOCKET EXTENDER

For use with selected trims and housings. Extends lamp 1" (25mm).