



## Performance Overview:

Wattage: 45 Watts  
 Lumen Output: Up to 5,300 Lumens  
 Efficacy (lm/W): Up to 118 Lumens  
 Kelvin: 4000K, 5000K  
 CRI: >80

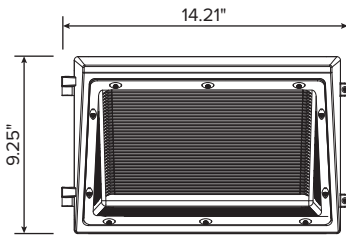

FRONT

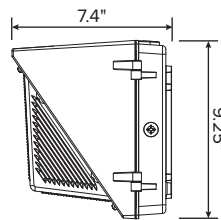

SIDE



## Ordering Guide:

| ESL | - | WP            | - | 45W   | - | 2                  | - |                                      | -                                 | Options & Accessories                                           |
|-----|---|---------------|---|-------|---|--------------------|---|--------------------------------------|-----------------------------------|-----------------------------------------------------------------|
| ESL |   | TYPE          |   | WATTS |   | GENERATION         |   | KELVIN                               |                                   | ESL-WP-PC (Photocell for 30W-135W Wall Packs)                   |
|     |   | WP (WallPack) |   | 45W   |   | 2 (2nd Generation) |   | 40 (4000 Kelvin)<br>50 (5000 Kelvin) |                                   | ESL-4OCC-LDD (Occupancy Sensor, 0-10v Dimming, 8'-20' Mounting) |
|     |   |               |   |       |   |                    |   |                                      |                                   | ESL-REM-100 (Remote control to field program 4OCC Sensor)       |
|     |   |               |   |       |   |                    |   |                                      |                                   | ESL-EMG-2DC-9W (External Emergency Backup)                      |
|     |   |               |   |       |   |                    |   |                                      | EMERGENCY                         |                                                                 |
|     |   |               |   |       |   |                    |   |                                      | Blank (No EMG)<br>EMG (See Below) |                                                                 |

| ITEM#          | WATTS | LUMEN OUTPUT | EFFICACY (lm/W) | KELVIN | DLC QPL CODE |
|----------------|-------|--------------|-----------------|--------|--------------|
| ESL-WP-45W-240 | 45W   | 5,223        | 117             | 4000K  | PSWJ7MH8     |
| ESL-WP-45W-250 | 45W   | 5,300        | 118             | 5000K  | PJYZVQM      |



## Product Specifications:

### Optical:

- Precision Engineered Optical Lens
- Consistent Uniformity
- Impact Resistant
- UV Protection

### Construction:

- Die Cast Aluminum Housing
- High Performance Heat Sink
- Weathertight LED Driver Housing
- Continuous Gasket Seal
- LEDs Mounted to and Protected by Aluminum Housing with Easy Driver Access Hinged Door
- (3) 1/2" Threaded Conduit Holes

## Electrical:

Wattage: 45 Watts

Power Factor: @120V: 0.91 / @277V: 0.9

Input Voltage: 120-277 VAC

Input Current @ 120V: 0.375 Amps

Input Current @ 277V: 0.162 Amps

Total Harmonic Distortion (THD):

THD @ 120V: 15%

THD @ 277V: 15%

Operating Temperature: -40°F to 104°F (-40°C to 40°C)

Lifespan: 50K Hours

Weight: 8.04 Lbs

## Options & Accessories:



### ESL-4OCC-LDD

Sensor Type: Microwave

Sensitivity Adjustment: 20% / 50% / 75% / 100%

Dimming Control Output: 0-10V

Detection Radius/angle: Max. 26ft/360°

Detection Area (square footage): 2123ft²@20ft/360°

Mounting Height: 20ft Max

Remote Range: 50ft

Programming: Via Dip Switch

For more information please see the  
ESL-4OCC-LDD cut sheet



### ESL-EMG-2DC-9W

Output Power: 9 Watts

Rated Voltage: 100-277 VAC, 50-60Hz

Emergency Operation: ≥90 Minutes

Charging Time: 24 Hours

2-Wire Illumination Test Switch

High Temperature, Nickel-Cadmium Battery

RoHS Compliant

UL 924, CSA C.22.2 No. 141-15, CEC Title 20

For more information please see the  
ESL-4OCC-LDD cut sheet




### ESL-REM-100




### ESL-WP-PC

### Performance Overview:

Wattage: 45 Watts  
 Lumen Output: Up to 5,300 Lumens  
 Efficacy (lm/W): Up to 118 Lumens  
 Kelvin: 4000K, 5000K  
 CRI: >80

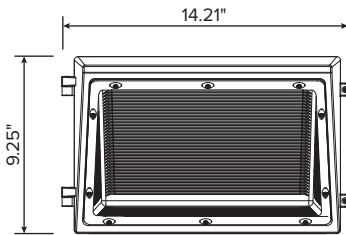

FRONT

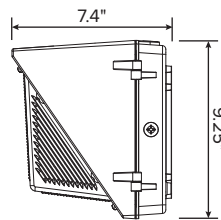

SIDE



### Ordering Guide:

| ESL                                                                                                                                                                                                                         | WP            | 45W   | 2                  |                                      | Options & Accessories             |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------|-------|--------------------|--------------------------------------|-----------------------------------|
| ESL                                                                                                                                                                                                                         | TYPE          | WATTS | GENERATION         | KELVIN                               | EMERGENCY                         |
|                                                                                                                                                                                                                             | WP (WallPack) | 45W   | 2 (2nd Generation) | 40 (4000 Kelvin)<br>50 (5000 Kelvin) | Blank (No EMG)<br>EMG (See Below) |
| ESL-WP-PC (Photocell for 30W-135W Wall Packs)<br>ESL-4OCC-LDD (Occupancy Sensor, 0-10v Dimming, 8'-20' Mounting)<br>ESL-REM-100 (Remote control to field program 4OCC Sensor)<br>ESL-EMG-2DC-9W (External Emergency Backup) |               |       |                    |                                      |                                   |

| ITEM#          | WATTS | LUMEN OUTPUT | EFFICACY (lm/W) | KELVIN | DLC QPL CODE |
|----------------|-------|--------------|-----------------|--------|--------------|
| ESL-WP-45W-240 | 45W   | 5,223        | 117             | 4000K  | PSWJ7MH8     |
| ESL-WP-45W-250 | 45W   | 5,300        | 118             | 5000K  | PJYZVQM      |



## Product Specifications:

### Optical:

- Precision Engineered Optical Lens
- Consistent Uniformity
- Impact Resistant
- UV Protection

### Construction:

- Die Cast Aluminum Housing
- High Performance Heat Sink
- Weathertight LED Driver Housing
- Continuous Gasket Seal
- LEDs Mounted to and Protected by Aluminum Housing with Easy Driver Access Hinged Door
- (3) 1/2" Threaded Conduit Holes

## Electrical:

Wattage: 45 Watts

Power Factor: @120V: 0.91 / @277V: 0.9

Input Voltage: 120-277 VAC

Input Current @ 120V: 0.375 Amps

Input Current @ 277V: 0.162 Amps

Total Harmonic Distortion (THD):

THD @ 120V: 15%

THD @ 277V: 15%

Operating Temperature: -40°F to 104°F (-40°C to 40°C)

Lifespan: 50K Hours

Weight: 8.04 Lbs

## Options & Accessories:



### ESL-4OCC-LDD

Sensor Type: Microwave

Sensitivity Adjustment: 20% / 50% / 75% / 100%

Dimming Control Output: 0-10V

Detection Radius/angle: Max. 26ft/360°

Detection Area (square footage): 2123ft²@20ft/360°

Mounting Height: 20ft Max

Remote Range: 50ft

Programming: Via Dip Switch

For more information please see the  
ESL-4OCC-LDD cut sheet



### ESL-EMG-2DC-9W

Output Power: 9 Watts

Rated Voltage: 100-277 VAC, 50-60Hz

Emergency Operation: ≥90 Minutes

Charging Time: 24 Hours

2-Wire Illumination Test Switch

High Temperature, Nickel-Cadmium Battery

RoHS Compliant

UL 924, CSA C.22.2 No. 141-15, CEC Title 20

For more information please see the  
ESL-4OCC-LDD cut sheet



### ESL-REM-100



### ESL-WP-PC