




GE  
Lighting

**68051 - F35/CW/C/U6/WM**  
F35/CW/C/U6/WM

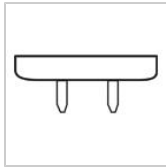

**GENERAL CHARACTERISTICS**

Lamp Type	Linear Fluorescent - U-Shaped
Bulb	T12
Base	Medium Bi-Pin (G13)
Rated Life	14000.0 hrs
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
LEED-EB MR Credit	1531 picograms Hg per mean lumen hour
Primary Application	Energy Saving

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	1650.0
Mean Lumens	1400.0
Nominal Initial Lumens per Watt	47
Color Temperature	4100.0 K
Color Rendering Index (CRI)	87.0

**ELECTRICAL CHARACTERISTICS**

Wattage	35.0
---------	------

**DIMENSIONS**

Maximum Overall Length (MOL)	22.5000 in(571.5 mm)
Nominal Length	22.500 in(571.5 mm)
Bulb Diameter (DIA)	1.500 in(38.1 mm)


**PRODUCT INFORMATION**

Product Code	68051
Description	F35/CW/C/U6/WM
Standard Package	Case
Standard Package GTIN	10043168680513
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168680516



GE  
Lighting

**68051 - F35/CW/C/U6/WM**  
F35/CW/C/U6/WM

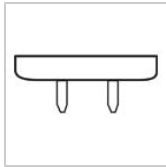

**GENERAL CHARACTERISTICS**

Lamp Type	Linear Fluorescent - U-Shaped
Bulb	T12
Base	Medium Bi-Pin (G13)
Rated Life	14000.0 hrs
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
LEED-EB MR Credit	1531 picograms Hg per mean lumen hour
Primary Application	Energy Saving

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	1650.0
Mean Lumens	1400.0
Nominal Initial Lumens per Watt	47
Color Temperature	4100.0 K
Color Rendering Index (CRI)	87.0

**ELECTRICAL CHARACTERISTICS**

Wattage	35.0
---------	------

**DIMENSIONS**

Maximum Overall Length (MOL)	22.5000 in(571.5 mm)
Nominal Length	22.500 in(571.5 mm)
Bulb Diameter (DIA)	1.500 in(38.1 mm)

**PRODUCT INFORMATION**

Product Code	68051
Description	F35/CW/C/U6/WM
Standard Package	Case
Standard Package GTIN	10043168680513
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168680516