

# ADJUSTABLE FLOOR BOX KITS



*with a Variety of Metal & Plastic Covers* **Arlington**



**EASY RECEPTACLE INSTALLATION IN FLOOR HEIGHTS UP TO 2"**

*UL LISTED • Adjusts to Floor Height up to 2"*

# ADJUSTABLE FLOOR BOX KITS

**INSTALL A RECEPTACLE IN THE FLOOR, THE EASY WAY!**


## LOW COST... EASY INSTALLATION

Arlington's UL LISTED, Adjustable **FLOOR BOXES** give installers a low cost, convenient way to install a receptacle in a new or existing floor.

We have a floor box kit to fit nearly any application or jobsite condition including our single gang *adjustable boxes*. They fit varying floor heights up to 2" in new work or retrofit.

Our adjustable box is available with non-metallic or metal covers that hide miscut flooring. Gaskets inside the cover prevent water intrusion – and threaded plugs or flip lids protect the box when it's not in use.



Non-metallic  
18.3 cu inch box

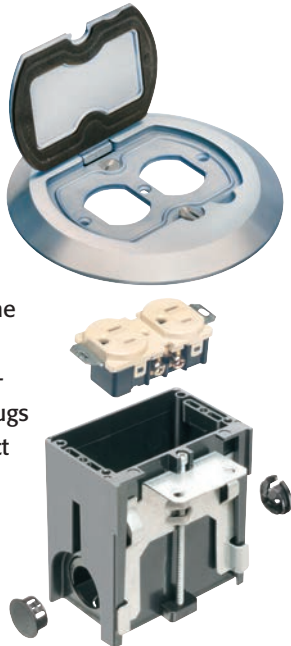

**Round or Rectangular  
Plastic, Brass or  
Nickel-plated Brass COVERS**  
*with a single flip lid,  
two flip lids or two threaded plugs*



**Arlington**

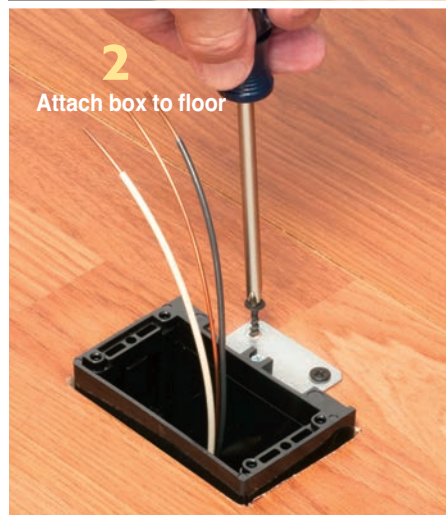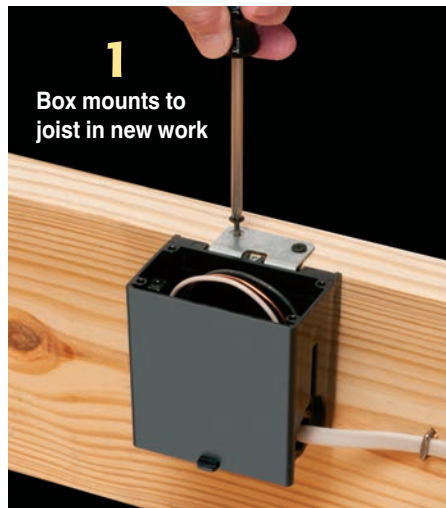

## COVERS WITH SINGLE FLIP LID




FLBAFR101MB

**SINGLE Gang**  
**COVER SHAPE**


FLBAFR101NL



FLBAFR101BR

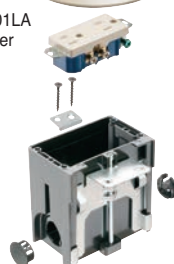FLBAFR101MB  
Brass coverFLBAFR101LA  
Plastic cover

| CATALOG NUMBER | UPC/DCI/NAED MFG. #018997 | DESCRIPTION                             | UNIT | STD |
|----------------|---------------------------|-----------------------------------------|------|-----|
|                |                           | ADJUSTABLE FLOOR BOX COVER COLOR/FINISH | PKG  | PKG |

**METAL COVER with SINGLE FLIP LID**

|             |       |                                                 |   |   |
|-------------|-------|-------------------------------------------------|---|---|
| FLBAFR101MB | 00749 | Non-metallic box, Brass single flip lid         | 1 | 4 |
| FLBAFR101NL | 00750 | Non-metallic box, Nickel-plated single flip lid | 1 | 4 |

**NON-METALLIC COVER with SINGLE FLIP LID**

|             |       |                                                                     |   |   |
|-------------|-------|---------------------------------------------------------------------|---|---|
| FLBAFR101BR | 00711 | Non-metallic box, Brown non-metallic cover w single flip lid        | 1 | 4 |
| FLBAFR101BL | 00710 | Non-metallic box, Black non-metallic cover w single flip lid        | 1 | 4 |
| FLBAFR101CA | 00712 | Non-metallic box, Caramel non-metallic cover w single flip lid      | 1 | 4 |
| FLBAFR101LA | 00713 | Non-metallic box, Light Almond non-metallic cover w single flip lid | 1 | 4 |
| FLBAFR101W  | 00714 | Non-metallic box, White non-metallic cover w single flip lid        | 1 | 4 |

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" round plastic or metal cover/flip lid assembly, (2) #6-32 x 1-1/4" screws, (4) #6 drywall screws, (1) NM900 plug, (1) NM94 connector, (1) metal clip and (1) plug.

## COVERS WITH TWO FLIP LIDS



FLBAF101MB

**SINGLE Gang**  
**COVER SHAPE**


FLBAF101CA



FLBAF101NL



FLBAF101LA

FLBAF101MB  
Brass cover

| CATALOG NUMBER | UPC/DCI/NAED MFG. #018997 | DESCRIPTION                             | UNIT | STD |
|----------------|---------------------------|-----------------------------------------|------|-----|
|                |                           | ADJUSTABLE FLOOR BOX COVER COLOR/FINISH | PKG  | PKG |

**METAL COVER, RECTANGULAR with TWO FLIP LIDS**

|            |       |                                                 |   |   |
|------------|-------|-------------------------------------------------|---|---|
| FLBAF101MB | 13805 | Non-metallic box, Brass w two flip lids         | 1 | 4 |
| FLBAF101NL | 13806 | Non-metallic box, Nickel-plated w two flip lids | 1 | 4 |

**NON-METALLIC COVER, RECTANGULAR with TWO FLIP LIDS**

|            |       |                                                                   |   |   |
|------------|-------|-------------------------------------------------------------------|---|---|
| FLBAF101BR | 04343 | Non-metallic box, Brown non-metallic cover w two flip lids        | 1 | 4 |
| FLBAF101BL | 04342 | Non-metallic box, Black non-metallic cover w two flip lids        | 1 | 4 |
| FLBAF101CA | 52301 | Non-metallic box, Caramel non-metallic cover w two flip lids      | 1 | 4 |
| FLBAF101LA | 04341 | Non-metallic box, Light Almond non-metallic cover w two flip lids | 1 | 4 |
| FLBAF101W  | 04340 | Non-metallic box, White non-metallic cover w two flip lids        | 1 | 4 |

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 3-3/4" x 4-5/8" plastic or 4" x 4-5/8" metal cover assembly w/ two flip lids, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

# ADJUSTABLE FLOOR BOX KITS

ADJUSTS TO FINISHED FLOOR HEIGHT

with a Variety of Metal & Plastic Covers

## COVERS WITH TWO THREADED PLUGS

SINGLE Gang

COVER SHAPE

 


| CATALOG NUMBER                                           | UPC/DCI/NAED MFG. #018997 | DESCRIPTION                                                        | UNIT | STD |
|----------------------------------------------------------|---------------------------|--------------------------------------------------------------------|------|-----|
|                                                          |                           | ADJUSTABLE FLOOR BOX COVER COLOR/FINISH                            | PKG  | PKG |
| <b>METAL COVER, ROUND with TWO THREADED PLUGS</b>        |                           |                                                                    |      |     |
| FLBAR101MB                                               | 52261                     | Non-metallic box, Brass w two threaded plugs                       | 1    | 4   |
| FLBAR101NL                                               | 52451                     | Non-metallic box, Nickel-plated w two threaded plugs               | 1    | 4   |
| <b>NON-METALLIC COVER, ROUND with TWO THREADED PLUGS</b> |                           |                                                                    |      |     |
| FLBAR101BR                                               | 04351                     | Non-metallic box, Brown non-metallic cover w threaded plugs        | 1    | 4   |
| FLBAR101BL                                               | 04350                     | Non-metallic box, Black non-metallic cover w threaded plugs        | 1    | 4   |
| FLBAR101LA                                               | 04349                     | Non-metallic box, Light Almond non-metallic cover w threaded plugs | 1    | 4   |
| FLBAR101W                                                | 04348                     | Non-metallic box, White non-metallic cover w threaded plugs        | 1    | 4   |

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

SINGLE Gang

COVER SHAPE



| CATALOG NUMBER                                                 | UPC/DCI/NAED MFG. #018997 | DESCRIPTION                                                      | UNIT | STD |
|----------------------------------------------------------------|---------------------------|------------------------------------------------------------------|------|-----|
|                                                                |                           | ADJUSTABLE FLOOR BOX COVER COLOR/FINISH                          | PKG  | PKG |
| <b>METAL COVER, RECTANGULAR with TWO THREADED PLUGS</b>        |                           |                                                                  |      |     |
| FLBA101MB                                                      | 52259                     | Non-metallic box, Brass w two threaded plugs                     | 1    | 4   |
| FLBA101NL                                                      | 52450                     | Non-metallic box, Nickel-plated w two threaded plugs             | 1    | 4   |
| <b>NON-METALLIC COVER, RECTANGULAR with TWO THREADED PLUGS</b> |                           |                                                                  |      |     |
| FLBA101BR                                                      | 04347                     | Non-metallic box, Brown non-metallic cover w threaded plugs      | 1    | 4   |
| FLBA101BL                                                      | 04346                     | Non-metallic box, Black non-metallic cover w threaded plugs      | 1    | 4   |
| FLBA101LA                                                      | 04345                     | Non-metallic box, Light Almond non-metallic cover threaded plugs | 1    | 4   |
| FLBA101W                                                       | 04344                     | Non-metallic box, White non-metallic cover w threaded plugs      | 1    | 4   |

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 4-1/4" x 5-1/8" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.



Arlington

Patented/Other patents pending

Distributed by

1 Stauffer Industrial Park. Scranton, PA 18517

800.233.4717 • www.aifittings.com • EMAIL sales@aifittings.com