

BURNDY Catalog Number
UPC Number
Description
Status

KA26U
 7818103701000
 6STR-2/0STR DUAL RATED
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.63
 Length (in) 1.47
 Bolt Hole Size (in) 0.25
 Thickness 0.19
 D - in 0.81
 Pad Width (in) 0.64
 N (in) 0.45

General

Number of Conductors 1
 Number of Holes 1
 Product Description Aluminum Universal Terminal, 1 Hole, 6-2/0 AWG (Str), 1/4" Stud, 1 Screw, Al/Cu Rated, Tin Plated

Conductor(s)

Aluminum Size (Range) 14 STR- 2/0 STR
 Copper Solid Size (Range) N/A
 Copper Stranded (Range) 14-2/0

Physical

Installation Torque 120
 Type of Plating Tin
 Connector Type Terminal
 Bolt Hole Size 1/4
 Plated (Yes or No) Y
 Product Material Aluminum

Approvals / Certifications

Rated for Direct Burial N
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 Industry Standards UL468A-468B

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

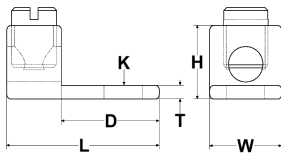

BURNDY Catalog Number
UPC Number
Description
Status

KA26U
 7818103701000
 6STR-2/0STR DUAL RATED
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.63
 Length (in) 1.47
 Bolt Hole Size (in) 0.25
 Thickness 0.19
 D - in 0.81
 Pad Width (in) 0.64
 N (in) 0.45

General

Number of Conductors 1
 Number of Holes 1
 Product Description Aluminum Universal Terminal, 1 Hole, 6-2/0 AWG (Str), 1/4" Stud, 1 Screw, Al/Cu Rated, Tin Plated

Conductor(s)

Aluminum Size (Range) 14 STR- 2/0 STR
 Copper Solid Size (Range) N/A
 Copper Stranded (Range) 14-2/0

Physical

Installation Torque 120
 Type of Plating Tin
 Connector Type Terminal
 Bolt Hole Size 1/4
 Plated (Yes or No) Y
 Product Material Aluminum

Approvals / Certifications

Rated for Direct Burial N
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 Industry Standards UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175