

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

KS25  
 7818100131066  
 SERVIT 4 STR - 1/0 STR  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in) 0.73  
 Size (Hex) or Size (Bolt) 3/4  
 Cross Flats 0.94  
 Size (Hex) or Size (Bolt) - in 0.750  
 B Length (in) .83  
 B Length (Fraction) 83/100

**General**

Product Description Copper Split Bolt, Cu: 4 AWG-1/0 AWG (Str) (Run & Tap)

**Conductor(s)**

Copper Tap Range 14 AWG-1/0  
 CopperWeld Solid Run Size (Range) 2/0  
 Copper Stranded Run (Range) 4 AWG-1/0  
 CopperWeld Stranded Tap Size (Range) 5 D AWG-2 A AWG  
 Copper Solid Tap (Range) 14 AWG-1/0  
 CopperWeld Solid Tap Size (Range) 2/0  
 Copper Solid Run Size (Range) 4 AWG-1/0  
 CopperWeld Stranded Run Size (Range) 4 D AWG-2 A AWG

**Physical**

Installation Torque 385  
 Type of Plating Unplated  
 Connector Type Split Bolt  
 Plated (Yes or No) N  
 Product Material Copper

**Approvals / Certifications**

Rated for Direct Burial Y  
 UL Listed Y  
 CSA Certified Y  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N  
 Industry Standards RUS

**Documentation**

For further technical assistance, please contact us


**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

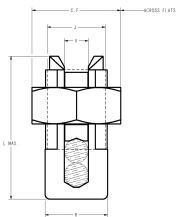

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

KS25  
 7818100131066  
 SERVIT 4 STR - 1/0 STR  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in) 0.73  
 Size (Hex) or Size (Bolt) 3/4  
 Cross Flats 0.94  
 Size (Hex) or Size (Bolt) - in 0.750  
 B Length (in) .83  
 B Length (Fraction) 83/100

**General**

Product Description Copper Split Bolt, Cu: 4 AWG-1/0 AWG (Str) (Run & Tap)

**Conductor(s)**

Copper Tap Range 14 AWG-1/0  
 CopperWeld Solid Run Size (Range) 2/0  
 Copper Stranded Run (Range) 4 AWG-1/0  
 CopperWeld Stranded Tap Size (Range) 5 D AWG-2 A AWG  
 Copper Solid Tap (Range) 14 AWG-1/0  
 CopperWeld Solid Tap Size (Range) 2/0  
 Copper Solid Run Size (Range) 4 AWG-1/0  
 CopperWeld Stranded Run Size (Range) 4 D AWG-2 A AWG

**Physical**

Installation Torque 385  
 Type of Plating Unplated  
 Connector Type Split Bolt  
 Plated (Yes or No) N  
 Product Material Copper

**Approvals / Certifications**

Rated for Direct Burial Y  
 UL Listed Y  
 CSA Certified Y  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N  
 Industry Standards RUS

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175