




# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

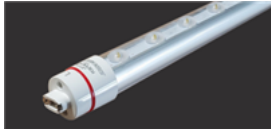

## LED21T896P1S840D 8' 21W Led Signhero 40K 180DEG BLST Bypass *Keystone Technologies*

Catalog Number	LED21T896P1S840D
Manufacturer	Keystone Technologies
Description	96IN Led Sign Tube, 4000K, Single Sided Output and Rotatable R17D End Caps, 21W, 120-277V Input
Weight per unit	2.6 (lbs/each)
Product Category	Shape & Circular Lamps

### Features

Ballast Type	N/A
beam angle	180 Deg
Circuit Type	N/A
Input Voltage	120-277V
ip rating	N/A
lumens	2650
Nominal Length	96 in
Nominal Size	N/A
Number of Lamps	N/A
Output Current	N/A
Output Voltage	N/A
Sensor Type	N/A
Wattage	21
Wire Type	N/A

### Material, Color, and Finish

Base Type	R17D
color rendering index (cri)	>80 Deg
color temperature	4000
housing color	N/A

### Descriptions

Construction	N/A
Description	8' 21W LED SIGNHERO 40K 180DEG BLST BYPASS
extra long description	Key KT-LED21T8-96P1S-840-D /G2 96"
Long Description	96IN LED SIGN TUBE, 4000K, SINGLE SIDED OUTPUT AND ROTATABLE R17D END CAPS, 21W, 120-277V INPUT
Product Type	96", 21W, 2, 650 Lumens, 180' Beam Spread, Single Sided Lamp,



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

## Manufacturer Information

Brand	Keystone
GTIN	00843654132792
Manufacturers Part Number	KT-LED21T8-96P1S-840-D /G2
UPC	843654132792

## Taxonomies, Classifications, and Categories

Category Description	LED SPECIALTY LAMPS & MODULES
----------------------	-------------------------------

## Packaging

Carton	1
Package	9
Weight Per each	2.56

## Uses, Certifications, and Standards

Energy Star	N
-------------	---