

KT-LED9A19-O-8XX-ND

REPLACEMENT LAMP

DESCRIPTION

9W A19 Lamp | 2700–5000K | > 80 CRI | Omni-Directional



LAMP TYPE: A19

BASE TYPE: E26 (Medium)

WATTAGE: 9W

COLOR TEMPERATURE: 2700–5000K

COLOR RENDERING INDEX (CRI): > 80

WARRANTY: 3 Years

RATED LIFE: L70 (15,000 Hours)



TYPICAL APPLICATIONS

- Table, desk, and floor lamps
- Wall sconces
- Surface-mount ceiling fixtures
- General lighting
- Pendant lights

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, diffused lens for comfortable glare-free performance
- Durable plastic housing lowers the risk for breakage
- Long life minimizes replacement and maintenance costs
- Suitable for use in damp locations
- UL enclosed rated, suitable for use in totally enclosed luminaires
- Operating temperature range –4°F/–20°C to 95°F/35°C
- PF > 0.60
- ANSI compliant construction ensures fitment for intended applications
- UL Listed
- Complies with Part 15 of FCC


ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Beam Angle	Dimmable	Efficacy
KT-LED9A19-O-827-ND	A19 bulb; Omni-directional; Non-dimming	2700K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-830-ND	A19 bulb; Omni-directional; Non-dimming	3000K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-835-ND	A19 bulb; Omni-directional; Non-dimming	3500K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-840-ND	A19 bulb; Omni-directional; Non-dimming	4000K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-850-ND	A19 bulb; Omni-directional; Non-dimming	5000K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W

KT-LED9A19-O-8XX-ND

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

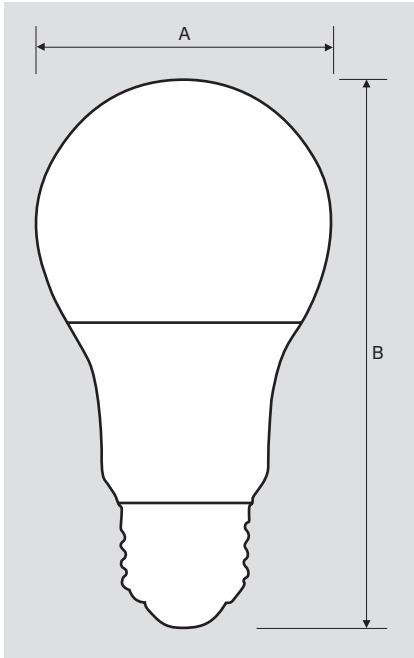

LAMP DIMENSIONS

A (Diameter)	2.36"
B (Length)	4.33"

BASE TYPE: E26 (Medium)

PACKAGING

Carton Quantity	60 pcs
Carton Dimensions	15.55" x 13.07" x 10"
Carton Weight	9.8 lbs

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	EASY CODE	UPC
KT-LED9A19-O-827-ND	60 pcs	ANV-10	843654126456
KT-LED9A19-O-830-ND	60 pcs	QSP-72	843654126470
KT-LED9A19-O-835-ND	60 pcs	GIE-15	843654127569
KT-LED9A19-O-840-ND	60 pcs	AIO-19	843654133751
KT-LED9A19-O-850-ND	60 pcs	KBN-67	843654126494

CATALOG NUMBER BREAKDOWN

KT-LED9A19-O-8XX-ND

1 2 3 4 5 6 7 8

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 800 Series
- 7 Color Temperature
- 8 Non-Dimming



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED9A19-O-8XX-ND

REPLACEMENT LAMP

DESCRIPTION

9W A19 Lamp | 2700–5000K | > 80 CRI | Omni-Directional



LAMP TYPE: A19

BASE TYPE: E26 (Medium)

WATTAGE: 9W

COLOR TEMPERATURE: 2700–5000K

COLOR RENDERING INDEX (CRI): > 80

WARRANTY: 3 Years

RATED LIFE: L70 (15,000 Hours)



TYPICAL APPLICATIONS

- Table, desk, and floor lamps
- Wall sconces
- Surface-mount ceiling fixtures
- General lighting
- Pendant lights

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, diffused lens for comfortable glare-free performance
- Durable plastic housing lowers the risk for breakage
- Long life minimizes replacement and maintenance costs
- Suitable for use in damp locations
- UL enclosed rated, suitable for use in totally enclosed luminaires
- Operating temperature range –4°F/–20°C to 95°F/35°C
- PF > 0.60
- ANSI compliant construction ensures fitment for intended applications
- UL Listed
- Complies with Part 15 of FCC


ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Beam Angle	Dimmable	Efficacy
KT-LED9A19-O-827-ND	A19 bulb; Omni-directional; Non-dimming	2700K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-830-ND	A19 bulb; Omni-directional; Non-dimming	3000K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-835-ND	A19 bulb; Omni-directional; Non-dimming	3500K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-840-ND	A19 bulb; Omni-directional; Non-dimming	4000K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W
KT-LED9A19-O-850-ND	A19 bulb; Omni-directional; Non-dimming	5000K	120V	9W	60W halogen	E26	800 lm	> 80	230°	No	89 lm/W

KT-LED9A19-O-8XX-ND

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

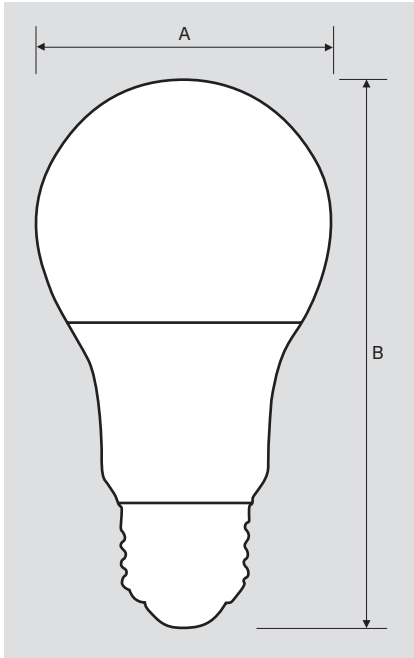

LAMP DIMENSIONS

A (Diameter)	2.36"
B (Length)	4.33"

BASE TYPE: E26 (Medium)

PACKAGING

Carton Quantity	60 pcs
Carton Dimensions	15.55" x 13.07" x 10"
Carton Weight	9.8 lbs

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	EASY CODE	UPC
KT-LED9A19-O-827-ND	60 pcs	ANV-10	843654126456
KT-LED9A19-O-830-ND	60 pcs	QSP-72	843654126470
KT-LED9A19-O-835-ND	60 pcs	GIE-15	843654127569
KT-LED9A19-O-840-ND	60 pcs	AIO-19	843654133751
KT-LED9A19-O-850-ND	60 pcs	KBN-67	843654126494

CATALOG NUMBER BREAKDOWN

KT-LED9A19-O-8XX-ND

1 2 3 4 5 6 7 8

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 800 Series
- 7 Color Temperature
- 8 Non-Dimming