




## LSW-30CW-PC LSW-30WW-PC

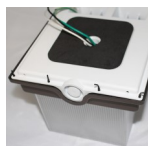

1/2" hub located at back and bottom of housing for mounting versatility




Non-cutoff optics with wide forward throw distribution ideal for extending spacing to mounting height ratio



LWS comes pre-wired with 120 volt photo electric control

### DIMENSIONS:

6-7/8"(W) x 11"(H) x 5-1/8"(D)

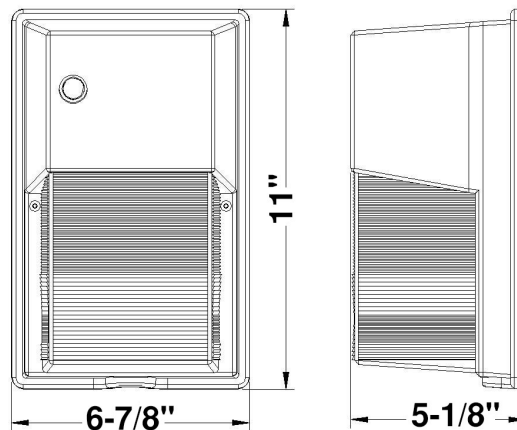

## LED NON-CUTOFF WALL PACK

Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.

### ELECTRICAL SPECIFICATIONS:

- Voltage: 120-277VAC 50/60Hz
- Wattage: 30W
- Other wattages: 20W
- Power factor: >0.95
- Efficacy: 90LM/W~95LM/W

### HOUSING SPECIFICATIONS:

- Die cast aluminum
- Outdoor powder coat finish (Dark Bronze)
- Operating temperature: -4°F ~ 104°F
- Lifespan: 50000 Hrs.
- IP rating: IP65, Wet Locations

### CERTIFICATIONS: UL, DLC





| MODEL       | WATTS | VOLTAGE     | LUMENS  | COLOR TEMP |
|-------------|-------|-------------|---------|------------|
| LSW-30CW-PC | 30W   | 120~277V AC | 2900 LM | 5000K      |
| LSW-30WW-PC | 30W   | 120~277V AC | 2700 LM | 3000K      |

### LIGHTING SPECIFICATIONS:

- LED type/brand: Philips Lumileds / SMD 3030
- Total lumens: 2700LM and 2900LM
- Color temperature: 4000K / 5000K
- Color rendering index: >82
- Beam angle: 90° x 110°


### WARRANTY: 7 years

### PHOTOMETRICS:

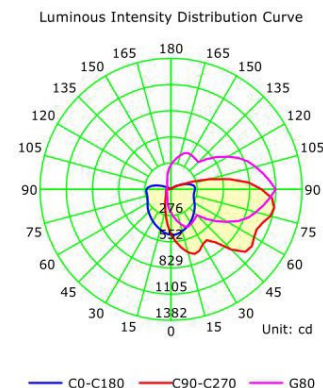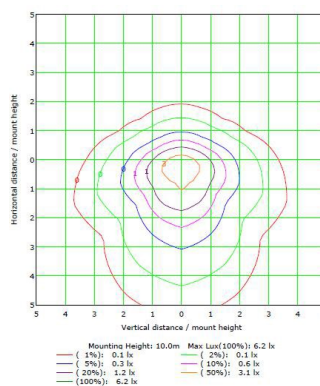



## LSW-30CW-PC LSW-30WW-PC

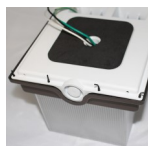

1/2" hub located at back and bottom of housing for mounting versatility




Non-cutoff optics with wide forward throw distribution ideal for extending spacing to mounting height ratio



LWS comes pre-wired with 120 volt photo electric control

### DIMENSIONS:

6-7/8"(W) x 11"(H) x 5-1/8"(D)

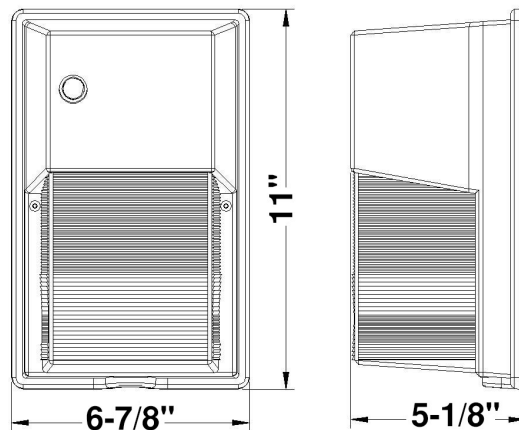

## LED NON-CUTOFF WALL PACK

Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.

### ELECTRICAL SPECIFICATIONS:

- Voltage: 120-277VAC 50/60Hz
- Wattage: 30W
- Other wattages: 20W
- Power factor: >0.95
- Efficacy: 90LM/W~95LM/W

### HOUSING SPECIFICATIONS:

- Die cast aluminum
- Outdoor powder coat finish (Dark Bronze)
- Operating temperature: -4°F ~ 104°F
- Lifespan: 50000 Hrs.
- IP rating: IP65, Wet Locations

### CERTIFICATIONS: UL, DLC



| MODEL       | WATTS | VOLTAGE     | LUMENS  | COLOR TEMP |
|-------------|-------|-------------|---------|------------|
| LSW-30CW-PC | 30W   | 120~277V AC | 2900 LM | 5000K      |
| LSW-30WW-PC | 30W   | 120~277V AC | 2700 LM | 3000K      |

### LIGHTING SPECIFICATIONS:

- LED type/brand: Philips Lumileds / SMD 3030
- Total lumens: 2700LM and 2900LM
- Color temperature: 4000K / 5000K
- Color rendering index: >82
- Beam angle: 90° x 110°

### WARRANTY: 7 years

### PHOTOMETRICS:

