



Fittings and Brackets

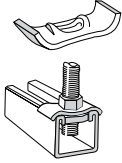


CAT. NO. AB-242
For use with either 3/8" or 1/2" hanger rod

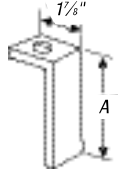


CAT. NO. AB252


CAT. NO.	A (IN.)	STD. CTN.
AB252 1	3 7/8	10
AB252 2	5 7/8	10
AB252 3	7 7/8	10
AB252 4	9 7/8	10

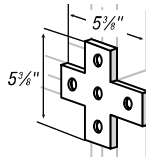


CAT. NO. AB253

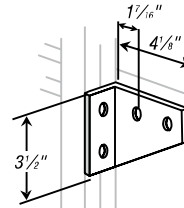


CAT. NO. AB254 L

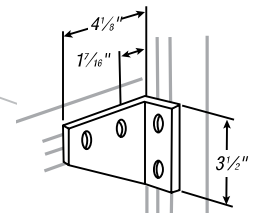


CAT. NO. AB254 R

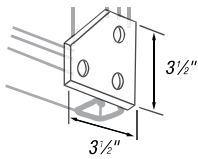


CAT. NO. AB255

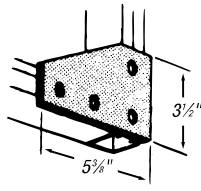


CAT. NO. AB257

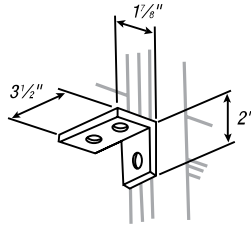


CAT. NO. AB260 L

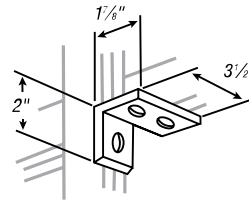


CAT. NO. AB260 R

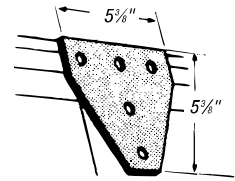


CAT. NO. AB261

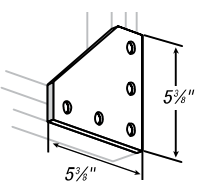


CAT. NO. AB263

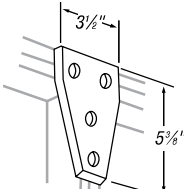


CAT. NO. AB265

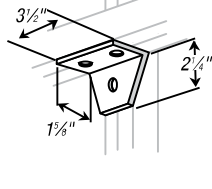


CAT. NO. AB274

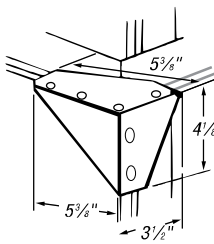


CAT. NO. AB284 L

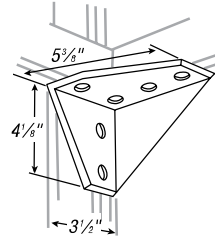


CAT. NO. AB284 R

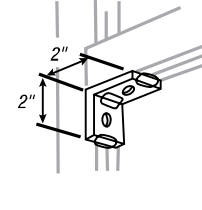


CAT. NO. AB299

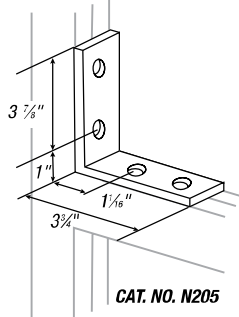


CAT. NO. N205

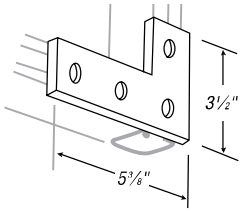


CAT. NO. N-219

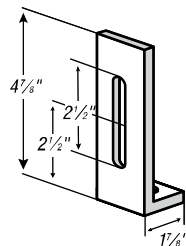


CAT. NO. X201

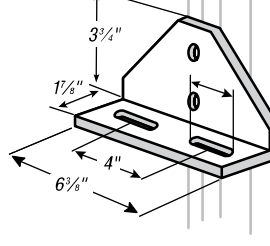


CAT. NO. X204
Slot size is 3/16" x 1 1/2"

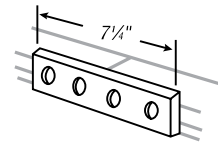


CAT. NO. X207

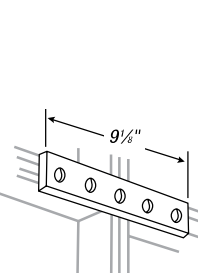

CAT. NO. X208

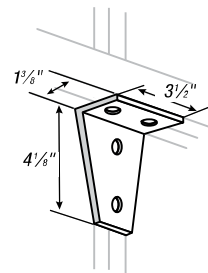

CAT. NO. X289

 

CAT. NO. X299

Standard Dimensions

- Hole Spacing: 13/16" From End
- Hole Spacing: 1 7/8" Centers
- Hole Size: 3/16" Diameter
- Material: 1 1/2" Width
- Material: 1/4" Thick

Standard Finish – GoldGalv®, unless otherwise stated.
Add EG suffix for SilverGalv® Finish