

52" Signature Fan

P2521-09 Brushed Nickel with reversible White/Natural Cherry blades

P2521-20 Antique Bronze with reversible Medium Cherry/Classic Walnut blades

P2521-33 Cobblestone with reversible Honey Pine/Medium Cherry blades

P2521-40 Millstone with reversible Medium Oak/Light Oak blades

P2521-71 Gilded Iron with reversible Classic Walnut/Dark Cherry blades

P2521-77 Forged Bronze with reversible Classic Walnut/Medium Cherry blades

P2521-81 Antique Nickel with reversible Medium Oak/Cherry blades

P2521-93 Corinthian Bronze with reversible Dark Teak/Medium Cherry blades

Size: 52" dia., 14-5/8" ht.
CTC 11-9/16" ht.

30-year limited warranty
SureConnect® blade arms
12° blade pitch

45° canopy (up to 12:12 ceiling pitch)

Dual mount

Triple capacitor, 153mm x 18mm reversible motor

80" lead wires

Plywood blade construction

Light fixture adaptable

CUL



P2521-77
Forged Bronze with Classic Walnut blades



 
Medium Cherry blades

P2521-40
Millstone with Medium Oak blades



Light Oak blades

P2521-33
Cobblestone with Medium Cherry blades



Honey Pine blades

P2521-93
Corinthian Bronze with Dark Teak blades



 
Medium Cherry blades

P2521-71
Gilded Iron with Dark Cherry blades




Classic Walnut blades

P2521-81
Antique Nickel with Cherry blades



Medium Oak blades

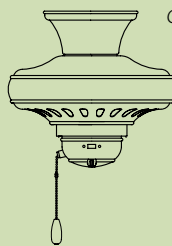

CTC installation

52" Signature Fan

P2521-09 Brushed Nickel with reversible White/Natural Cherry blades

P2521-20 Antique Bronze with reversible Medium Cherry/Classic Walnut blades

P2521-33 Cobblestone with reversible Honey Pine/Medium Cherry blades

P2521-40 Millstone with reversible Medium Oak/Light Oak blades

P2521-71 Gilded Iron with reversible Classic Walnut/Dark Cherry blades

P2521-77 Forged Bronze with reversible Classic Walnut/Medium Cherry blades

P2521-81 Antique Nickel with reversible Medium Oak/Cherry blades

P2521-93 Corinthian Bronze with reversible Dark Teak/Medium Cherry blades

Size: 52" dia., 14-5/8" ht.
CTC 11-9/16" ht.

30-year limited warranty
SureConnect® blade arms
12° blade pitch

45° canopy (up to 12:12 ceiling pitch)

Dual mount

Triple capacitor, 153mm x 18mm reversible motor

80" lead wires

Plywood blade construction

Light fixture adaptable

CUL



P2521-77
Forged Bronze with
Classic Walnut blades



 
Medium Cherry
blades

P2521-40
Millstone with
Medium Oak blades



Light Oak
blades

P2521-33
Cobblestone with
Medium Cherry blades



Honey Pine blades

P2521-93
Corinthian Bronze with
Dark Teak blades



 
Medium Cherry
blades

P2521-71
Gilded Iron with
Dark Cherry blades




Classic Walnut
blades

P2521-81
Antique Nickel
with Cherry blades



Medium Oak
blades

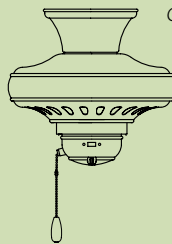

CTC installation