



GE  
Lighting

**20835 - Q50MR16/C/NFL25**

GE MR16



**GENERAL CHARACTERISTICS**

|                           |                           |
|---------------------------|---------------------------|
| Lamp Type                 | Halogen - MR              |
| Bulb                      | MR16                      |
| Base                      | 2-Pin (GX5.3)             |
| Filament                  | C-6                       |
| Rated Life                | 6000.0 hrs                |
| Lamp Enclosure Type (LET) | Open or enclosed fixtures |

**PHOTOMETRIC CHARACTERISTICS**

|                                |          |
|--------------------------------|----------|
| Initial Lumens                 | 800.0    |
| Center Beam Candlepower (CBCP) | 3200.0   |
| Color Temperature              | 3050.0 K |
| Beam Spread                    | 25.0 °   |

**ELECTRICAL CHARACTERISTICS**


|         |      |
|---------|------|
| Wattage | 50.0 |
| Voltage | 12.0 |

**DIMENSIONS**

|                              |                    |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 1.8750 in(47.6 mm) |
| Bulb Diameter (DIA)          | 2.000 in(50.8 mm)  |

**PRODUCT INFORMATION**

|                                  |                 |
|----------------------------------|-----------------|
| Product Code                     | 20835           |
| Description                      | Q50MR16/C/NFL25 |
| ANSI Code                        | EXZ             |
| Standard Package                 | BUNDLE          |
| Standard Package GTIN            | 00043168208352  |
| Standard Package Quantity        | 20              |
| Sales Unit                       | Unit            |
| No Of Items Per Sales Unit       | 1               |
| No Of Items Per Standard Package | 20              |
| UPC                              | 043168994279    |

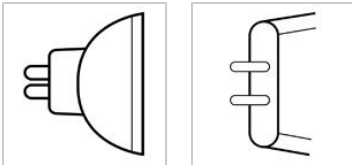

**CAUTIONS & WARNINGS**

**Caution**

- Lamp may shatter and cause injury if broken
  - Dispose of lamp in a closed container.
  - Do not use lamp if outer glass is scratched or broken.

**Warning**

- Risk of Burn
  - Allow lamp/fixture to cool before handling.
  - Turn power off before installing lamp.
- Risk of Fire
  - Keep combustible materials away from lamp.
  - Use in enclosed fixture rated for this product-- see instructions.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not touch glass with bare hands.
  - Do not use lamp if outer glass is scratched or broken.
  - Use eye protection when handling lamp.
  - Use in enclosed fixture rated for this product.