


RB6T5

RAB offers energy efficient fluorescent fixtures for large space lighting including warehouses, factories, and distribution centers. The RBAY delivers the high quality needed for these applications with strong, heavy duty 22 gauge rigid housing with no sharp edges. The superior strong-box protective foam case packaging protects the RBAY so it arrives in perfect shape and ready to install.

Color: N/A

Weight: 21.0 lbs

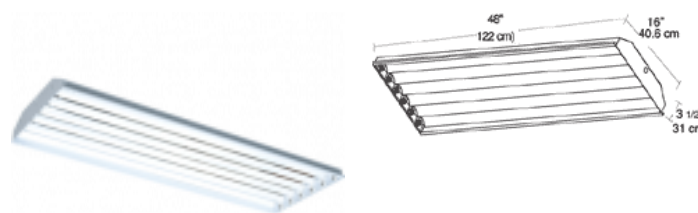

Lamp Info

Type: T5HO
 Watts: 324W
 Shape/Size: N/A
 Base: N/A
 ANSI: N/A
 Hours: 20,000
 Lamp Lumens: 24,008
 Efficacy: 66 LPW

Ballast Info

Type: Prog. Start
 120V: 3A
 208V: N/A
 240V: N/A
 277V: 1.33A
 Input Watts: 362W
 Efficiency: 90%

Technical Specifications

UL Listing:

Dry Locations Only. Ceiling Mount Only.

Housing:

Heavy duty 22 gauge steel housing and wiring box with 1/2" NPS knockouts. Painted white. Easy wiring and maintenance access panel. Includes "Y" hooks.

Reflector:

Alanod 320G-E with reflectivity of 86%.

Lamp:

T5HO (not supplied).

CRI:

85.

Total Watts:

6x54W.

Input Volts:

120-277V.

Input Amps:

3.0/1.28.

Ballast Factor:

1.00.

Base:

Medium Bi Pin.

Mounts:

Surface or Chain (Y Hooks included).

Patents:

RAB sensor and fixture designs are protected under U.S. and International Intellectual Property laws.

RAB
LIGHTING

Tech Help Line: 888 RAB-1000

Email: sales@rabweb.com

On the web at: www.rabweb.com

Copyright ©2013 RAB Lighting, Inc. All Rights Reserved

Note: Specifications are subject to change without notice

Page 1 of 1