

INSPECTION HOUSING, HIGH DENSITY POLYETHYLENE (HDPE), 13.1" OD, 10"

CATALOG NUMBER

T416B



FEATURES

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

PRODUCT ATTRIBUTES

Material: High Density Polyethylene (HDPE)

Color: Green

Load Rating: 300lb/ft²


Diameter, Grade Level (DG): 10 1/4"

Outer Diameter (OD): 13.1"

Height (H): 10"

Unit Weight: 4.5 lb

DIAGRAMS

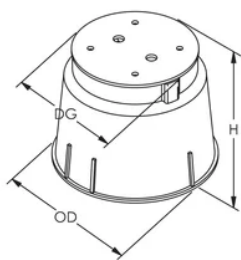

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER

INSPECTION HOUSING, HIGH DENSITY POLYETHYLENE (HDPE), 13.1" OD, 10"

CATALOG NUMBER

T416B



FEATURES

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

PRODUCT ATTRIBUTES

Material: High Density Polyethylene (HDPE)

Color: Green

Load Rating: 300lb/ft²


Diameter, Grade Level (DG): 10 1/4"

Outer Diameter (OD): 13.1"

Height (H): 10"

Unit Weight: 4.5 lb

DIAGRAMS

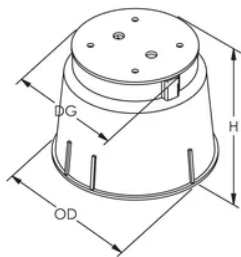

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER