




Standard Grade Receptacles

2-Pole, 3-Wire Grounding
2-Pole, 2-Wire Non-Grounding
15A, 125V/AC

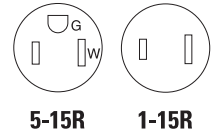

FEATURES

- Tamper Resistant versions provide compliance with 2011 NEC® Article 406.12 that states that all receptacles installed in dwelling units must be tamper resistant. 
- Weather Resistant versions provide compliance with 2011 NEC® Article 406.9 that states that all receptacles installed in wet and damp locations must be weather resistant. 
- Longer, wider strap provides 40% more contact area to wall board, virtually eliminating floating installations.
- Patented built-in wire stripper for #14 and #12 AWG wire to speed installation.
- Patented built-in wire looper for pre-looping.
- High impact-resistant thermoplastic face and back body eliminates breakage.
- Double-wipe ground contacts ensure long-term ground retention.
- Easy access split circuit break-off tab.
- Tri-combo screws accept Slotted-, Phillips-, and Robertson-head tools for installation flexibility.
- Terminal screws backed out and ready for wiring.
- Side wire terminals accept up to #10 AWG solid wire.
- Push-in terminals accept #14 AWG solid wire.






TR270

Tamper Resistant Duplex Receptacles

15A 125V/AC; Side & Push Wire

Description	Color Suffix	Catalog No.	
Tamper Resistant NEMA 5-15R Duplex Receptacle	A, B, BK, LA, V, W	<input type="checkbox"/> TR270__	•
Auto Grounding Tamper Resistant NEMA 5-15R Duplex Receptacle	A, B, BK, LA, V, W	<input type="checkbox"/> TR270-9__	•

   cULus Listed to UL498, file no. E15058; NOM certified




TWR270

Tamper & Weather Resistant Duplex Receptacles

15A 125V/AC; Side & Push Wire

Description	Color Suffix	Catalog No.	
Tamper & Weather Resistant NEMA 5-15R Duplex Receptacle	LA, V, W	<input type="checkbox"/> TWR270__	•


  cULus Listed to UL498, file no. E15058; NOM certified






270

Duplex Receptacles

15A 125V/AC; Side & Push Wire



Description	Color Suffix	Catalog No.	
NEMA 5-15R Duplex Receptacle	A, B, BLK, LA, V, W	<input type="checkbox"/> 270__	•
Auto Grounding NEMA 5-15R Duplex Receptacle	A, B, LA, V, W	<input type="checkbox"/> 270-9__	•
NEMA 5-15R Duplex Receptacle, Less Ears	A, B, BK, LA, V, W	<input type="checkbox"/> 4270__	•

   Listed to UL498, file no. E15058; CSA certified to C22.2, no. 42; NOM certified

Duplex Receptacles

15A 125V/AC; Side Wire

Description	Color Suffix	Catalog No.	
NEMA 1-15R Duplex Receptacle, Non-Grounding	B, V, W	<input type="checkbox"/> 736__	•

  Listed to UL498, file no. E15058; NOM certified

Color Ordering Information: For ordering devices, include Cat. No. followed by the color code: A (Almond), B (Brown), BK (Black), BLK (Black), LA (Light Almond), V (Ivory), W (White)

Dimensional Information: B-60

Specification Information: Please visit www.cooperwiringdevices.com

 **NAFTA Compliant:** See page F-21