

FEATURES & SPECIFICATIONS

INTENDED USE

Ideal for mounting above entryways and loading docks.

CONSTRUCTION

Rugged, corrosion-resistant die-cast aluminum back housing and hinged door frame. Castings are sealed with a one-piece gasket to inhibit the entrance of external contaminants. Finish is bronze polyester powder paint for lasting durability.

ELECTRICAL

Ballast is constant wattage autotransformer. Ballast is 100% factory-tested.

Metal halide: super CWA pulse start ballasts, 88% efficient and EISA compliant, are required for 250-400W (must order SCWA option) for US shipments only. CSA required for pulse start shipments to Canada. 250M and 400M do not comply with California Title 20 regulations.

Socket: Mogul-base socket, nickel-plated screw shell and center contact.

OPTICS

Refractor is prismatic borosilicate glass. Reflector is die-formed anodized stippled aluminum.

Mogul-base lamp included in carton.

INSTALLATION

Housing is configured for mounting directly over a standard 4" outlet box or for surface wiring via any of three convenient 1/2" threaded conduit entry hubs.

LISTING

UL Listed to US and Canadian safety standards (see Options). Suitable for wet locations (25°C maximum ambient temperature).

WARRANTY

2-year limited warranty. Complete warranty terms located at:

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

| |
|----------------|
| Catalog Number |
| Notes |
| Type |

Wall Packs

TWR2


METAL HALIDE: 250-400W



TWR2 250W



TWR2 400W

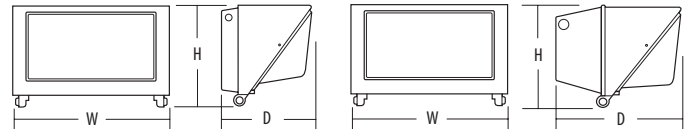

TWR2 250W

TWR2 400W

Specifications

Height: 9-1/4 (23.5)
 Width: 17-7/8 (45.4)
 Depth: 9-3/8 (23.8)
 *Weight: 26 lbs/ 11.8 kg

Specifications

Height: 9-1/4 (23.5)
 Width: 17-7/8 (45.4)
 Depth: 12-1/2 (31.8)
 *Weight: 31 lbs/ 14.07 kg

All dimensions shown in inches (centimeters) unless otherwise noted.

*Weight as configured in example below.

ORDERING INFORMATION

Example: TWR2 400M TB SCWA LPI

| Catalog Number | Wattage | Voltage | Photocell included | Lamp included | Available in Canada |
|---------------------------|---------|-----------------|--------------------|---------------|---------------------|
| Metal halide | | | | | |
| TWR2 250M 120/347 LPI CSA | 250 | 120/347 | N | Y | Y |
| TWR2 250M TB SCWA LPI | 250 | 120/208/240/277 | N | Y | N |
| TWR2 320M TB SCWA LPI | 320 | 120/208/240/277 | N | Y | N |
| TWR2 400M TB SCWA LPI | 400 | 120/208/240/277 | N | Y | N |


Accessories: Order as separate catalog number.
 Shipped separately

TWR2WG U Wireguard

TWR2 Metal Halide Wall Pack

TWR2 250M

Test No. LTL10414

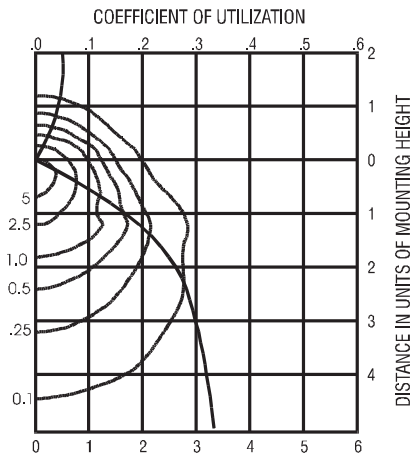

250W Metal Halide lamp, 20000 rated lumens. Footcandle values based on 20' mounting height, Distribution.

FEATURES & SPECIFICATIONS

INTENDED USE

Ideal for mounting above entryways and loading docks.

CONSTRUCTION

Rugged, corrosion-resistant die-cast aluminum back housing and hinged door frame. Castings are sealed with a one-piece gasket to inhibit the entrance of external contaminants. Finish is bronze polyester powder paint for lasting durability.

ELECTRICAL

Ballast is constant wattage autotransformer. Ballast is 100% factory-tested.

Metal halide: super CWA pulse start ballasts, 88% efficient and EISA compliant, are required for 250-400W (must order SCWA option) for US shipments only. CSA required for pulse start shipments to Canada. 250M and 400M do not comply with California Title 20 regulations.

Socket: Mogul-base socket, nickel-plated screw shell and center contact.

OPTICS

Refractor is prismatic borosilicate glass. Reflector is die-formed anodized stippled aluminum.

Mogul-base lamp included in carton.

INSTALLATION

Housing is configured for mounting directly over a standard 4" outlet box or for surface wiring via any of three convenient 1/2" threaded conduit entry hubs.

LISTING

UL Listed to US and Canadian safety standards (see Options). Suitable for wet locations (25°C maximum ambient temperature).

WARRANTY

2-year limited warranty. Complete warranty terms located at:

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

| |
|----------------|
| Catalog Number |
| Notes |
| Type |

Wall Packs

TWR2


METAL HALIDE: 250-400W



TWR2 250W



TWR2 400W

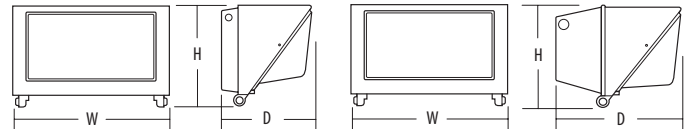

TWR2 250W

TWR2 400W

Specifications

Height: 9-1/4 (23.5)
 Width: 17-7/8 (45.4)
 Depth: 9-3/8 (23.8)
 *Weight: 26 lbs/ 11.8 kg

Specifications

Height: 9-1/4 (23.5)
 Width: 17-7/8 (45.4)
 Depth: 12-1/2 (31.8)
 *Weight: 31 lbs/ 14.07 kg

All dimensions shown in inches (centimeters) unless otherwise noted.

*Weight as configured in example below.

ORDERING INFORMATION

Example: TWR2 400M TB SCWA LPI

| Catalog Number | Wattage | Voltage | Photocell included | Lamp included | Available in Canada |
|---------------------------|---------|-----------------|--------------------|---------------|---------------------|
| Metal halide | | | | | |
| TWR2 250M 120/347 LPI CSA | 250 | 120/347 | N | Y | Y |
| TWR2 250M TB SCWA LPI | 250 | 120/208/240/277 | N | Y | N |
| TWR2 320M TB SCWA LPI | 320 | 120/208/240/277 | N | Y | N |
| TWR2 400M TB SCWA LPI | 400 | 120/208/240/277 | N | Y | N |


Accessories: Order as separate catalog number.
 Shipped separately

TWR2WG U Wireguard

TWR2 Metal Halide Wall Pack

TWR2 250M

Test No. LTL10414

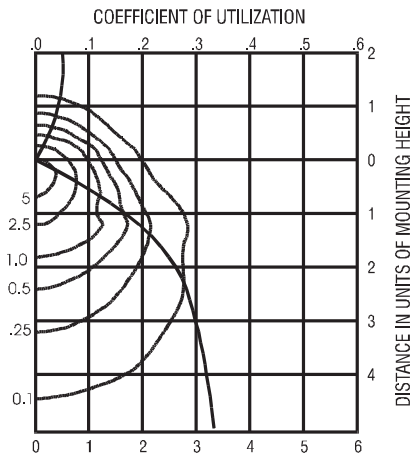

250W Metal Halide lamp, 20000 rated lumens. Footcandle values based on 20' mounting height, Distribution.