
(2) 14-50R, 5-20R2GFCI	(2) 5-20R2GFCI	(2) 5-20R2	R32U 5-20R2	R32U 5-20R2GFCI	R32U 5-20R2GFCI	R32U 5-20R2
A U004CP6010 U004CP4010	B U011CP6010 U011CP4010	C U011GP6 U011GP4	D U040GP6 U040GP4	E U040GP6010	F U041CP6010 U041CP4010	G U041GP6 U041GP4

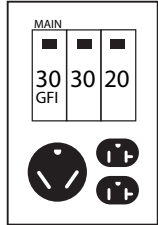
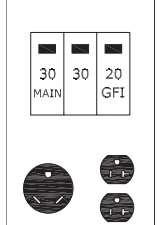
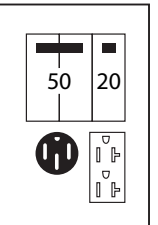
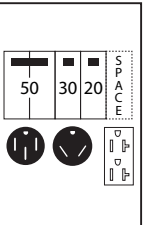
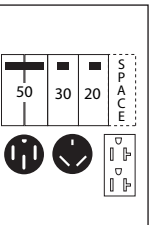
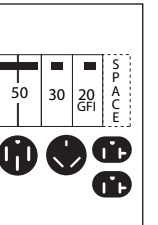
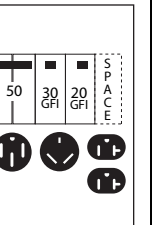
						
14-50R 5-20R2GFI	R32U 5-20R2	14-50R 5-20R2GFCI	14-50R, BR32U, 5-20R2GFCI	14-50R, BR32U, 5-20R2GFCI	14-50R, BR32U, 5-20R2	14-50R, BR32U, 5-20R2GFCI
H U042GP6	I U043GP6	J U055CP6010 U055CP4010	K U075CP6010 U075CP4010	L U075CP6010D	M U075GP6 U075GP4	N U075GP6019

FIG.	UL	MODEL NUMBER		RECEPTACLES	CIRCUIT PROTECTION	AMP	VOLTS	WIRE RANGE*	CABINET SIZE	HUB OPENING	LOAD & NEUTRAL BAR	UNIT WT.	STD. PKG.
		EARTH BURIAL	PAD MOUNT										
A	Y	U004CP6010	U004CP4010 %	(2) 14 50R 5 20R2GFC	(2) CB250 CB120	120	120/240	T2	9PT	N	LC55N1	47	1
B	Y	U011CP6010	U011CP4010	(2) 5 20R2GFC	(2) CB120 SPACE CB120	70	120/240	T2	6PT	N	LC33N7	32	1
C	Y	U011GP6	U011GP4	(2) 5 20R2	(2) GF 120 SPACE CB120	70	120/240	T2	6PT	N	LC33N7	32	1
D	Y	U040GP6	U040GP4	R32U 5 20R2	GF 130 GF 120 SPACE CB120	70	120/240	T2	9PT	N	LC33N7	32	1
E	Y	U040GP6010	-----	R32U 5 20R2GFC	GF 130 CB120 SPACE CB120	70	120/240	T2	9PT	N	LC33N7	32	1
F	Y	U041CP6010 % +	U041CP4010 % +	R32U 5 20R2GFC	CB130 CB120 SPACE CB120	70	120/240	T2	6PT	N	LC33N7	32	1
G	Y	U041GP6	U041GP4	R32U 5 20R2	CB130 GF 120 SPACE CB120	70	120/240	T2	6PT	N	LC33N7	32	1
H	Y	U042GP6		R32U 5 20R2	GF 130 MA N CB130 CB120	30	120	T2	6PT	N	LC33N7	32	1
I	Y	U043GP6		R32U 5 20R2	CB130 MA N CB130 GF 120	70	120/240	T2	6PT	N	LC33N7	32	1
J	Y	U055CP6010	U055CP4010	14 50R 5 20R2GFC	CB250 CB120	70	120/240	T2	6PT	N	LC33N7	32	1
K	Y	U075CP6010 %+	U075CP4010 %	14 50R BR32U 5 20R2GFC	CB250 CB130 CB120 SPACE CB120	100	120/240	T2	9PT	N	LC55N1	47	1
L	Y	U075CP6010D P+		14 50R BR32U 5 20R2GFC	CB250 CB130 CB120 SPACE CB120	100	120/240	T2	9PT	N	LC55N1	47	1
M	Y	U075GP6	U075GP4	14 50R BR32U 5 20R2	CB250 CB130 GF 120	100	120/240	T2	9PT	N	LC55N1	47	1
N	Y	U075GP6019		14 50R BR32U 5 20R2	CB250 GF 130 GF 120	100	120/240	T2	9PT	N	LC55N1	47	1

% Available with factory-installed TV/Telephone, replace "010" with "031"

Tv/Tel model diagrams on page 86

P Post depth dimension is non-standard (4-3/8")

* Wire Range Table on page 92

+ Available w/350 MCM loop lugs, replace "010" with "039"

MODEL NUMBER	REPLACEMENT PARTS		CABINET SIZE pages 90 91	ENCLOSURE STYLE page 90	CABINET DIMENSIONS **			KNOCKOUT FIGURE page 90
	METER SOCKET	POST LUGS			HEIGHT	WIDTH	DEPTH	
					A	B	C	
U041GB6		LT100B250	6PT					
U041GP4		LT100S300	6PT					
U041GP4L		LT100S250	6PT					
U041GP6		LT100S300	6PT					
U041GP6L		LT100S250	6PT					
U041GTL			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U042GB6		LT100B250	6PT					
U042GP6		LT100S300	6PT					
U043GP6		LT100S250	6PT					
U055C010			6 X 14	A	14 3/8"	7 1/4"	5 3/16"	1
U055CP4010		LT100S300	6PT					
U055CP6010		LT100S300	6PT					
U055G			6 X 14	A	14 3/8"	7 1/4"	5 3/16"	1
U055GB6		LT100B250	6PT					
U075CB4010		LT100B350	9PT					
U075CB4031		LT100B350	9PT					
U075CB4L10		LT100B350	9PT					
U075CB6010		LT100B350	9PT					
U075CB6031		LT100B350	9PT					
U075CB6L10		LT100B350	9PT					
U075CP4010		LT100S300	9PT					
U075CP4031		LT100S300	9PT					
U075CP4L10		LT100S300	9PT					
U075CP4L31		LT100S250	9PT					
U075CP6010		LT100S300	9PT					
U075CP6010D		LT100S250	9PT					
U075CP6031		LT100S300	9PT					
U075CP6039		LT100S350	9PT					
U075CP6039D			9PT					
U075CP6L10		LT100S300	9PT					
U075CP6L31		LT100S300	9PT					
U075CTL010			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U075CTLL10			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U075GB6		LT100B350	9PT					
U075GP4		LT100S300	9PT					
U075GP4L		LT100S250	9PT					
U075GP6		LT100S300	9PT					
U075GP6019		LT100S250	9PT					
U075GP6L		LT100S300	9PT					
U075GTL			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U076C010			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U131CP6010		LT100S250	14PT					
U131CTL010			14 X 21	A	21 3/8"	14 3/4"	6 7/16"	3
U175CP6HP010			14PT					
U355C010			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U355G			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U355GP6		LT100S250	9PT					
U412CP6010		LT100S300	9PT					
U412G			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U412GP6		LT100S300	9PT					
U611CB4010		LT100B250	9PT					
U611CB6010		LT100B250	9PT					
U611CP4010		LT100S250	9PT					
U611CP6010		LT100S300	9PT					
U611CTL010			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U611GTL			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U775C010			9 X 17	A	17 3/8"	9 3/4"	5 3/16"	2
U775CP4010		LT100S300	9PT					
U775CP6010		LT100S250	9PT					

** For Post Cabinet Sizes and Dimensions see page 91