

Wall Light

64 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT

Glare Free



Design is Protected by U.S. Patent No. 9,482,395



WLD64LED

WATTS: 64

CCT: 4500K
LUMENS: 6,966
LPW: 111 CRI: 83
DIMMING: 10-100%

CCT: 3000K
LUMENS: 6,501
LPW: 104 CRI: 81
DIMMING: 10-100%

Ordering Information

CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WLD64LED	64W LED Wall Light	120-277	4500K
WLD64LED3K	64W LED Wall Light	120-277	3000K

Options

ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol
EB	Emergency Back-Up
4	480V Driver


Note: Atlas uses only premium LED compatible photocontrols

Performance


- 95% Efficient Reflector Targets the Light
- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern

Dimensions and Specifications

Overall Height: 9.01" **Depth: 9.78"**
Overall Width: 18.2" **Weight: 15 lbs.**

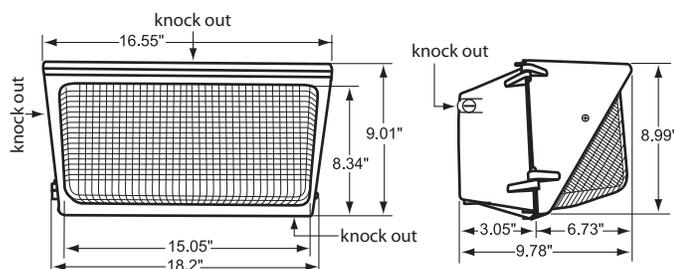

Recommended Mounting Height - 18-20 ft.

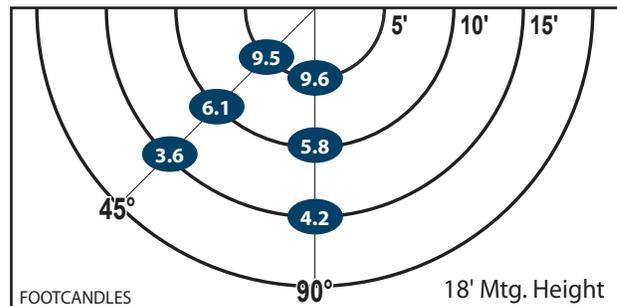

Mtg. Hgt.	FOOTCANDLES ON THE GROUND						Avg. FCs 450 SQ. FT.
	90°			45°			
	5'	10'	15'	5'	10'	15'	
18'	9.6	5.8	4.2	9.5	6.1	3.6	6.5
20'	6.8	4.8	3.4	6.6	5.2	3.4	5.0

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

